
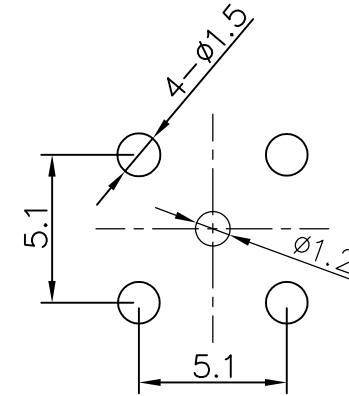
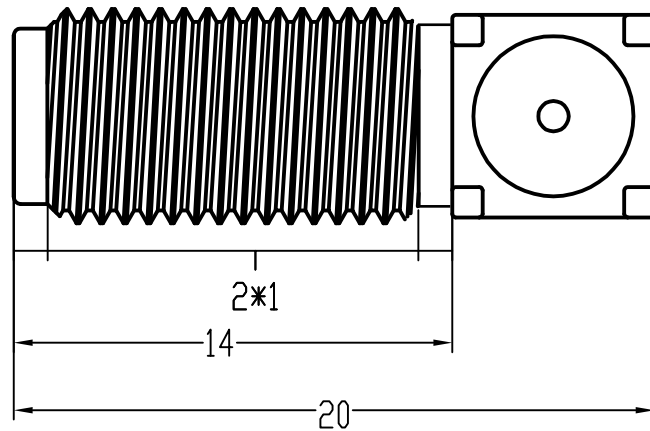


RoHS Compliant

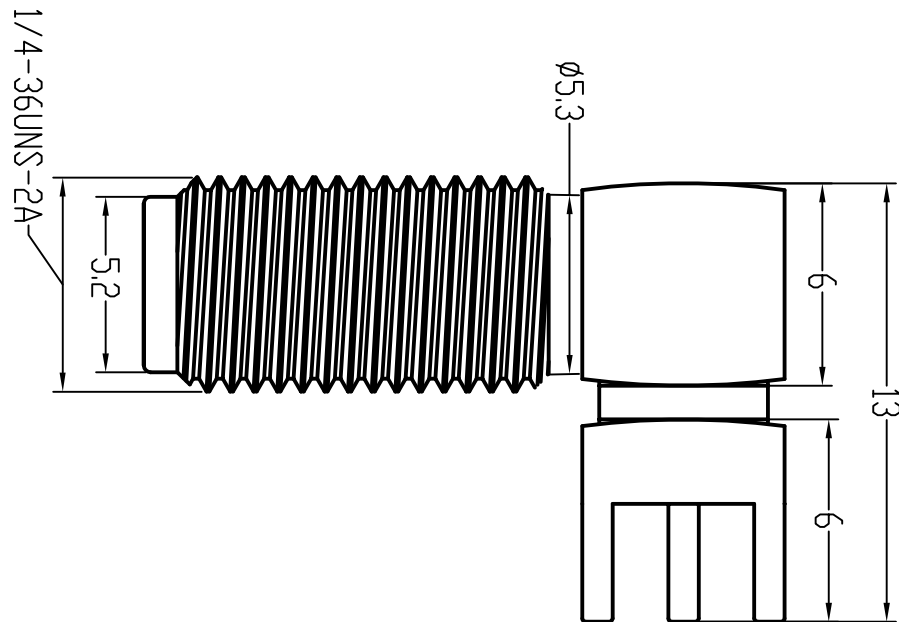

PCB板

#### ■电气特性 (Electrical performance)

- ▲ 特性阻抗 (Characteristic impedance) : 50Ω
- ▲ 使用频率范围 (Rated current) : 0~18GHz
- ▲ 接触电阻 (Contact resistance) : 内导体≤ 3mΩ 外导体≤2mΩ
- ▲ 耐电压 (Dielectrically withstanding voltage): 1000VRMS
- ▲ 额定电压 (Voltage rating) : 335 VRMS
- ▲ 绝缘电阻 (Insulation Resistance): ≥ 5000MΩ

|                                                        |                                                                   |               |                     |               |    |
|--------------------------------------------------------|-------------------------------------------------------------------|---------------|---------------------|---------------|----|
| 深圳市敏连达科技有限公司<br>Shenzhen Minlianda Technology Co.,Ltd. |                                                                   | 品名 (ITEM NO)  | SMA 带孔90° DIP L20.0 |               |    |
|                                                        |                                                                   | 料号 (PART NO)  | MLD-SMA-KWE14-L20   |               |    |
| 单位 (UNIT): MM                                          | 未注公差<br>TOLERANCE UNSPECIFIED                                     | 版次 (REV): A/0 | 页次 (PAGE): 1/1      | 设计 (DESIGN)   | 柯南 |
| 比例 (SCALE) 1:1                                         | X.X ± 0.38<br>X.XX ± 0.20<br>X.XXX ± 0.10<br>X" ± 5"<br>X.X" ± 2" | 模号 (MODEL NO) |                     | 审核 (CHECKED)  | 邱敏 |
|                                                        |                                                                   | 图号 (DWG NO)   |                     | 核准 (APPROVED) | 陈镇 |