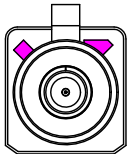
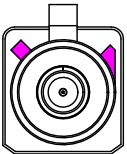
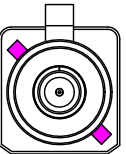
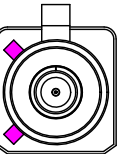
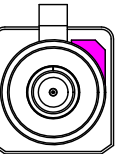
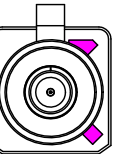
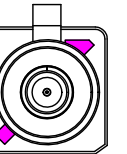
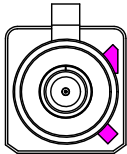
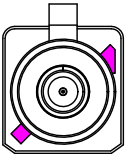
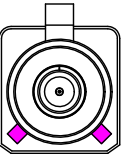
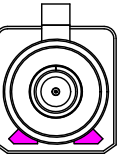
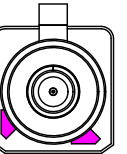
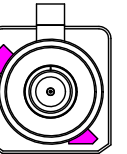
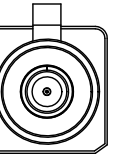


1		2		3		4	
RoHS						REVISIONS	
						REV. ECN NO. LOCATION DESCRIPTION DATE DESIGN	
						A0 N/A INITIAL RELEASE 2024.08.232024.08.23	
						Specifications(规格):	
						1.Impedance(特性阻抗): 50Ω;	
						2.Frequency (工作频率): DC~6GHz;	
						3.VSWR (电压驻波比): 1.50@3GHz;	
						1.60@6GHz;	
						4.Insulation resistance(绝缘阻抗): ≥100MΩ;	
						5.Dielectric withstand voltage (介质耐电压): 800V AC;	
						6.Mating cycles (耐久性): ≥5 cycles; ;	
						7.Retention force latch(保持力): ≥110N;	
						8.Temperature range(使用温度): -40℃~+105℃;	
						9.Waterproof Rating(防水等级): IP67;	
						10.PART NO.:	
						XK1PLM1S6-WA06-X	
						11.Housing P/N:	
						Code: A~Z	
						XKHM1-PT24-X	
						Code: A~Z	

Code List:

Colde							
	A	B	C	D	E	F	G
Color/RAL-No.	Black/9005	White/9001	Blue/5005	Bordeaux/4004	Green/6002	Brown/8011	Grey/7031
PART NO.	XK1PLM1S6-WA06-A	XK1PLM1S6-WA06-B	XK1PLM1S6-WA06-C	XK1PLM1S6-WA06-D	XK1PLM1S6-WA06-E	XK1PLM1S6-WA06-F	XK1PLM1S6-WA06-G
Colde							
	H	I	K	L	M	N	Z
Color/RAL-No.	Violet/4003	Beige/1001	Curry/1027	Carmine red/3002	Pastel Orange/2003	Pastel Green/6019	Water Blue/5021
PART NO.	XK1PLM1S6-WA06-H	XK1PLM1S6-WA06-I	XK1PLM1S6-WA06-K	XK1PLM1S6-WA06-L	XK1PLM1S6-WA06-M	XK1PLM1S6-WA06-N	XK1PLM1S6-WA06-Z

NOTE: ALL RIGHTS RESERVED,BANNED COPY!

ANGLAR	±5°
X.	±0.40
X.x	±0.30
X.xx	±0.15
X.xxx	±0.15
UNSPECIFIED TOLERANCES	



DESIGN	希文	VIEW: 	MODEL TYPE: FAKRA Male Connector for RG58,IP67		
CHECKED		UNIT: mm/in	PART NO.: XK1PLM1S6-WA06-X		
APPROVED		SIZE: A4	DWG NO.: X-XK1PLM1S6-WA06-X		
			SCALE	PAGE	REVISION
			N/A	2/2	A0