

Electrical Characteristics/电气特性

% of Rated Current	Opening Time
100%	4 hours, Minimum
200%	1~60 seconds
250%	5 seconds, Maximum

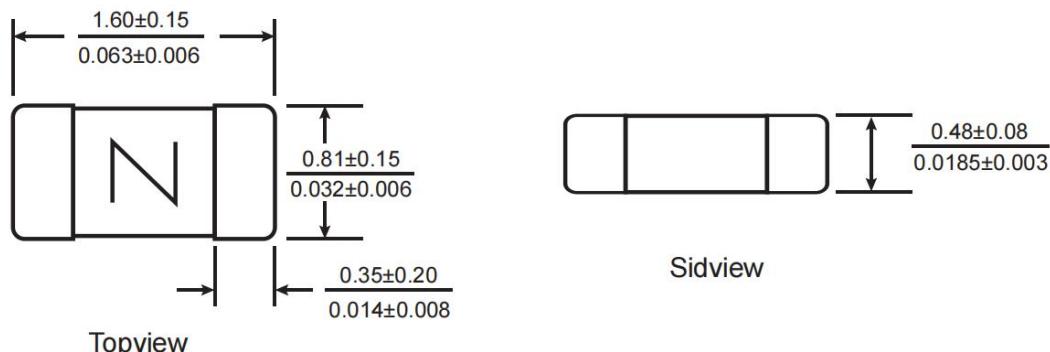
Performance Specifications/电性参数

Part Number	Marking	Rated Current (A)	Rated Voltage DC(V)	Interrupting Rating	Typical Cold Resistance (mΩ)	Typical Voltage Drop (mV)	Typical Pre-Arcing I ² t (A ² sec)
LTC0603-1800TSL	Z	8	32V	50A	6.3	66	3.43

■ DC Interrupting Rating (Measured at rated voltage, time constant of less than 50 microseconds, battery source)
 ■ DC Cold Resistance are measured at <10% of rated current in ambient temperature of 25°C
 ■ Typical Pre-Arcing I²t are measured at 100% of rated current.

Product Dimensions (mm)/产品尺寸

Drawing not to scale (Unit:mm/inch)


Packing/包装

Packaging Option	Quantity
LTC0603-1800TSL	5000 pcs/reel