



Color: ☐ multi-colored

Physical data	
Pin spacing	4/8 mm
Blade width	4 mm
Blade length	40 mm
Grip length	100 mm

Mechanical data	
Suitable	for 2060 Series
Tip type	Operating
Continuous blade	No
Blade type	Straight
Roll-away protection	Yes
Hanging eyelet	Yes
Grip marking	Yes

Material data	
Color	multi-colored
Material 1	Polypropylen (PP)
Material 2	Thermoplastische Elastomere (TPE)
Fire load	0 MJ
Blade surface	Burnished
Weight	24.5 g



Commercial data	
Product Group	14 (Tools)
PU (SPU)	5 pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821827726
Customs tariff number	82055980000

Product Classification	
UNSPSC	27111601
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 9.0	EC002848
ETIM 10.0	EC002848
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance


Compliance Search

Environmental Product Compliance 206-860

↓

Installation Notes

Conductor termination

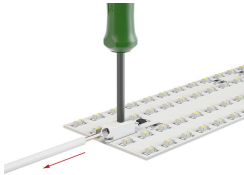

Inserting/removing fine-stranded conductors by lightly pressing on a push-button.

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com