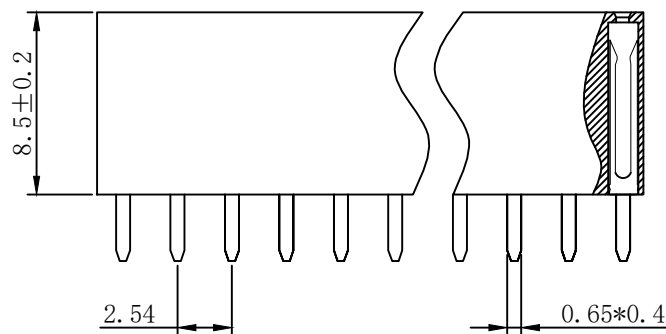
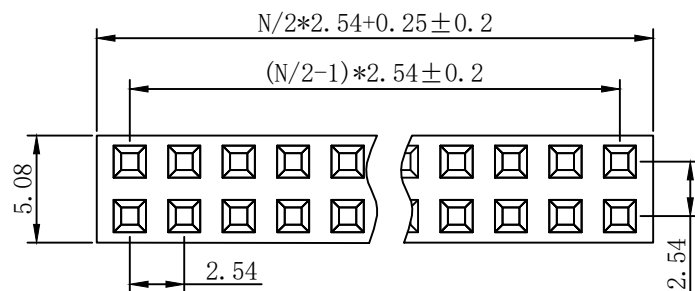


材料Material

原料Insulator:PBT(UL 94V-0)

相关材料Related Material: Brass

表面涂层Surface Coating: Au or Over Ni

规格Specification

额定电流Current rating:2.5AMP

耐压Dielectric Withstanding Voltage:1000v Ac Min

绝缘电阻Insulation Resistance:1000MΩ min

接触电阻Contact resistance:20MΩ Max

工作温度Working Temperature:-40℃~+105℃

Max.Processing Temp瞬时温度:

PBT 230° ±5° 10S

上海洲日电子有限公司

Shanghai Zhouri Electronics CO.,LTD

上海康司玛电子科技有限公司

Shanghai KSM Electronic Technology Co., Ltd

tel:021-51571121

<http://www.zhouri.net>

fax:021-51571120

<http://www.ksmchina.com>

产品名称:

2.54-2*N

绘图:

牛万龙

日期:20250617

审核:

张海娜

日期:20250617

版本编号:

ZRLCGY2025-06-17-CJ A/1

第三视角:

单位: mm

比例:

图幅:A4

页次 共 01 第 01