


Dimensions

■ Servo motor with tachogenerator

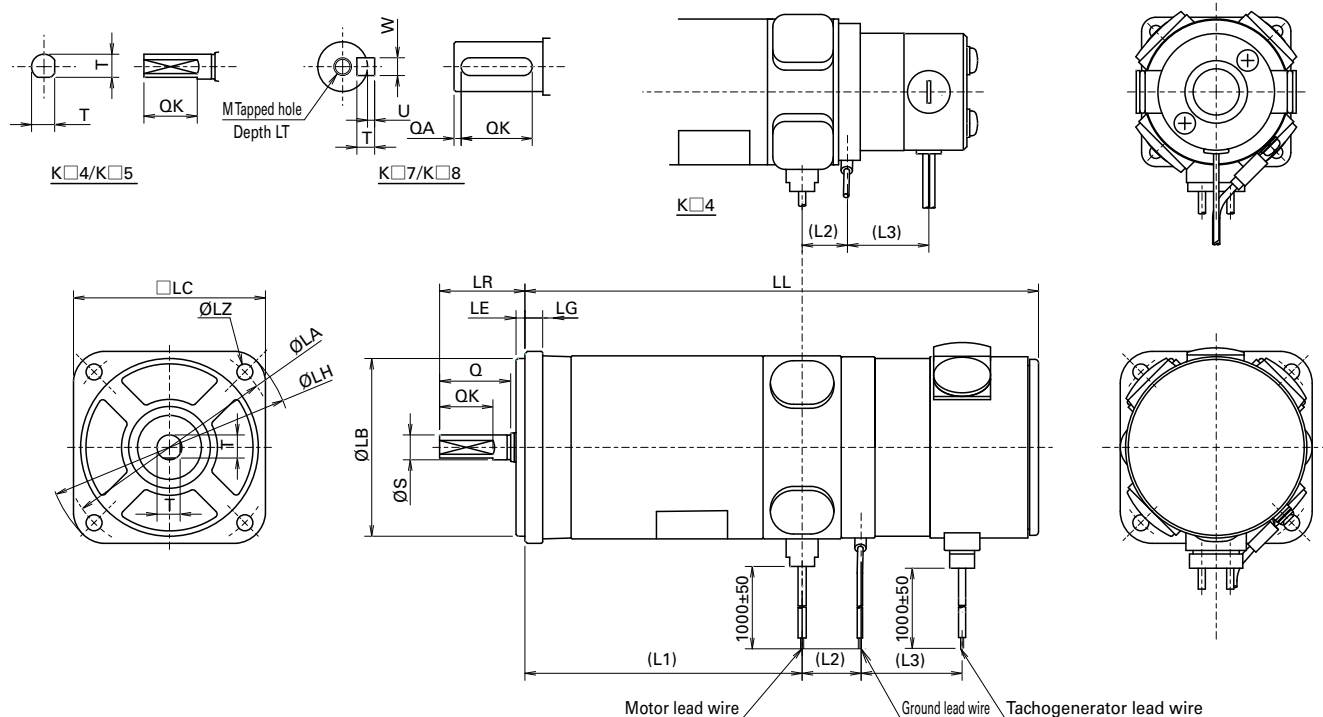

(Unit: mm)

Model No.	LL	LG	L1	L2	L3	LA	LB	LE	LH	LC	LZ	LR	
KB402TXX	85±1	5±0.5	40.5	11.5	23	48±0.2	0 34-0.025	2±0.3	56	42±0.5	4-φ3.5	24±0.8	
K□404TXX	98±1		53.5										
K□406TXX	111±2		66.5										
K□506TXX	124.5±2		58	17	28	60±0.3	0 50-0.025	2.5±0.3	69	54±0.5	4-φ4.5		
K□511TXX	144.5±2		78										
KA720TXX	148.5±2	8±0.5	74.5	17.5	34	90±0.3	0 70-0.030	3±0.4	100	76±0.8	4-φ5.5	30±0.8	
KA730TXX	172.5±2		98.5										
KA840TXX	183±2		103.5	22	33	100±0.3	0 80-0.030		112	88±0.8	4-φ6.6	35±0.8	
KA850TXX	197.5±2		118.5										

Model No.	S	Q	QA	QK	W	T	U	M	LT	Mass [kg]
KB402TXX	0 7 -0.009	20±0.5	—	15±1.5	Two slots 6.5±0.2			—	—	0.34
K□404TXX										0.49
K□406TXX										0.59
K□506TXX										1.0
K□511TXX										1.21
KA720TXX	0 14 -0.011	25±0.5	2	20±0.7	+0.024 5+0.012	5	0 2-0.2	M5	8	2.15
KA730TXX	0 16 -0.011	30±0.5		25±0.7				M6	10	2.85
KA840TXX										3.85
KA850TXX										4.45