


This document contains proprietary information and such information may not be disclosed to others for any purposes, not used for sales/marketing/procurement purposes without written permission

REV	DESCRIPTION OF REVISION	ECN NO.	BY	DATE	APPROVED
A	Initial Release	—	H.wei	19/03/17	19/03/17

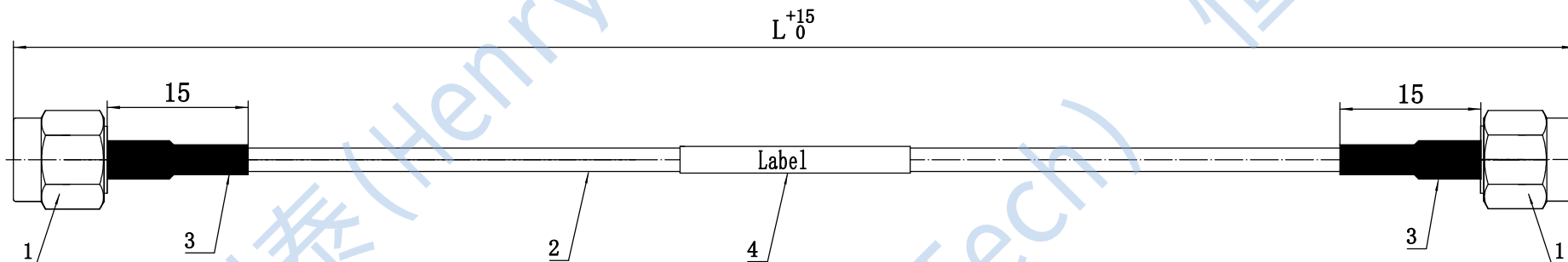

1 Electrical 电气性能

1.1 Impedance 特性阻抗: 50 Ω

1.2 Frequency 频率范围: DC~6GHz

1.3 VSWR 电压驻波比: ≤ 1.30

1.4 Insulation resistance 绝缘电阻: $\geq 5000M\Omega$

1.5 Dielectric withstanding voltage 介质耐压: 1000V

No.	Product Model	Length L(mm)
1	HL-SMAM-086-SMAM-100MM	100mm
2	HL-SMAM-086-SMAM-150MM	150mm
3	HL-SMAM-086-SMAM-200MM	200mm
4	HL-SMAM-086-SMAM-300MM	300mm
5	HL-SMAM-086-SMAM-1000MM	1000mm

No.	Description	Qty.	Note
1	SMA Male Conn.	2	
2	RG086 Cable	1	
3	Black Color Heat Shrinkable Tube	2	
4	Lable White Color	1	

DRAWN: H.wei 19/03/17
ENGINEER: L.yu 19/03/17
APPROVED: W.yi 19/03/17
TOLERANCES UNLESS OTHERWISE SPECIFIED: X ± 0.50 .X ± 0.20 XX ± 0.10 ANGLES $\pm 1^\circ$

TITLE: Cable Assembly SMA Male Both End for RG086 Cable
PART NO: HL-SMAM-086-SMAM-100MM

 HenryTech			
 DIMENSION IN MILLIMETERS (mm)			
SIZE: A4	SCALE: N/A	SHEET: 1/1	REV: A

Notes:

1. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE NOTICE AT ANY TIME

2. CUSTOMER OUTLINE DRAWING FOR REFERENCE ONLY