


FEATURES

- Non-fused terminal block
- Nylon body
- Nickel plated brass clamps

RS PRO, 12 Way, 4mm², Nylon Non-Fused Terminal Block, 400V

RS Stock No.: 492-8700

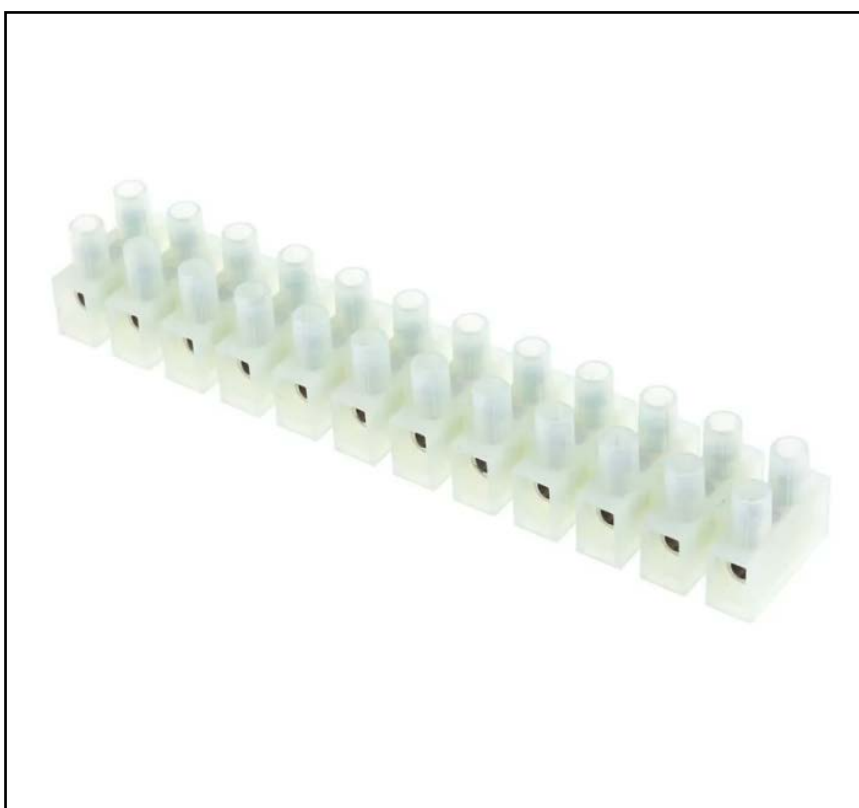

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

From RS PRO, this non-fused terminal block presents a reliable and cost-effective solution to wire-to-wire connections. This nylon terminal block has a quick-snap body that allows you to easily shorten the length, allowing for a highly customizable connector solution.

General Specifications

Fused	No
Mounting Type	Through Hole
Contact Material	Brass
Termination Method	Screw Down
Contact Plating	Nickel
Colour	Natural
Material	Nylon
Wire Protection	Yes
Number of Ways	12
Applications	Connecting lighting to switches, Connecting wiring to a ground, HVAC Systems, Power Supplies

Electrical Specifications

Current Rating	32A
Voltage Rating	400V
Test voltage	2500V

Mechanical Specifications

Wire Size	4mm ²
Pitch	10mm
Screw Size	M3 x 6mm

Operation Environment Specifications

Maximum Operating Temperature	125°C
-------------------------------	-------

Approvals

Standards Met	RoHS, CE, UL 94V-2, IEC 695-2-1, 2
---------------	------------------------------------

