
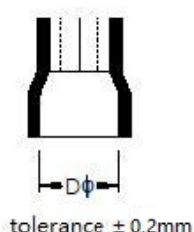


Datasheet

Insulated Crimp Spade Connector

RS Stock number 208-2515, 534-272, 534-266, 534-250, 534-632, 534-626, 534-610, 534-503

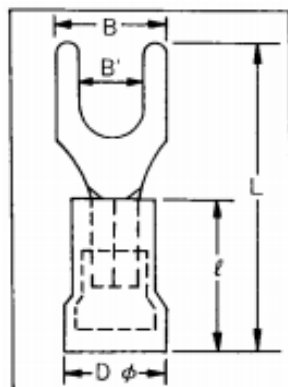

Insulated	Wire range		Dimensions(mm)					Stud size B'	
Stock no.	AWG	mm ²	Colour	B	D φ	L	ℓ	AWG	mm
2082515	22-16	0.5-1.5	Red	5.7	4.3	20.5	9.9	4	3.2
534272	22-16	0.5-1.5	Red	6.4	4.3	20.0	9.9	6	3.7
534266	22-16	0.5-1.5	Red	7.2	4.3	20.5	9.9	8	4.3
534250	22-16	0.5-1.5	Red	9.5	4.3	20.0	9.9	10	5.3

Stock no.	AWG	mm ²	Colour	B	D φ	L	ℓ	AWG	mm
534632	16-14	1.5-2.5	Blue	6.4	4.8	20.5	9.9	6	3.7
534626	16-14	1.5-2.5	Blue	7.2	4.8	20.5	9.9	8	4.3
534610	16-14	1.5-2.5	Blue	9.5	4.8	20.5	9.9	10	5.3

Stock no.	AWG	mm ²	Colour	B	D φ	L	ℓ	AWG	mm
534503	12-10	2.5-6.0	Yellow	6.4	6.5	25.5	13.5	6	3.7

Tolerant: ± 0.5mm