



EN

Datasheet

RS PRO NYLON-INSULATED CORD END TERMINALS

Stock number: 178-7280

MAXIMUM ELECTRIC CURRENT:

A.W.G.	24
AMP.	5.5


MAXIMUM ELECTRICAL RATING: 105° C 600 VOLTS MAX.

INSULATION MATERIAL: NYLON

TERMINAL MATERIAL: COPPER TUBE

SURFACE TREATMENT: TIN PLATE

INSULATION COLOR: VIOLET

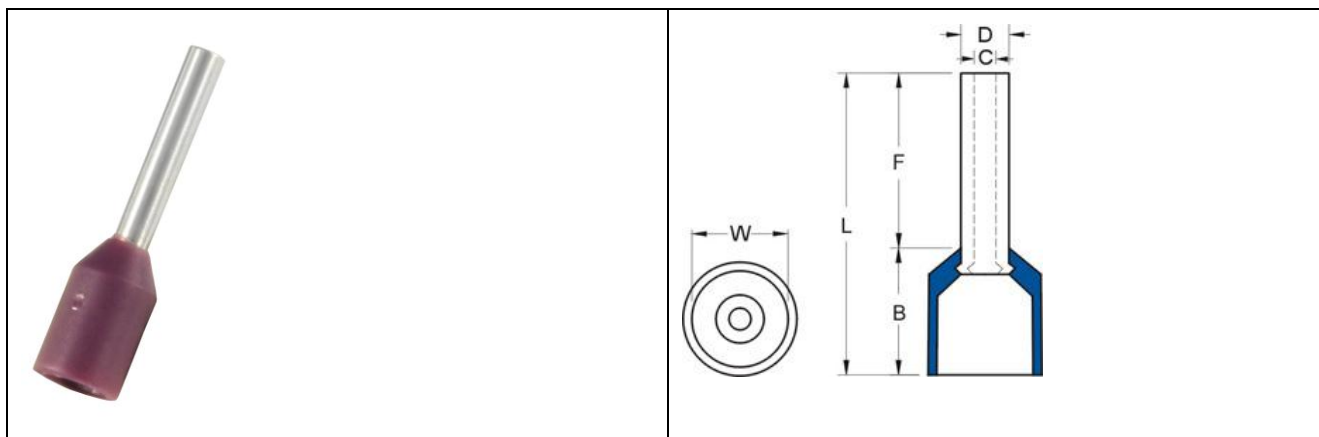

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION inch(mm)					
		F	L	W	B	D	C
24 A.W.G. 0.25 mm ²	 178-7280	0.236 6	0.409 10.4	0.075 1.9	0.173 4.4	0.043 1.100	0.031 0.8