

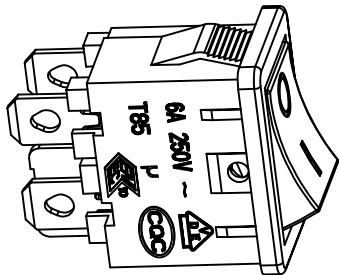
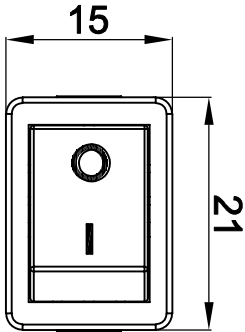
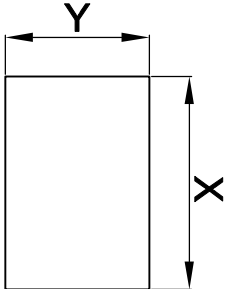


MR-6

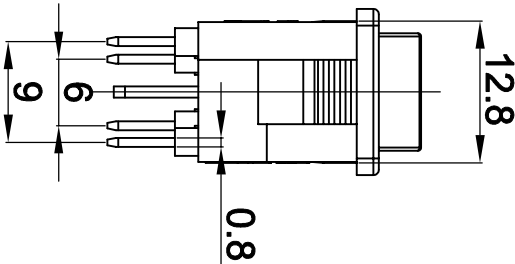

受控文件

Rating: 10A 125V AC (UL CUL)  
6A 250V AC (UL CUL TUV CB) 
Contact Resistance: 50mΩ Max
Insulation Resistance: DC 500V 100MΩ Min
Dielectric Strength: AC1500V 1 minute
Electrical life: 10,000 cycles
Operating Temperature: 0°C~85°C

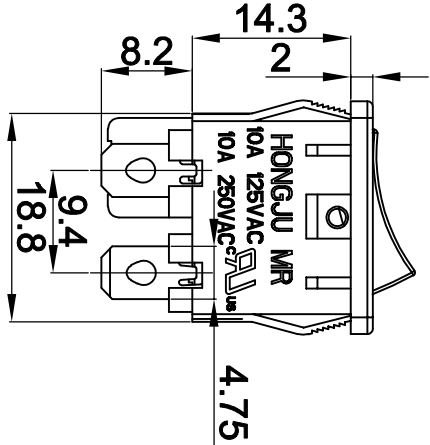


CUT-OUT

	X	Y
0.75~1.25	19.2-0.1	13.0+0.1
1.25~2.00	19.4-0.1	13.0+0.1
2.00~3.00	19.8-0.1	13.0+0.1



MATERIAL:

Body:Nylon66,UL rated:94V-0 min
Actuator:Nylon66,UL rated:94V-0 min
Terminal:Brass,silver or tin plated

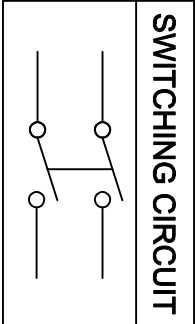

X	0	1	2	4	5	6	7
Marking	None						

公差 TOLERANCES				X±0.3		YX±0.2		角度 ANGLE ±1°		单位 DIMENSION UNIT		mm.	
版本 VERSION				A1		比例尺 SCALE		NONE		日期 DATE		品名 TITLE	
A1				重新整理后发行		2014.07.15		N/A		核准		MR-6-210-C5N-WW	
版本 VER				变更说明 CHANGE DESCRIPTION		日期 DATE		ECN NO.		APPROVED BY		Z.H.B.	
						核 对		CHECKED BY		绘图		DRAWN BY	
												MR-6-210-C5N-WW_A1	
												图号 DRAWING NO	