

RoHS


Specifications(规格):

- 1.Impedance(特性阻抗) : 50Ω;
2.Frequency (工作频率) : DC~6GHz;
3.VSWR (电压驻波比) : 1.50@3GHz; 1.60@6GHz; .
4.Insulation resistance(绝缘阻抗) : ≥100MΩ;
5.Dielectric withstand voltage (介质耐电压) : 800V AC;
6.Mating cycles (耐久性) : ≥25 cycles;
7.Retention force latch(保持力) : ≥110N;
8.Temperature range(使用温度): -40℃~+105℃;

PART NO.:

X Z X T 1 - M4F-XXXX-K1F- X X
① ② ③ ④ ⑤

- ① Cable TYPE:
3: RG174
4: 1.5DS
7: Dacar302
8: RG174LL
② Successive number: 1~Z
③ Length (mm): 1000=1000mm
④ Coding A: A~Z
⑤ Coding B (B1~B4): A~Z

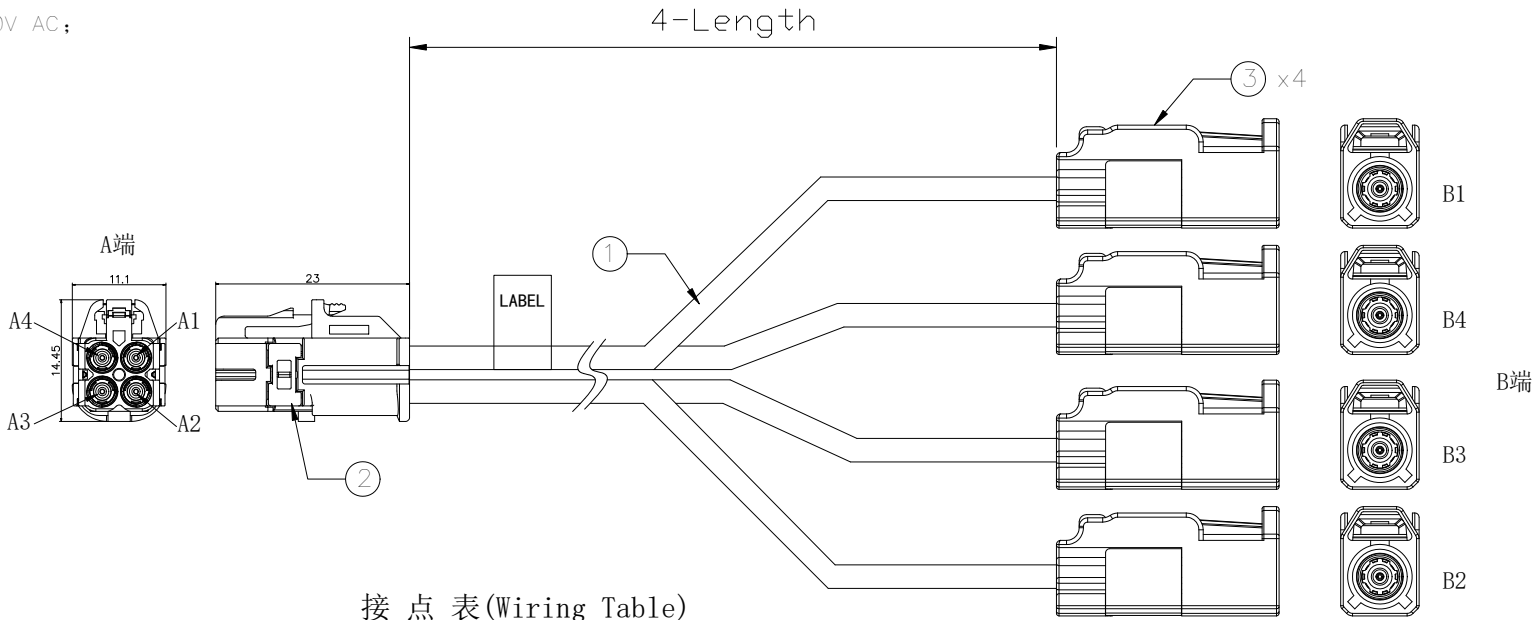

接点表(Wiring Table)

A端(A port)	Cable	B端(B port)
A1 [Pin shell]	Conductor Braid	Pin Shell B1
A2 [Pin shell]	Conductor Braid	Pin Shell B2
A3 [Pin shell]	Conductor Braid	Pin Shell B3
A4 [Pin shell]	Conductor Braid	Pin Shell B4

PART NO.	Length (mm/inch)	TOLERANCES (mm/inch)
XZ8T1-M4F-500-K1F-ZZ	500 [19.685]	±10 [0.394]
XZ8T1-M4F-1000-K1F-ZZ	1000 [39.370]	±15 [0.591]
XZ8T1-M4F-1500-K1F-ZZ	1500 [59.055]	±15 [0.591]
XZ8T1-M4F-2000-K1F-ZZ	2000 [78.740]	±20 [0.787]
XZ8T1-M4F-3000-K1F-ZZ	3000 [118.110]	±30 [1.181]

3	Connector	FAKRA Female connector,Z Code	4SET	
2	Connector	MINI FAKRA female connector(T),Z Code	1SET	
1	Cable	RG174LL Cable PVC OD2.80mm Black,-40~105℃	4PCS	
NO.	NAME	SPEC.	Q'TY	NOTE



DESIGN 希文 VIEW:  MODEL TYPE:
Assembly cable, MINI FAKRA series
CHECKED UNIT: mm/in PART NO.:
XZ8T1-M4F-XXXX-K1F-ZZ
APPROVED SIZE: A4 DWG NO.:
X-XZ8T1-M4F-XXXX-K1F-ZZ

XKB INDUSTRIAL PRECISION CO.,LIMITED

SCALE	PAGE	REVISION
N/A	1/1	A0