
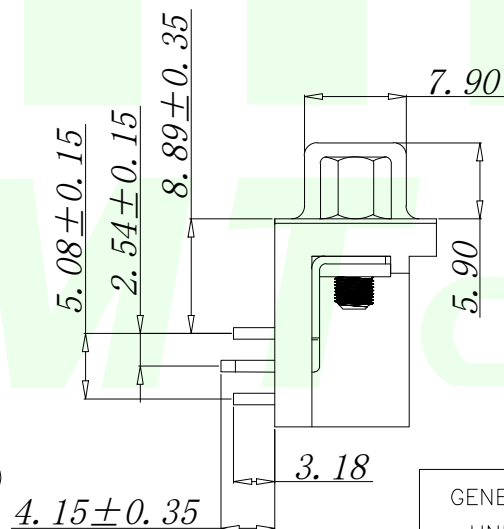
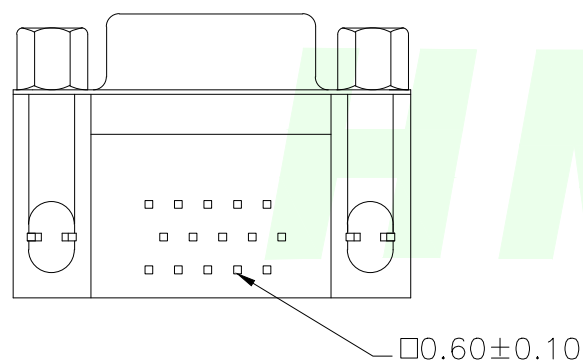


RoHs

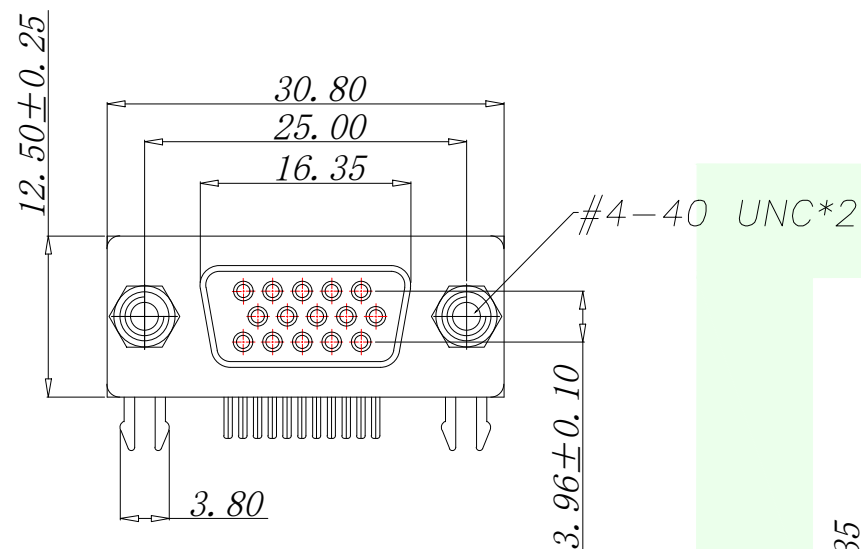


- MATERIAL:

1. Insulator: PBT+30% Glass Fiber
2. Contact: Brass
3. Contact Plated: Gold Flash over Tin Or Gold Plated Or Tin Plated
4. Shell: Steel, Nickel Plated

- SPECIFICATION:

1. Current Rating: 5 AMPS
2. Insulation Resistance: 100M Ω MIN. At 500VDC
3. Dielectric Strength: 500V for One minute
4. Operation Temperature: -55° C ~ +105° C.

* 【胶芯颜色、防火要求、环保要求及电镀规格 依据客户实际订单要求为准】

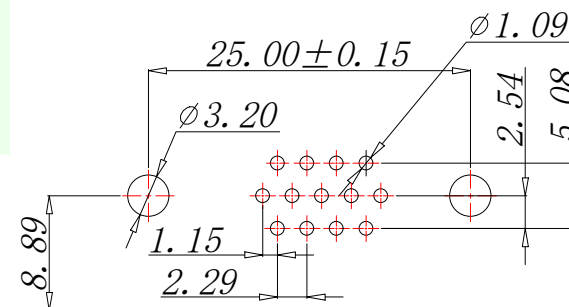GENERAL TOLERANCES
UNLESS SPECIFIED

X.X ±0.30 X.° ±5°

.XX ±0.20 X.X° ±1°

.XXX ±0.10 X.XX° ±0.5°

MANUFACTURE DWG



深圳市华明通电子有限公司

Shenzhen Huamingtong Electronics Co., Ltd

PART NO.

DSUB-DS1038-15FB

DESIGN: James

CHED: Talen

APPD: Sophia

TITLE:

HDR15F 铜锁

CUSTOMER

SCALE

N:A

SIZE

A4

SHEET

UNITS

MM

1/1