


产 品/Product : **H50 Rubber SMA-JW ,868M/915M,GSM900/1800M antenna**

料 号/PN : **AH1G.104**

应 用/Application : ISM 868/915MHz system, NB-IoT/GSM900/1800M, LoRa / Remote /Transfer /Recciever ;

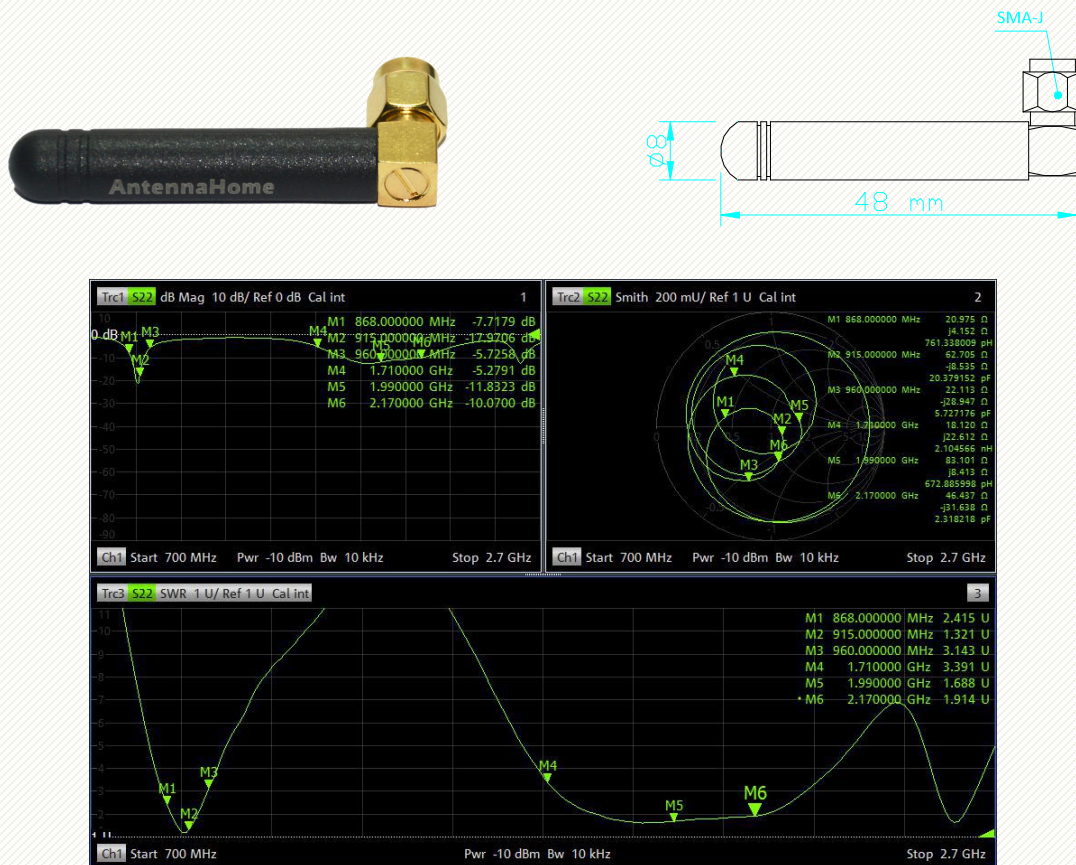

电气参数(Electrical Properties)

频率/Frequency:	868M/915M,GSM900/1800M
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤2.0
增益/Gain:	1.5 dBi
极化方式/Polarization:	Vertical / Omni

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	SMA-JW
材料&颜色/Material&Color:	Copper / ABS
安装方式/Mounting:	SMA connector
尺寸/Size:	∅8×H50 mm
重量/Weight:	5.7g/pcs
工作温度/Operate Temp:	-40 ~ 85 ℃

关联产品/Relation Product



SMA-K DIP ([AHCG.202](#))



SMA-K ASSY ([AHCG.101](#))



H175 Rubber Magnetic
([AH1G.401](#))





H200 FiberGlass ([AH1G.501](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

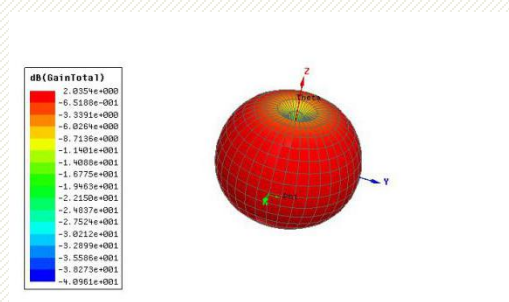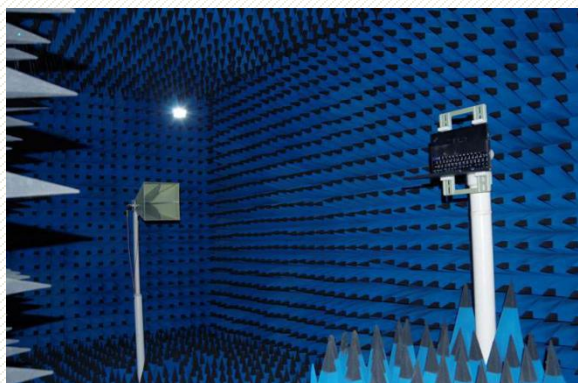

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)