


产 品/Product : **L200** RG316 **cable** NK-PIN, **Cable Assy**

料 号/PN : **AHCG.RG316NKPL200**

应 用/Application : **All RF transmit /receiver communication system ; ~6GHz**

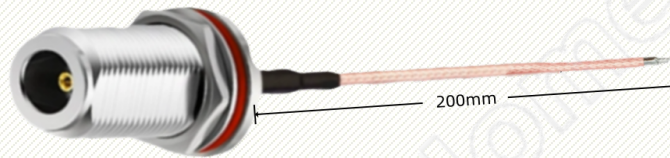

电气参数(Electrical Properties)

频率/Frequency:	DC~6000 MHz
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤ 1.3
插入损耗/Insertion Loss:	0.5 dB
极化方式/Polarization:	/

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	NK / P I N
材料&颜色/Material&Color:	Copper / Black cable
安装方式/Mounting:	SMA connector
尺寸/Size:	L=200 mm
重量/Weight:	48g/pcs
工作温度/Operate Temp:	-40 ~ +85 $^{\circ}\text{C}$

关联产品/Relation Product



SMA-K DIP ([AHCG.202](#))



SMA-K Q4 DIP ([AHCG.201](#))



SMA/B-IPX ([AHCG.102](#))





IPX G1 ([AHCG.204](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

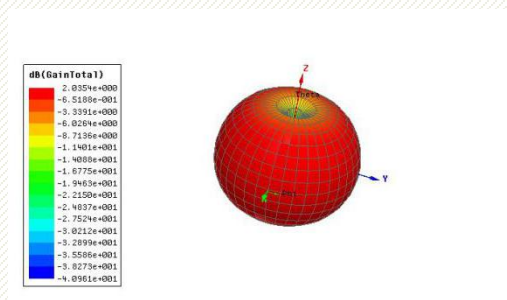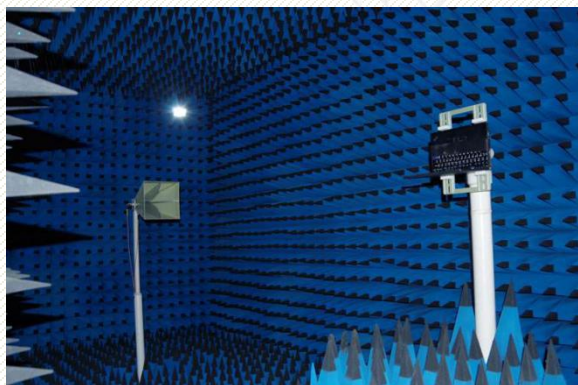

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)