


---

27.50

- 1.Current Rating:3A AC, DC
- 2.Voltage Rating:250V AC, DC
- 3.Temperatuer Range:−25°C~+85°C
- 4.Contact Resistance:30mΩ Max
- 5.Insulation Resistance: 1000MΩ Min
- 6.Withstanding Voltang: 800V AC/minute
- 7.Material:Housing PA66

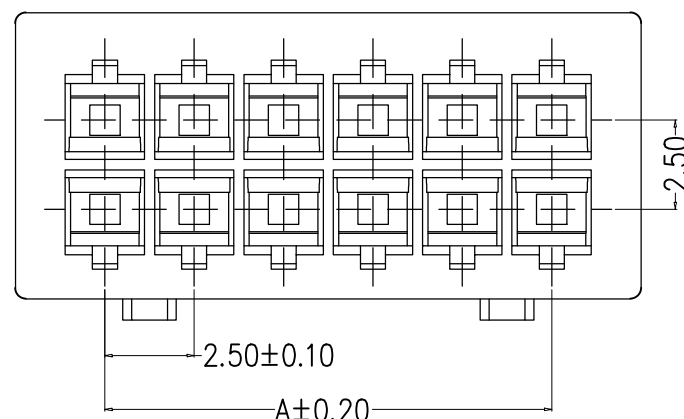