

7/16系列 射频同轴连接器

7/16 series RF Coaxial Connector

特性

- 较大型螺纹同轴连接器
- 紧固稳定、低损耗、工作电压高
- 具有防水结构
- 应用于微波传输和移动通信系统中

产品技术特点

温度范围：- 65~+125℃

特性阻抗：50Ω

频率范围：DC~7.5GHz

电压驻波比：≤1.15(DC~4GHz)

绝缘电阻：≥10000MΩ(实验电压500V)

介质耐压：3500V(rms)

工作电压：1800V(rms)

接触电阻：中心接触件：≤0.4mΩ;

外接触件：≤1.5mΩ


机械寿命：500次

执行标准

IEC 61169-1 GB/T 11313. 1



界面尺寸

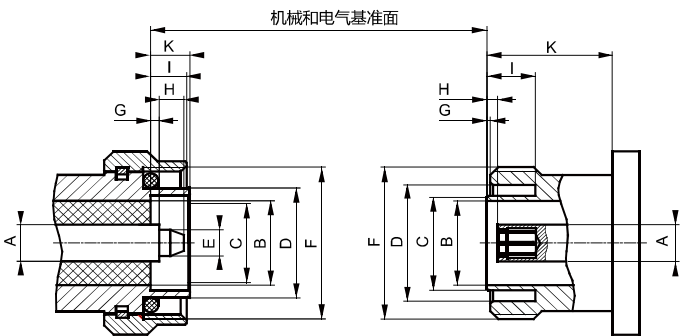


插针连接器




	Min(mm)	Max(mm)
A	7.00标称值	
B	Ø15.85	Ø16.25
C	Ø18.03	Ø18.21
D	Ø20.60	Ø21.40
E	Ø4.96	Ø5.04
F	M29X1.5	
G	1.47	1.77
H	/	4.50
I	7.00	9.00
K	7.00	8.00

插孔连接器




	Min(mm)	Max(mm)
A	7.00标称值	
B	Ø15.85	Ø16.25
C	Ø17.84	Ø18.02
D	Ø22.10	Ø22.90
E	/	/
F	M29X1.5	
G	0.5	0.7
H	1.77	2.07
I	8.10	/
K	10.00	/

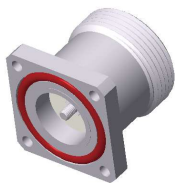



7/16-KFD-3

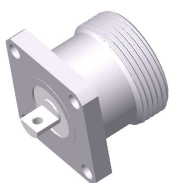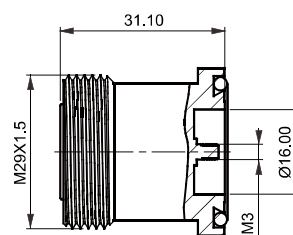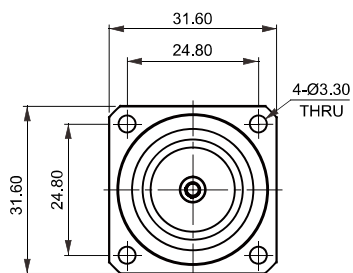



7/16-KFD-1

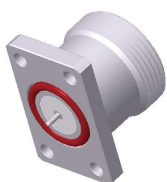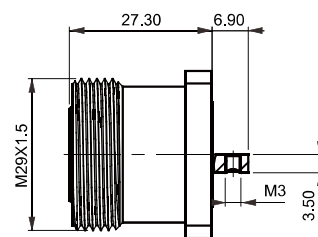
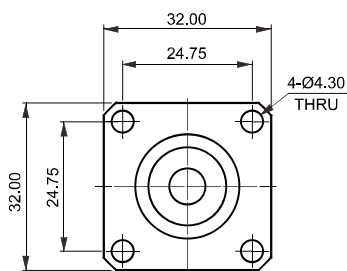


7/16-KFD-13

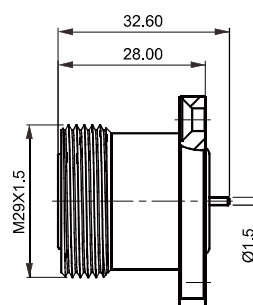
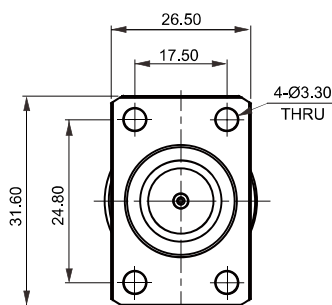


7/16-KFB3-13

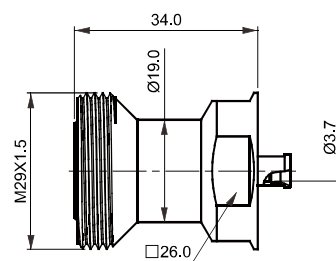
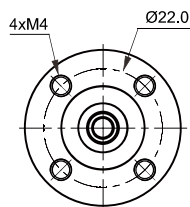


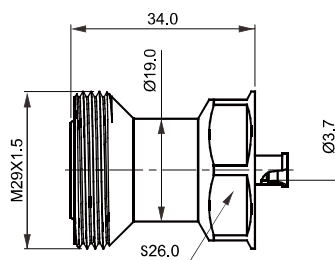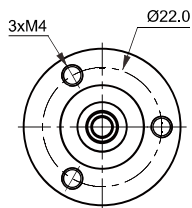



7/16-KFB3-14

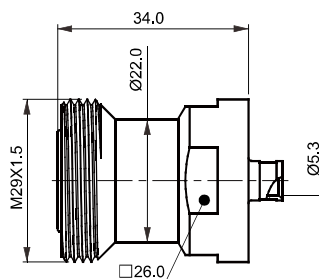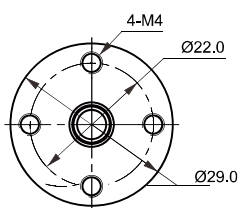

7/16-KFB3-3

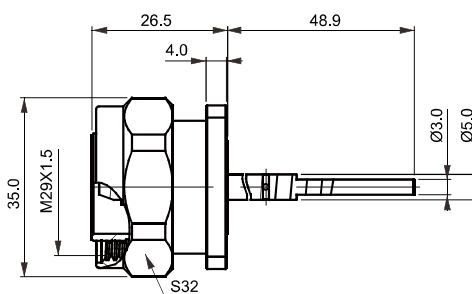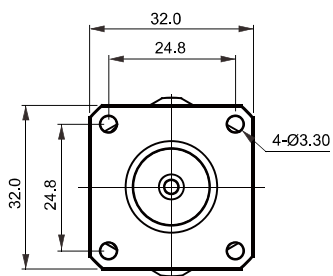

7/16-JFD

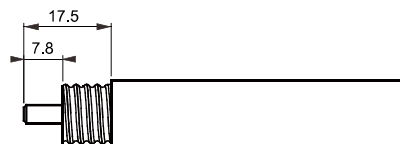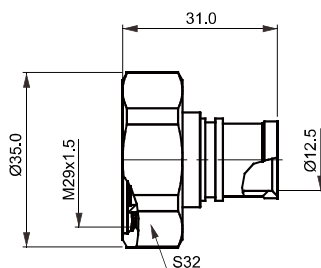

7/16-J533

MEMO

