



Features




- 1 **Modular plug supporting Cat.6A**
 - Transmission Speed : 10Gbps
 - Frequency : 500MHz
 - Ethernet Standard : 10GBASE-T
- 2 **EMI prevention**
- 3 **Easy assembly**
- 4 **Can be used for ix Industrial cable assemblies**
*Ideal when using ix Industrial with RJ45



Dimensions

TM61P-88P

(mm)

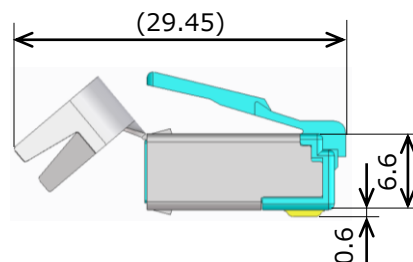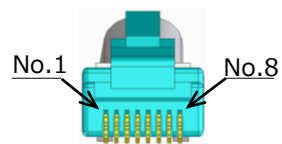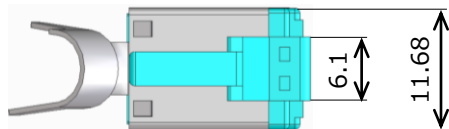

Cat.6A Compatible Modular Plug / Variation

Applicable Cable	TM61P Series	TM31P Series
Conductor	24-26 AWG Stranded Cable	24-27 AWG Stranded Cable
Insulation Diameter	ø0.9-1.0mm	ø0.9-1.0mm
Sheath Outer Diameter	ø6.0-6.5mm	ø5.8-6.0mm
Other	Available Latch Covers: - Black only - Protective latch cover - Short latch cover	

Specifications

Rated Current	1A
Rated Voltage	125V AC
Operating Temperature	-25 to +60℃*
Contact Resistance	50mΩ Max.
Withstanding Voltage	500V AC for 1 min.
Insulation Resistance	100MΩ Min. (100V DC)
Mating Durability	200 times

- RoHS Compatible

Nov.1.2025 Copyright 2025 HIROSE ELECTRIC CO., LTD. All Rights Reserved.

Product Number Structure

Plug TM61 P – 8 8P
 1 2 3 4

1 Series Name	TM61
2 Connector Type	P···Plug
3 Opening Size	8···8pos. size
4 No. of Pos.	8P···8pos.

Cover TM61P – BT
 1 2

1 Series Name	TM61P
2 Others	Short Cover, Black

Connector

Part No.	HRS No.	Purchase Unit
TM61P-88P	CL0222-0900-0	100pcs per tray
TM61P-BT	CL0222-0901-0	100pcs per pack

Material / Finish

COMPONENT	MATERIAL	FINISH, REMARKS
Insulation Case	Polycarbonate Resin	Clear
Contact	Copper Alloy	Contact Gold Plating 1.27μm
Shield	Copper Alloy	Nickel Plating
Guide Plate	Polyamide Resin	Clear

COMPONENT	MATERIAL	FINISH, REMARKS
Cover	Polyamide Resin	Black

Tool

Part No.	HRS No.	Purchase Unit
HT502/TM61P-88P	CL0902-2231-0	1pc