 


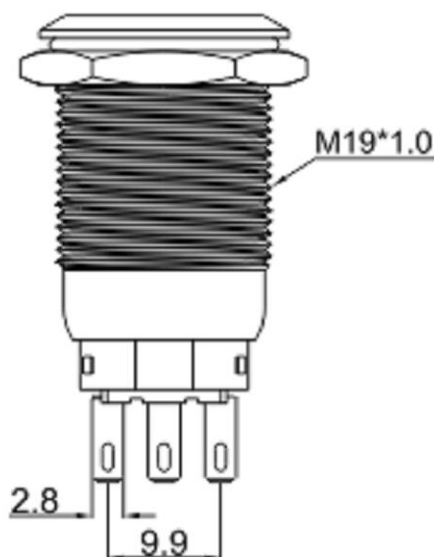
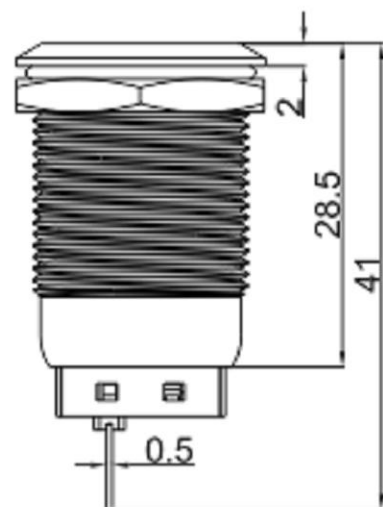



ROHS

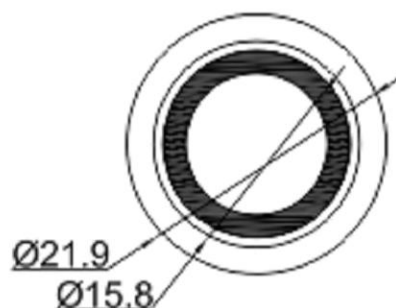

Panel Thickness: 10mm MAX.

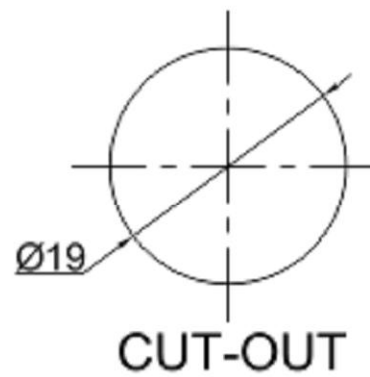

Product specifications:
 Rating: 5A 250VAC;; 2A 36VDC;
 Contact Resistance: 50mQ Max;
 Dielectric Strength: 1500VAC For 1 minute;
 Total Travel: 1.5±0.5mm
 Operating Force: 600±200gf
 Mechanical Life: 20000 Cycles;
 Load Life: 50000 cycles;
 Openrating Temperature: -20 °C~70 °C
 Function:OFF-(ON) ON-OFF

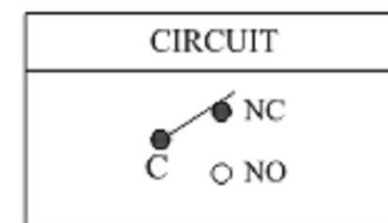

MATERIAL:

Actuator: SUS ;
 Top Base: SUS;
 Buttom Base:PA66+GF ;
 Terminal: Brass,Silver plated ;
 Nut: Brass, Ni plated .


The material contained in this drawing is the property of XiBang. Any use other than that specifcally authorized by XiBang i5 prohibited. The above drawing IS subjected to change for improvement without prior notice.



东莞市溪榜电子有限公司
 DONG GUAN XI BANG ELECTRONICS CO.,LTD

TITLE : METAL PUHS BUTTON SWITCH

 MODEL : XB-PBM19-13Z-F-NNN-S0-S



TOLERANCE
 ≤1.5mm±0.1
 > 1.5mm±0.2
 >=10mm±0.3

ANGLE
 ±2°

UNIT : MM	DWN.	ZENQ. CHEN	DATE	
SCALE : 3 : 1	CHK'D	PENG. GAO	DATE	
VBRSION	01	APPD.	FEI. LONG. HE	DATE

7	SPRING	STEEL WIRE	1	NATURE
6	STEEL BALL	STEEL	1	NATURE
5	BOARD	PHENOLIC RESIN	1	NATURE
4	CONTACT CLIP	PBS STRIP	2	Ag PLATED
3	FRAME	IRON STRIP	1	Ni PLATED
2	TERMINAL	BRASS STRIP	8	Ag PLATED
1	KNOB	POM	1	BLACK
NO.	PART NAME	MATERIAL	QTY.	FINISHING