

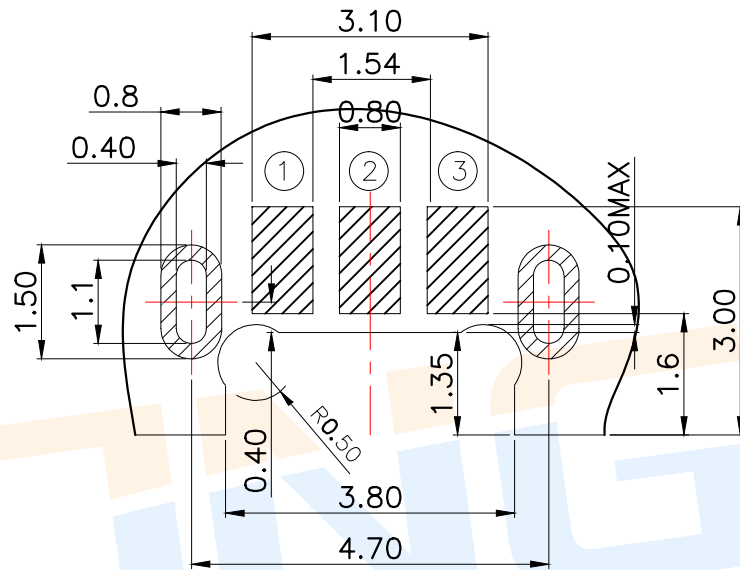
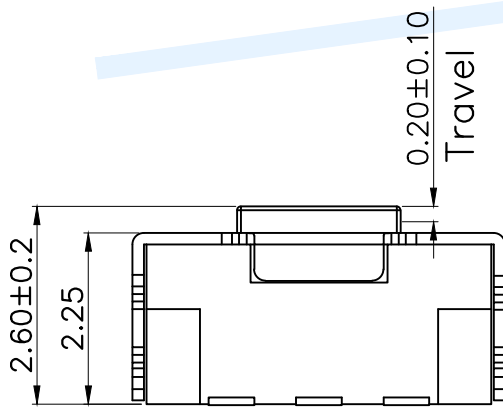
 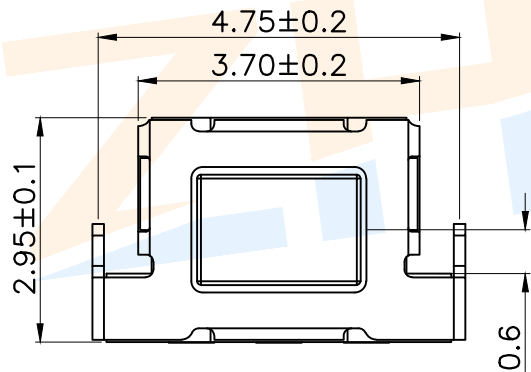
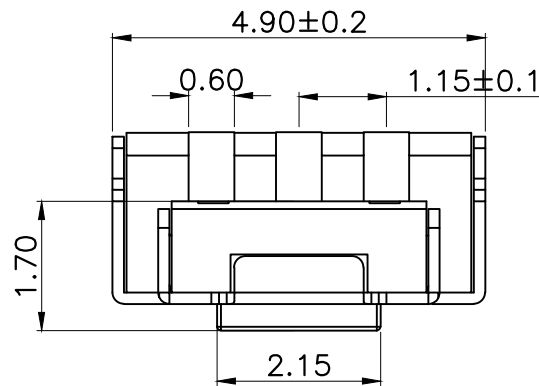



RoHS



PCB Layout(Pattern side)

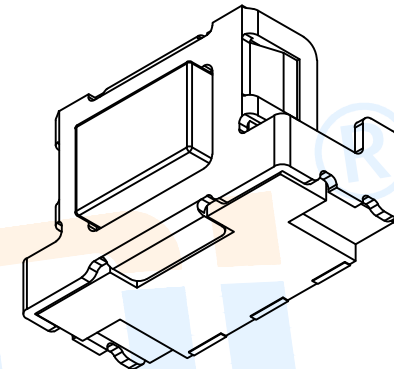

Circuit Diagram

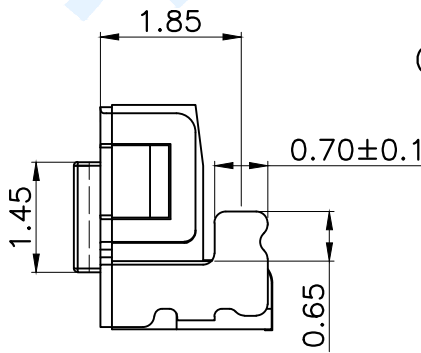

Product No. : TS-061D-□□□

型号:

: 包装方式

-P=编带(非编带, 不启用)

: 弹片

D2=SUS/1PCS

D4=SUS/2PCS

操作力度:

180=180gf±50gf

250=250gf±50gf

Ⓕ	Dust film		1	Polyimide tape	
Ⓖ	Terminal		3	Phosphorus bronze	Silvering
Ⓓ	Reed		2	SUS	Silvering
Ⓒ	Base		1	LCP	Black
Ⓑ	Cover		1	Phosphorus bronze	Silvering
Ⓐ	Button		1	LCP	Black
NO.	Name	Number	Qty	Materil	Remarks

ZHONGDI® Zhongdi Electronic Technology Co., Ltd

design	date	name	TACT SWITCHS
Review	date	model	TS-061D-□□D□
Approved	date		

Drawing number:

Proportion 1:1 unit mm gage number A4

modify Review Approved

angle	±2°
10~30	±0.30
5~10	±0.20
~ 5	±0.10

Tolerance not specified

项 目 Item	技术参数 Technical Parameter	标 准 Standard
电气性能 Electrical Properties	额定电流 Rated Current:	50mA
	额定电压 Rated voltage:	DC 12V
	接触电阻 Contact resistance:	≤100mΩ
	绝缘电阻 Insulation Resistance:	DC 250V 1 min ≥100MΩ
	耐压强度 Compressive strength:	AC 250V 50Hz/1 min
机械 性能 Mechanical Properties	机械寿命 Mechanical life:	100,000 cycles Min
	操作行程 Operation Stroke:	0.20mm±0.10mm
环境性能 Environmental	工作温度 Operation temperature:	-25℃~ +75℃
	使用湿度 Use humidity:	≤85% RH
可靠性特性 Reliability Characteristics	回流焊 Reflow Soldering:	≤260℃ 时间 Time 3s
	波峰焊 Wave soldering:	
	手工焊 Manual welding:	≥260℃ 时间 Time 3s
应用领域 Application area	影音产品、电子玩具、数码产品、通讯产品、安防产品等. Audiovisual products, electronic toys, digital products, communication products, security products, etc	



绝缘电阻测量仪




直流低电阻测试仪




耐电压测试仪



回流焊机

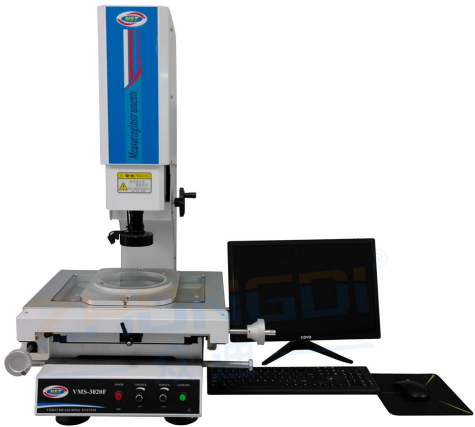

二次元测量仪

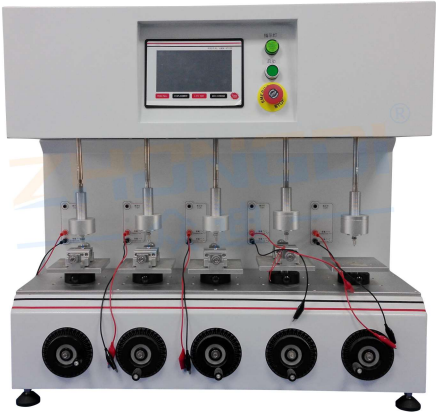

高精密寿命测试仪



盐雾测试仪



按键荷重曲线仪

ZHONGDI® 众迪										Zhongdi Electronic Technology Co., Ltd									
design			date			name			TACT SWITCHS										
Review			date																
Approved			date			model			TS-061D-□D□										
umber:																			
1:1		unit		mm		gape number								A4					