


	1	2	3	4	5	6	7	8																																														
A	RoHS REACH						版次	内 容	日期	负责人																																												
	A/0	新设计																																																				
B	<table border="1" style="margin-left: 10px; border-collapse: collapse;"> <tr><td>>15.0</td><td>ø3.0</td></tr> <tr><td>15.0</td><td>ø3.0</td></tr> <tr><td>14.0</td><td>ø3.0</td></tr> <tr><td>13.0</td><td>ø3.0</td></tr> <tr><td>12.5</td><td>ø3.0</td></tr> <tr><td>12.0</td><td>ø3.0</td></tr> <tr><td>11.5</td><td>ø3.0</td></tr> <tr><td>11.0</td><td>ø3.0</td></tr> <tr><td>10.5</td><td>ø3.0</td></tr> <tr><td>10.0</td><td>ø3.2</td></tr> <tr><td>9.5</td><td>ø3.2</td></tr> <tr><td>9.0</td><td>ø3.2</td></tr> <tr><td>8.5</td><td>ø3.3</td></tr> <tr><td>8.0</td><td>ø3.3</td></tr> <tr><td>7.5</td><td>ø3.3</td></tr> <tr><td>7.0</td><td>ø3.3</td></tr> <tr><td>6.5</td><td>ø3.3</td></tr> <tr><td>6.0</td><td>ø3.3</td></tr> <tr><td>5.5</td><td>ø3.3</td></tr> <tr><td>5.0</td><td>ø3.5</td></tr> <tr><td>4.3</td><td>ø3.5</td></tr> <tr><td>帽头H</td><td>直径A mm (mm)</td></tr> </table>		>15.0	ø3.0	15.0	ø3.0	14.0	ø3.0	13.0	ø3.0	12.5	ø3.0	12.0	ø3.0	11.5	ø3.0	11.0	ø3.0	10.5	ø3.0	10.0	ø3.2	9.5	ø3.2	9.0	ø3.2	8.5	ø3.3	8.0	ø3.3	7.5	ø3.3	7.0	ø3.3	6.5	ø3.3	6.0	ø3.3	5.5	ø3.3	5.0	ø3.5	4.3	ø3.5	帽头H	直径A mm (mm)								
>15.0	ø3.0																																																					
15.0	ø3.0																																																					
14.0	ø3.0																																																					
13.0	ø3.0																																																					
12.5	ø3.0																																																					
12.0	ø3.0																																																					
11.5	ø3.0																																																					
11.0	ø3.0																																																					
10.5	ø3.0																																																					
10.0	ø3.2																																																					
9.5	ø3.2																																																					
9.0	ø3.2																																																					
8.5	ø3.3																																																					
8.0	ø3.3																																																					
7.5	ø3.3																																																					
7.0	ø3.3																																																					
6.5	ø3.3																																																					
6.0	ø3.3																																																					
5.5	ø3.3																																																					
5.0	ø3.5																																																					
4.3	ø3.5																																																					
帽头H	直径A mm (mm)																																																					
C																																																						
D																																																						
E																																																						
F																																																						
G	<p>技术参数:</p> <ol style="list-style-type: none"> 使用温度: -25~+85°C; 额定负荷: DC 12V 50mA; 接触电阻: ≤50mΩ; 绝缘电阻: ≥100MΩ; 耐压: AC250V(50Hz)/min; 动作力: 230g±50g; 使用寿命: 100000次; 未注尺寸公差参照下面表格。 							<p>PCB线路板安装图(±0.1)</p> <p>电路图</p>																																														
H																																																						
	1	2	3	4	5	6	7	8																																														
未注尺寸公差(mm)						设计		产品名称: 轻触开关																																														
		图面	44	审核	标准化					批准																																												
单位	mm																																																					
比例	1:1																																																					
重量																																																						
页码	1/1																																																					
版次	A/0																																																					
产品料号: TC-06B-27-5H																																																						
产品规格: 贴片反折脚宽10.3																																																						
深圳市富港科技有限公司																																																						

标记	版本	更正记录	修订人	审核
△				
△				
△				

卷裝示圖仅供參考

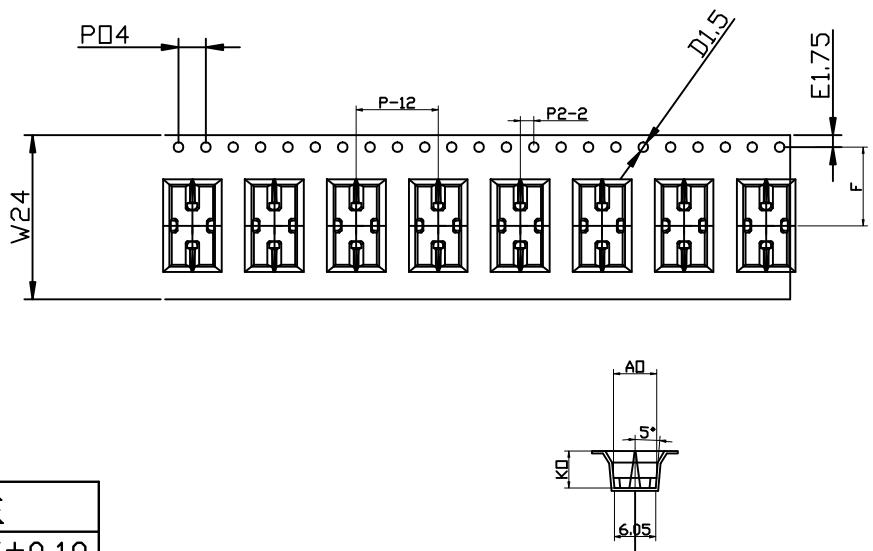

尺寸栏


尺寸栏	
E	1.75±0.10
F	11.5±0.10
P2	2.00±0.10
ØD	1.50± _{0.00} ^{0.10}
Po	4.00±0.10
W	24.00±0.30
P	12.0±0.10
Ao	6.30±0.10
B0	11.4±0.10
K0	5.45±0.10
t	0.40±0.05

生产参数

模 数	130 模
颗 数	1040 颗
卷 轮	330mm
包装数	1000 颗

说明

 1. 10个边孔的累计公差不能超过 $\pm 0.2\text{mm}$ 。
 2. 材料规格: PS 白色料抗静电, 厚度 0.40mm。
 - 3.13 英吋卷轮卷装长度: 12.48米, 包装零件
总颗数: 1040颗, 每盘实包颗数: 1000颗
 4. 所有尺寸设计参照EIA-481-C-2003。
 5. 载带在250mm长度内最大弯曲不能超过1mm 见
上图



	模具编号: 6X6
审核	客户编号: 6X6
	客户:
日期: 2021年10月30日	页数: 1 /1

