

Technical Data
Material:
Contact material:Brass
Plating:Gold Flash
Insulator material:Black polyester UL94V-0
Standard:PA6T+30%G.F

Electrical:
Current rating:1.5Amps/contact max.
Contact resistance: $\leq 20\text{m}\Omega$ /contact
Insulation resistance: $\geq 1000\text{M}\Omega$ at V=100V
Withstanding voltage:450V AC/minute



Mechanical:
Soldering temperature:+260℃, 4s max

UNSPECIFIED TOLERANCE: ± 0.20



A=2.0* n P+0.50 $\pm$ 0.50
B=2.0* n P-2.0 $\pm$ 0.20

Pin Number=1~40

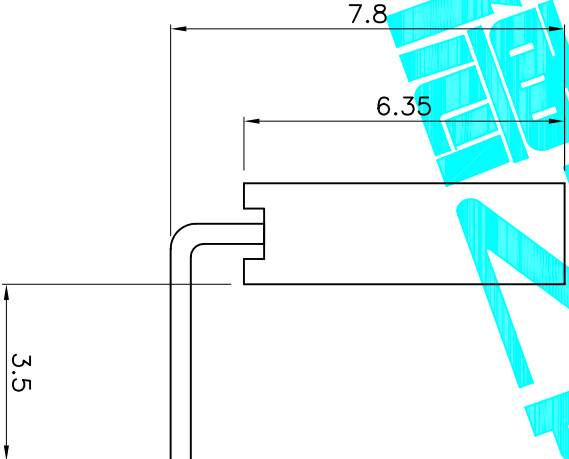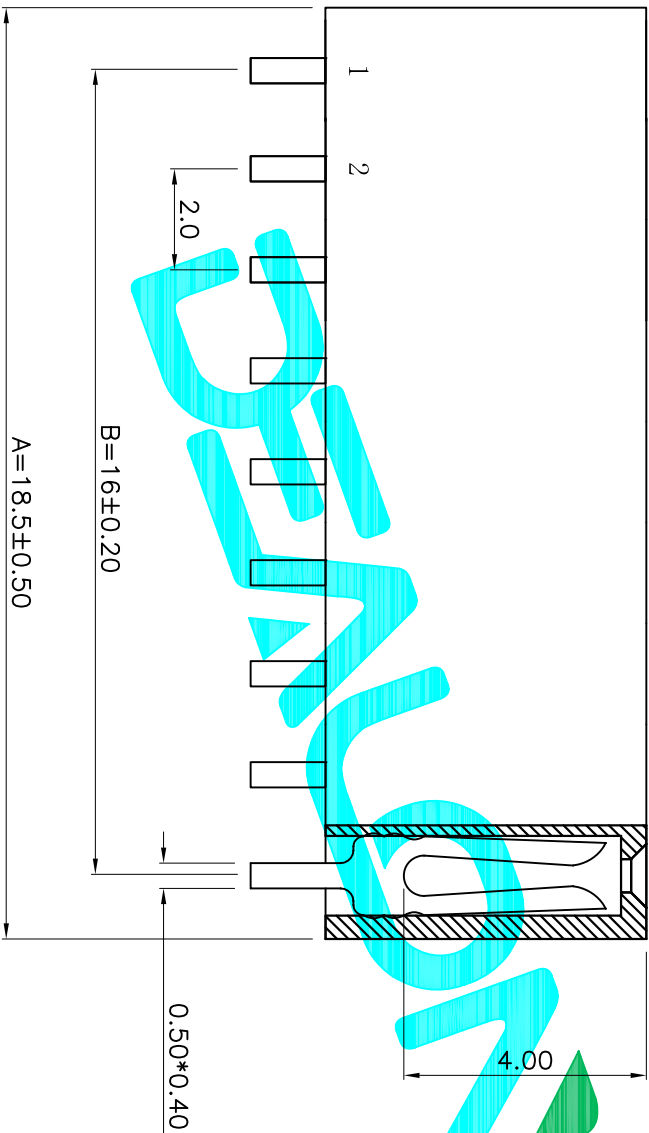

APPROVALS				DATE	DEALON 德之隆® ELECTRONICS CO.,LTD			
DRAWN	G.M.Chen	2015/5/22	TITLE:		2.00mm Female Header Connectors			
CHECKED			PART NO.		DW200W-11-XX-63			
APPROVALS			UNIT: mm		SCALE: 1:1		SHEET 1 OF 1	
TOLERANCES ARE			30 $\sim$ 0.1 $\pm$ 10 $\sim$ 0.05 5 $\sim$ 0.03	$\pm$ 0.30 $\pm$ 0.20 $\pm$ 0.15	ANGLE	$\pm$ 2°	PROJ.	
ECN NO.	REV.	DATE.	DESCRIPTION.		CHANGE.	CHECK.	APPRO.	
	A		NEW					