
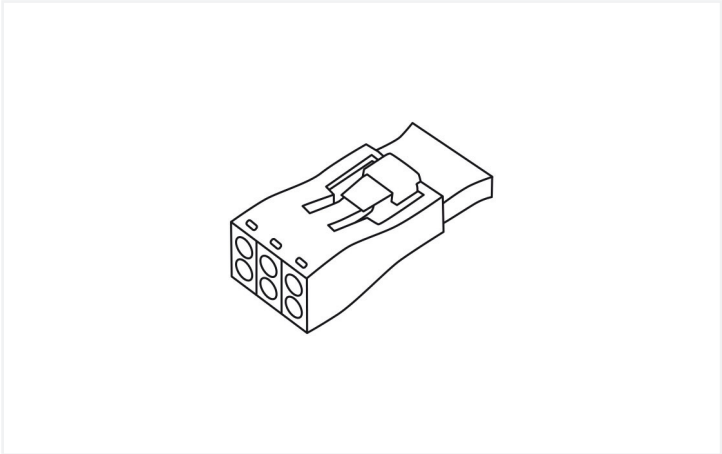


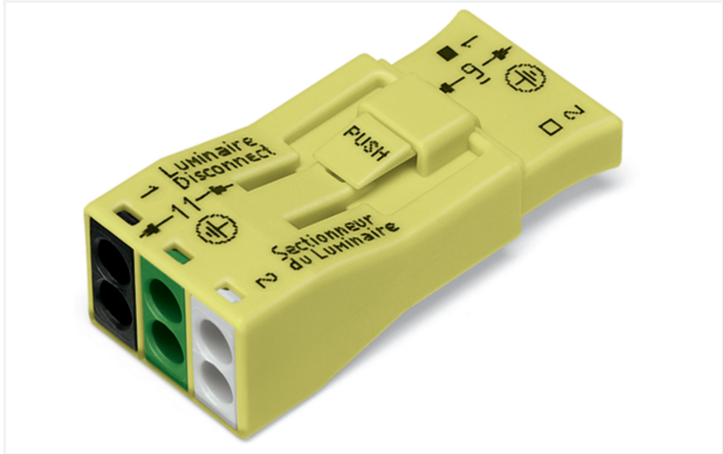

颜色: ■ 黄色

Luminaire disconnect connector, 873 Series, PUSH WIRE®

This luminaire disconnect connector (item number 873-953) provides hassle-free electrical installations. Conductors can only be connected to this luminaire disconnect connector if their strip length is between 11 and 13 mm. This product incorporates conductor terminals and utilizes PUSH WIRE®. Our tried-and-tested PUSH WIRE® connection offers the fastest method for clamping conductors. It utilizes the conductor's stiffness to overcome the clamping spring's contact force. The dimensions are (19 x 13.2 x 42) mm (width x height x depth).

注意：

说明

Touch-proof connectors are required for the ballast supply cables in fluorescent lighting fixtures in the USA and Canada. When replacing the ballast, the touch-proof connector is disconnected, the ballast is replaced, and the connection to the power supply is restored by reconnecting the connector. Reconnection streamlines ballast replacement while enhancing safety by safeguarding the installer from electric shock. The 873 Series Luminaire Disconnect Connectors are approved according to UL 2459 and CSA 22.2 for this type of application.

电气参数						
额定电气参数依据的标准		EN 60998			额定电气参数依据的标准	
		III	III	II		
过电压类别		III	III	II	过电压类别	
污染等级		3	2	2	污染等级	
额定电压		-	-	400 V	额定电压	
额定浪涌电压		-	-	4 kV	额定浪涌电压	
额定电流		-	-	6 A	额定电流	
		-	-			

接线参数			
接点		9	连接1
电位总数		3	
			插头
			插线式弹簧接线单元(PUSH WIRE®)
			推入式
			铜
			16 ... 12 AWG
			16 ... 12 AWG



连接1	
剥线长度	11 ... 13 mm / 0.43 ... 0.51 inches
极数	3

连接2	
连接类型	插座
单股导线2	18 AWG
剥线长度2	9 ... 11 mm / 0.35 ... 0.43 inches

物理数据	
厚度	19 mm / 0.748 inches
高度	13.2 mm / 0.52 inches
深度	42 mm / 1.654 inches

机械参数	
标记	1 Ⓞ 2

材料参数	
说明(材料数据)	有关材料规范的信息请点击此处
颜色	黄色
火灾荷载	0.144 MJ
重量	6.9 g

商业数据	
Product Group	8 (Misc. Chassis Mount Blocks)
PU (SPU)	500 个
包装类型	袋
原产国	CN
GTIN	4050821857952
海关税号	85366990990

Product Classification	
UNSPSC	39121421
eCl@ss 10.0	27-44-03-14
eCl@ss 9.0	27-44-03-14
ETIM 9.0	EC002560
ETIM 8.0	EC000458
ECCN	NO US CLASSIFICATION

环保产品合规性	
RoHS Compliance Status	Compliant,No Exemption



认证/证书

般認證



认证	标准	证书名称
CCA DEKRA Certification B.V.	EN 61984	NTR NL-7390
CCA DEKRA Certification B.V.	EN 61984	2178521.01
CCA DEKRA Certification B.V.	EN 60998	71-114174
CCA DEKRA Certification B.V.	EN 60998	NTR NL-7391
CSA DEKRA Certification B.V.	C22.2 No. 182.3	1961671
UL UL International Germany GmbH	UL 2459	E313353

符合性宣告和製造商宣告

认证	标准	证书名称
EU-Declaration of Confor- mity WAGO GmbH & Co. KG	-	-
UK-Declaration of Confor- mity WAGO GmbH & Co. KG	-	-

下载

Environmental Product Compliance

Compliance Search
Environmental Product Compliance 873-953



文档

Bid Text			
873-953	21.02.2019	docx 15.01 KB	↓
873-953	19.02.2019	xml 3.17 KB	↓



CAD/CAE-Data

CAD data
2D/3D Models 873-953



CAE data
ZUKEN Portal 873-953

