
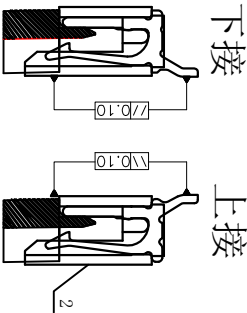


DIM B=[(n-1)x0.5+5±0.2

适用扁平电缆(Proper cable)

注：适用0.3mm厚扁平连接线，Pin位(N)：4-60。

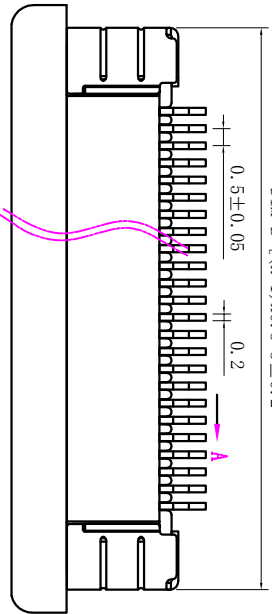

4	插针	n	C5191 t=0.20, 镀锡80u"min.
3	焊片	2	C2680 t=0.20 镀锡80u"min.(镍底15u"min.)
2	底座	1	LCF+35%GF 白色
1	锁条	1	PPS 黑色
项目	零件名称	数量	描述

技术要求:

1. 材料见右表。

2. 电气性能

2.1. 额定电流 1.0A

2.2. 额定电压 125V

2.3. 接触阻抗 20 mΩ MAX

2.4. 绝缘阻抗 100 MΩ MIN

2.5 耐电压 500V AC

3. 机械性能

3.1. 耐久性 30 次

3.2. 工作温度 -25~+75℃

3.3. 插入力(N*1.5)N MAX, 拔出力(N*0.5)N MIN。

产品名称:
FPC连接器

0.5A-NPBS

东莞市高钺达电子科技有限公司

X. ±0.25

X.° ±4°

产品型号: FPCXX-T1T1-2000-A

适用

单位: mm

.X ±0.20

.X° ±2°

设计

文件号

图样标记

.XX ±0.15

.XX°

审核

比例

版本

页次

一般尺寸


角度尺寸

批准

1:1

A

1/2

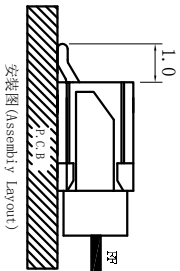

P数	DIM=A	DIM=B	DIM=C	DIM=D	P数	DIM=A	DIM=B	DIM=C	DIM=D
4	7.70	6.50	2.70	1.50	32	21.70	20.50	16.70	15.50
5	8.20	7.00	3.20	2.00	33	22.20	21.00	17.20	16.00
6	8.70	7.50	3.70	2.50	34	22.70	21.50	17.70	16.50
7	9.20	8.00	4.20	3.00	35	23.20	22.00	18.20	17.00
8	9.70	8.50	4.70	3.50	36	23.70	22.50	18.70	17.50
9	10.20	9.00	5.20	4.00	37	24.20	23.00	19.20	18.00
10	10.70	9.50	5.70	4.50	38	24.70	23.50	19.70	18.50
11	11.20	10.00	6.20	5.00	39	25.20	24.00	20.20	19.00
12	11.70	10.50	6.70	5.50	40	25.70	24.50	20.70	19.50
13	12.20	11.00	7.20	6.00	41	26.20	25.00	21.20	20.00
14	12.70	11.50	7.70	6.50	42	26.70	25.50	21.70	20.50
15	13.20	12.00	8.20	7.00	43	27.20	26.00	22.20	21.00
16	13.70	12.50	8.70	7.50	44	27.70	26.50	22.70	21.50
17	14.20	13.00	9.20	8.00	45	28.20	27.00	23.20	22.00
18	14.70	13.50	9.70	8.50	46	28.70	27.50	23.70	22.50
19	15.20	14.00	10.20	9.00	47	29.20	28.00	24.20	23.00
20	15.70	14.50	10.70	9.50	48	29.70	28.50	24.70	23.50
21	16.20	15.00	11.20	10.00	49	30.20	29.00	25.20	24.00
22	16.70	15.50	11.70	10.50	50	30.70	29.50	25.70	24.50
23	17.20	16.00	12.20	11.00	51	31.20	30.00	26.20	25.00
24	17.70	16.50	12.70	11.50	52	31.70	30.50	26.70	25.50
25	18.20	17.00	13.20	12.00	53	32.20	31.00	27.20	26.00
26	18.70	17.50	13.70	12.50	54	32.70	31.50	27.70	26.50
27	19.20	18.00	14.20	13.00	55	33.20	32.00	28.20	27.00
28	19.70	18.50	14.70	13.50	56	33.70	33.00	28.70	27.50
29	20.20	19.00	15.20	14.00	57	34.20	33.00	29.20	28.00
30	20.70	19.50	15.70	14.50	58	34.70	33.50	29.70	28.50
31	21.20	20.00	16.20	15.00	59	35.20	34.00	30.20	29.00
32	21.70	20.50	16.70	15.50	60	35.70	34.50	30.70	29.50