



1. External Dimensions (Unit:m/m)

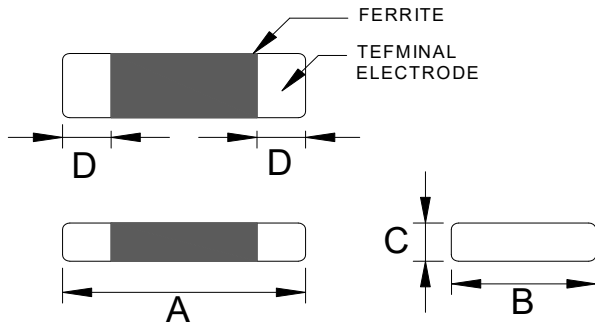

TYPE	METRIC	A	B	C	D	Q'Ty/Reel
FB3216	1206	3.2±0.2	1.6±0.2	1.1±0.2	0.5±0.3	3000

2. Construction

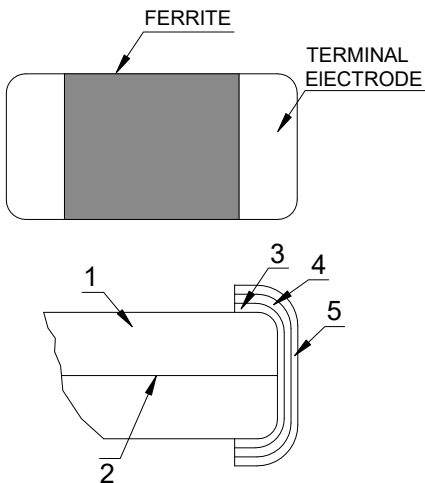

NO	PART	MATERIAL
1	Ferrite Body	Fe2O3
2	Silver electrode	Ag
3	Silver electrode	Ag
4	Plating	Ni
5	Plating	Sn

3. Part Number Code

FB 3216 T 102
 A B C D

A: Series Name Multilayer Ferrite Chip Beads
 B: Dimensions(mm) 3216: 3.2x1.6x1.1
 C: Tolerance T: ±25%
 D: Impedance 102=1000Ω

4. Electrical Characteristics

Part Number	Impedance (Ω±25%)	Test Freq. (MHz)	RDC (Ω)Max.	Rated Current (mA)Max.
FB3216T102	1000.0	100 MHz	0.3	1000.0

Curve:

