



ISO9001-2015
Certificate No:672022020207194

No.T52210311961TC Date;OCT 12,2022 No.T52310270397TC Date;apr 15,2023

承認書

SPECIFICATION FOR APPROVAL

客户名稱
CUSTOMER

品名規格
DESCRIPTION RH3.5x9.0x0.8

客户料號
CUS. P/N

提出日期
DATE 2025.05.12

出圖 RDAWING		
發行 MADE	復核 CHECKED	確認 APPROVED
李光赫	方煜镗	梁琼
销售部：张 丽		


承 認 CUSTOMER APPROVE



SPECIFICATION 產品規格書		DRAWING NO.:	
		RH3.5x9.0x0.8	
CUSTOMER			
CUSTOMER TYPE			
ITEM		RH3.5x9.0x0.8	
MATERIAL			
CUSTOMER P/N			
SCALE:	UNIT:	METHOD:	DATE:
NONE	mm.	第三角法	2025/05/12
DRAWN/DATE	CHECK/DATE	APPROVED/DATE	ISSUE NO
李光赫	方煜镗	梁琼	

1. DIMENSIONS:

ϕA	ϕC	D	W	L1	L2
3.50±0.15	0.80±0.15	9.00±0.30	0.55±0.02	28.0±0.2	28.0±0.2

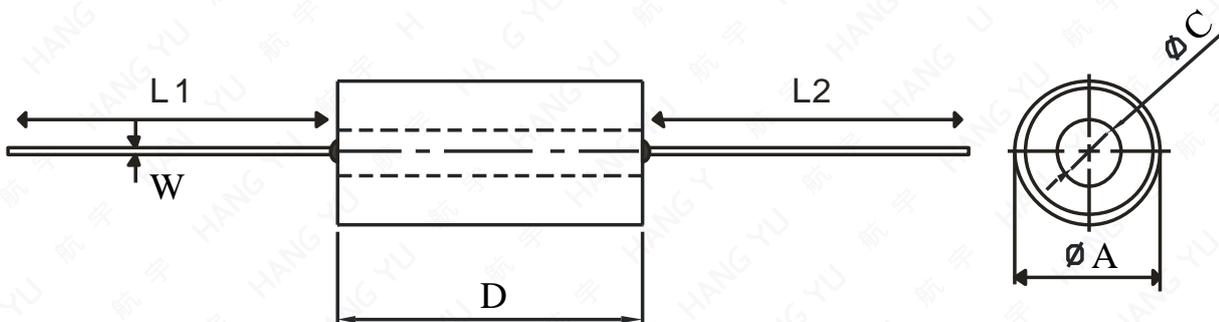

2. ELECTRONIC CHARACTERISTICS:

ITEM.	IMPEDANCE(Ω)	IMPEDANCE(Ω)
	25MHZ	100 MHZ
SPEC.	100MIN	135MIN

3.NOTES:

(1) WIRE & WINDING: ϕ 0.55-UEW 1/2TS.

(2) TEST FREQUENCY: 25MHZ/100MHZ.

(3) TEST METER: HP-4191A RF.


TEST DATA

ITEM.	ϕA	ϕC	D			
SPEC.	3.50±0.15	0.80±0.15	9.00±0.30			
01.	3.46	0.89	8.97			
02.	3.45	0.88	8.99			
03.	3.44	0.88	8.99			
04.	3.46	0.86	8.98			
05.	3.45	0.89	8.98			
ITEM.	IMPEDANC E(Ω)	IMPEDAN CE(Ω)				
	25MHZ	100MHZ				
SPEC.	100	135				
01.	105.23	141.23				
02.	104.74	139.74				
03.	105.47	140.47				
04.	104.98	140.98				
05.	105.64	141.64				

阻抗 - 頻率曲綫

IMPEDANCE V.S FREQUENCY (Z-Y)

客户名稱 CUSTOMER		日期 DATE	2025.05.12
規格 ITEM	RH3.5x9.0x0.8	編號 SERIAL NO.	

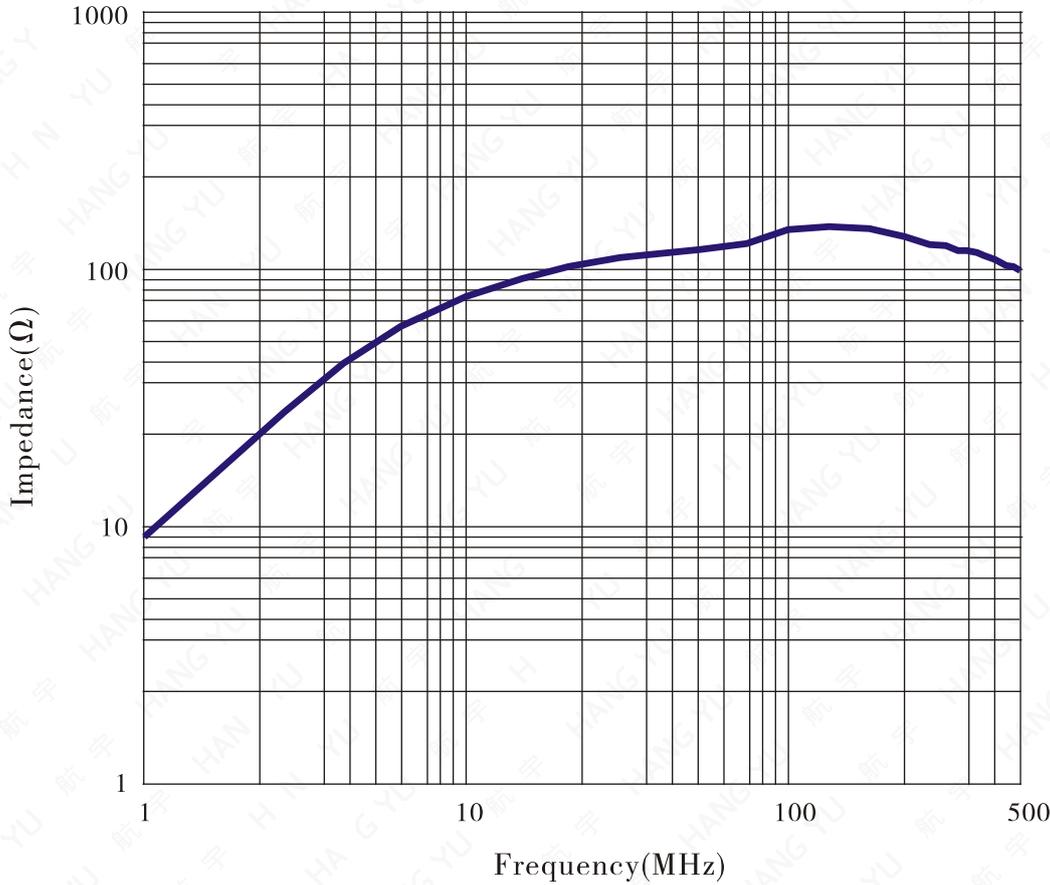

測試條件：
TESTING CONDITION:

1. 測試儀器: E4991A+16194A
Testing Equipment:
2. 測試頻率區間: 1-500MHz
Testing Frequency Range:
3. 測試綫組: $\Phi 0.5 \times 0.5 \text{TS} \times 100 \text{L}(\text{mm})$
Testing Coil Specification:

說明Note:

本承認書在客戶收到7天之內，須簽章返回，逾期視爲默認。

The Specification Approval is required to be sent back to the supplier with customer's chop or signature on it within 4 days after receiving it, or we will take it as approved by customer automatically.

測試 TESTED	復核 CHECKED	確認 APPROVED
李光赫	方煜鐳	梁琮