

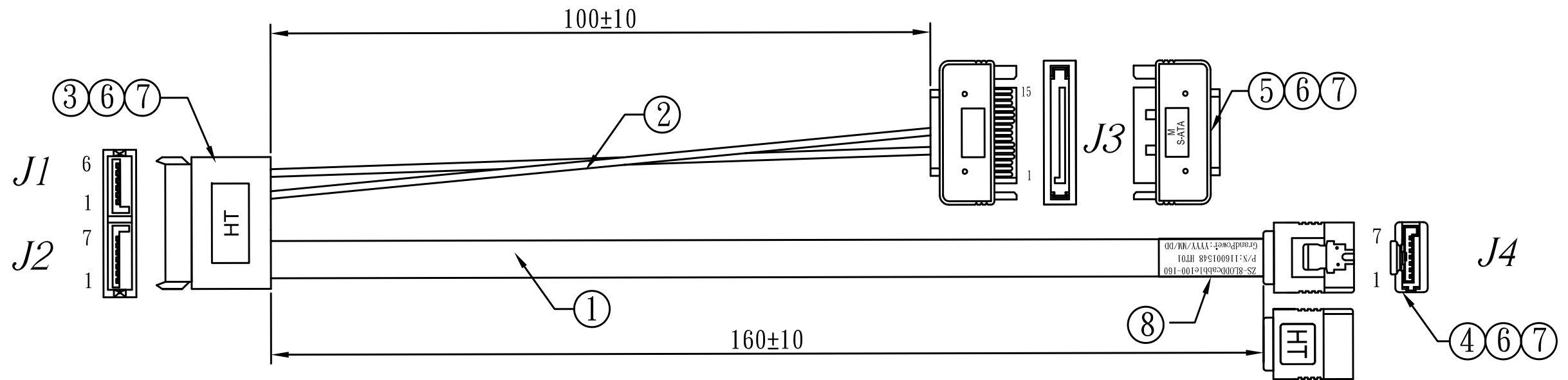
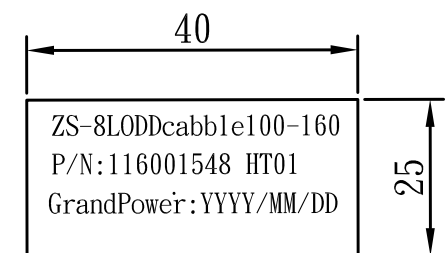


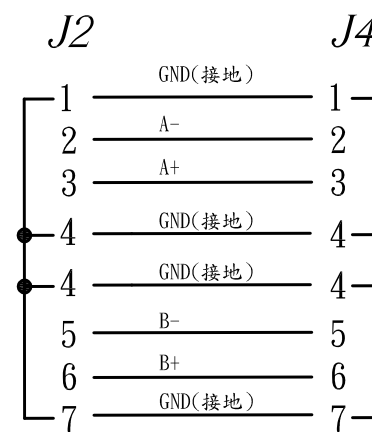

Contact Connection Table

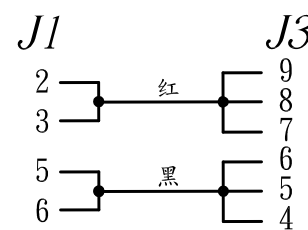

Notes:

All materials are RoHS compliant.

Testing Requirements

a. Continuity resistance: Max. 2Ω

b. Insulation resistance: 10MΩ

c. Voltage: 300V DC

Packaging: 10 PCS per bundle (packed in bubble bags), 750 PCS per carton.

Barcode Requirements:

Font: Arial

Character Height: Approx. 2 mm

Distance from Left Edge: 1.5–2 mm

Color Scheme: Black characters on white background

Date Marking: Use YYYY/MM/DD to indicate the production date (Year/Month/Day)

Part: SATA 7+6P/SATA 7P to SATA 15P Male Connector, Length (L) = 160mm

8	M1014030322001	Label: Black text on white background, L×W = 40mm × 25mm	1pcs	
7	EP02BK08B	45PPVC Overmolding Compound, Black (Environmentally Friendly Material)	10g	
6	EE00TR01B	General-Purpose PE Molding Compound (Environmentally Friendly Material)	5g	
5	BA15F009B	SATA 15P Male Connector, Gold-plated Copper Terminals (1μm), Crimp Type, LCP Black Plastic Core	1pcs	
4	BA07F006B	SATA 7P Female Connector, Crimp Type, with Shrapnel, Black PBT Plastic Core, Gold-plated Phosphor Bronze Terminals (1μm)	1pcs	
3	BA13F002B	SATA 7+6P (with Bevel) Female Connector, Crimp Type, Gold-plated Phosphor Bronze Terminals (1μm), LCP Black Plastic Core	1pcs	
2	A112201BK/RD0000000B	UL1007 22AWG OD:1.6 Black L=120mm*1;Red L=120mm*1	2pcs	
1	A022850BK0100000B	UL2725 [28AWG (1/0.32) × 2C + AL] × 2F + D (1/0.32) × 3, OD: 2.2×7.8 mm, Black Outer Jacket, Wire Marked with 26AWG (ROHS Material), (L) = 180 mm	1pcs	
No.	Material	Description	QTY	



贝迅泽技术（东莞）有限公司
BEIXUNZE TECHNOLOGY (DONGGUAN) CO., LTD

Tel:

www.hiemi.cn

PN:

HMPC-SATAG335

Drawn

CHC

Date

2024-11-19

A0

Check

LIKE

Date

2024-11-19

Approved

WSR

Date

2024-11-19