


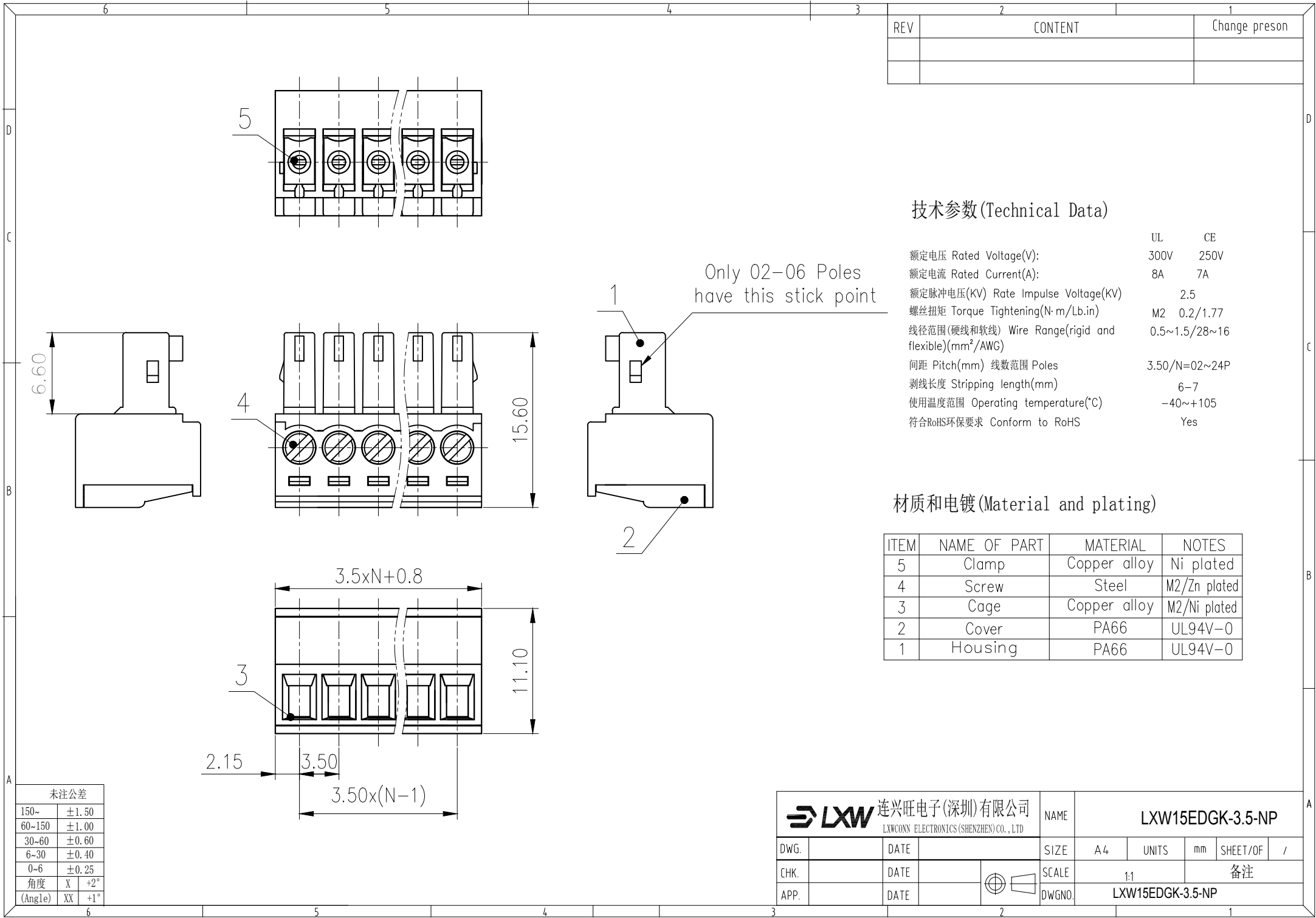

REV	CONTENT	Change preson

技术参数(Technical Data)

	UL	CE
额定电压 Rated Voltage(V):	300V	250V
额定电流 Rated Current(A):	8A	7A
额定脉冲电压(KV) Rate Impulse Voltage(KV)	2.5	
螺丝扭矩 Torque Tightening(N·m/Lb.in)	M2	0.2/1.77
线径范围(硬线和软线) Wire Range(rigid and flexible)(mm ² /AWG)	0.5~1.5/28~16	
间距 Pitch(mm) 线数范围 Poles	3.50/N=02~24P	
剥线长度 Stripping length(mm)	6~7	
使用温度范围 Operating temperature(°C)	-40~+105	
符合RoHS环保要求 Conform to RoHS	Yes	

材质和电镀(Material and plating)

ITEM	NAME OF PART	MATERIAL	NOTES
5	Clamp	Copper alloy	Ni plated
4	Screw	Steel	M2/Zn plated
3	Cage	Copper alloy	M2/Ni plated
2	Cover	PA66	UL94V-0
1	Housing	PA66	UL94V-0

未注公差	
150~	±1.50
60~150	±1.00
30~60	±0.60
6~30	±0.40
0~6	±0.25
角度	X +2°
(Angle)	XX +1°

 连兴旺电子(深圳)有限公司 LXWCONN ELECTRONICS(SHENZHEN)CO.,LTD				NAME	LXW15EDGK-3.5-NP					
DWG.		DATE			SIZE	A4	UNITS	mm	SHEET/OF	/
CHK.		DATE			SCALE	1:1		备注		
APP.		DATE			DWGNO.	LXW15EDGK-3.5-NP				