


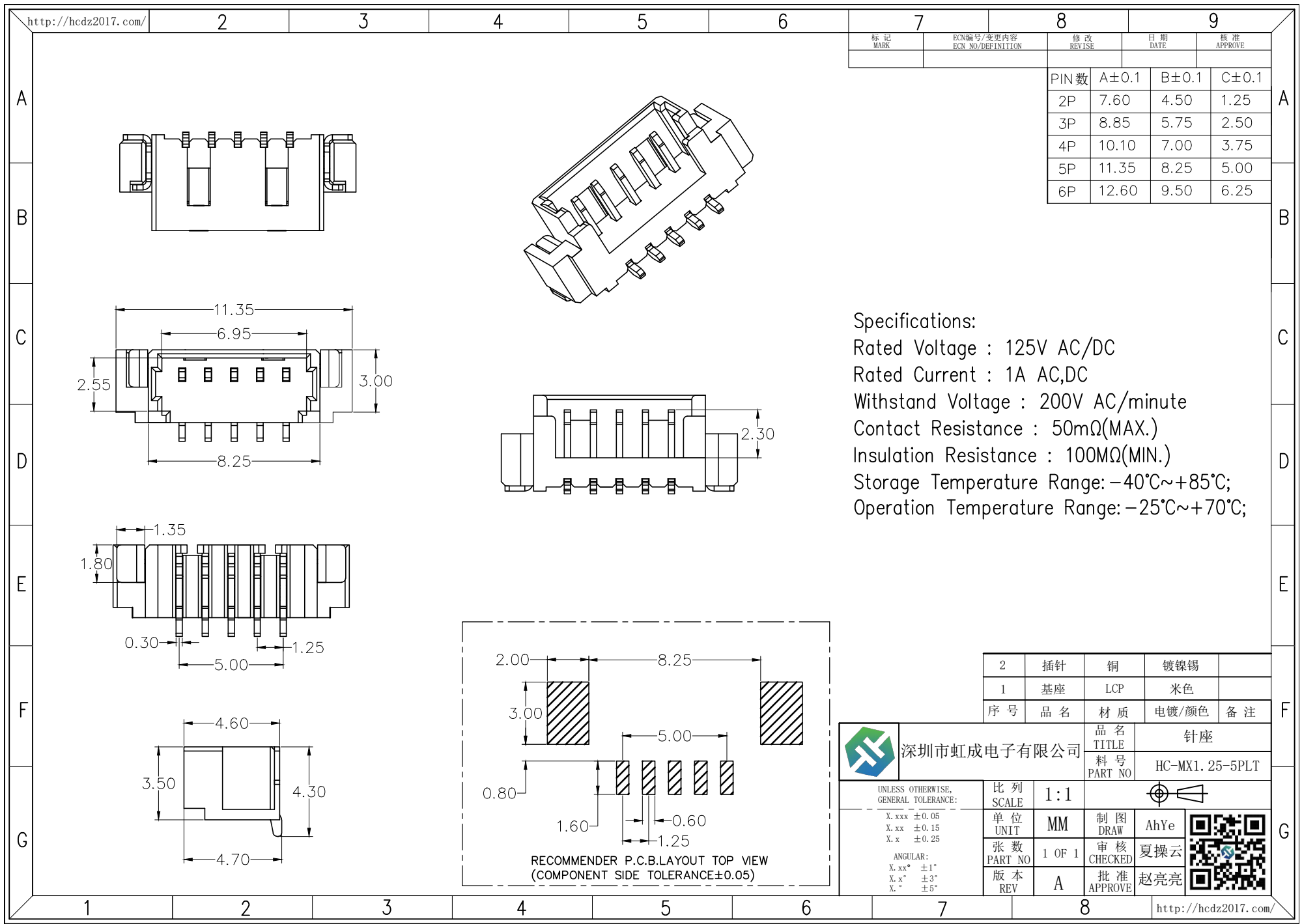

Specifications:
Rated Voltage : 125V AC/DC
Rated Current : 1A AC,DC
Withstand Voltage : 200V AC/minute
Contact Resistance : 50mΩ(MAX.)
Insulation Resistance : 100MΩ(MIN.)
Storage Temperature Range: -40°C~+85°C;
Operation Temperature Range: -25°C~+70°C;

2	插针	铜	镀镍锡	
1	基座	LCP	米色	
序号	品名	材质	电镀/颜色	备注
	品名 TITLE	针座		
	料号 PART NO	HC-MX1. 25-5PLT		
UNLESS OTHERWISE, GENERAL TOLERANCE:		比列 SCALE	1:1	
X. xxx ±0.05 X. xx ±0.15 X. x ±0.25		单位 UNIT	MM	制图 DRAW
ANGULAR: X. xx° ±1° X. x° ±3° X. ° ±5°		张数 PART NO	1 OF 1	审核 CHECKED
		版本 REV	A	批准 APPROVE
				夏操云 赵亮亮

