
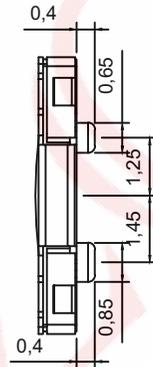
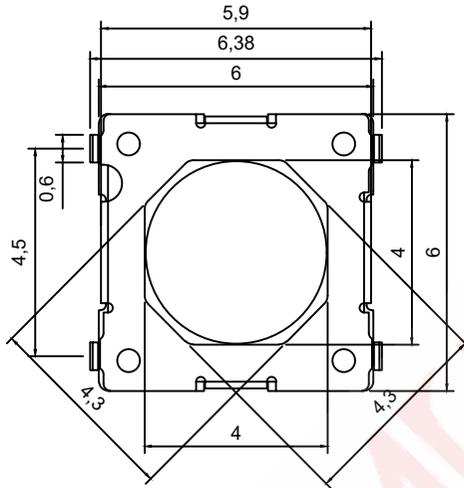


1 2
SAMZO REAC/ROHS

REV	ECN NO	DESCRIPTION	DESIGN	APPROVAL	DATE
A1	NEW	Replace frame			2018.06.12

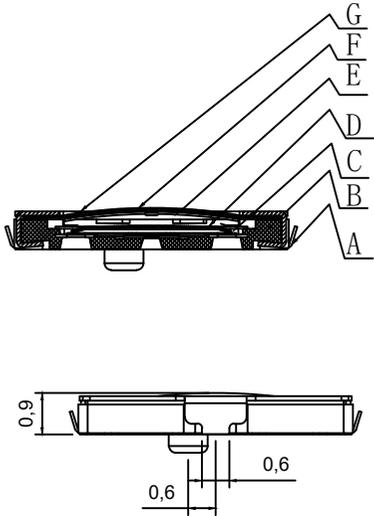



主要技术参数、性能
The Main Thchnology Performance

额定电流、电压 Rate voltage, current	50mA DC12V
接触电阻 Contact resistance	≤100mΩ
按力 Operating force	1-80±30 2-250±50
行程 Travel	1-0.25±0.1 2-0.40±0.1
绝缘电阻 Insulated resistance	≥100MΩ
介电强度 Dielectric strength	≥250VAC/1min

JT 4 E 90 1 1 2 0

A B C D E F G H

- A. 系列: JT-6*6两档开关系列
- B. 贴装方式: 4-180° SMT
- C. 引脚规格: 4-Pin
- D. 操作高度: 90-0.9mm
- E. 操作力度: 1-80/250gf
- F. 操作寿命: 1-30万次
- G. 固定方式: 2-带柱
- H. 物料编码: 0-常规

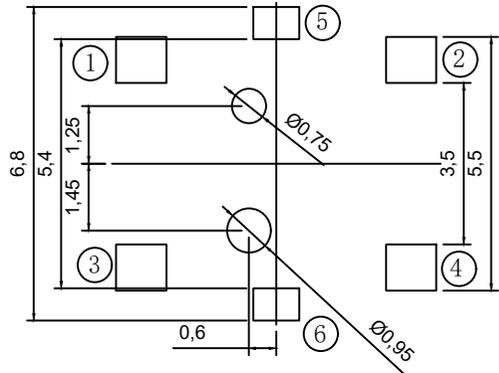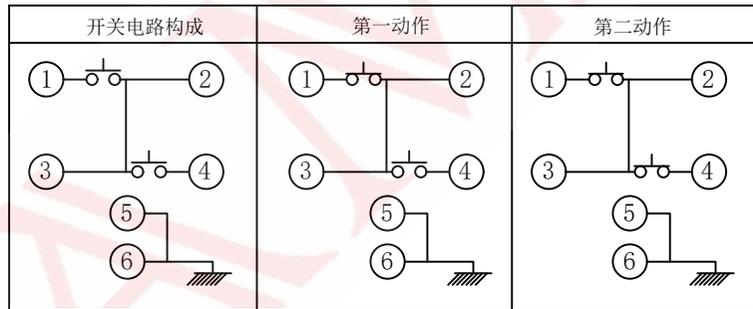

P. C. B. SOLDER LAND DIMENSION

A	ITEM	DESCRIPTION	MATERIAL	QTY	FINSH/COLOR	FIRST VIEW				The copyright belongs to samzo parts [China] Co., Ltd. please use the material after samzo parts agree to authorize. The final right of interpretation belongs to samzo parts. WWW.KKK-JP.COM	TITLE::		
	F	外膜	铁氟龙		白色						6*6两档直立式翘脚贴片开关		
	E	盖板	不锈钢	1	镀镍						GENERAL TOLERANCE		
	D	防尘防水膜	铁氟龙		黑色	≥0~2<	±0.15	SCALE	1:1		UNIT	mm	PART NO: JT4E90-0003
	C	弹片	不锈钢	2	镀银	DESIGN	WANGGUIFA	2018.06.12	≥2~5<		±0.25	MODEL NO: JT4E901120	
	B	本件	LCP	1	白色	CHECKED	ZHENGUILAN	2018.06.12	≥0~2<		±0.15	NAME: TACT SWITCH	
A	卡件	磷铜	1	镀银	APPROVED	LILIANJIANG	2018.06.14	≥5	±0.35	Electronic switch and connector manufacturer			