
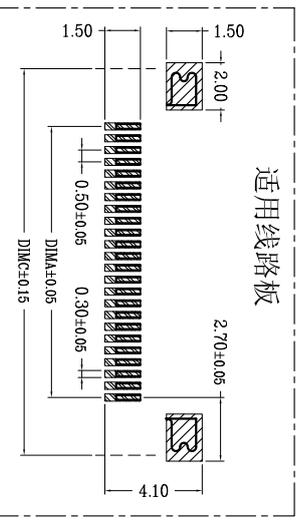
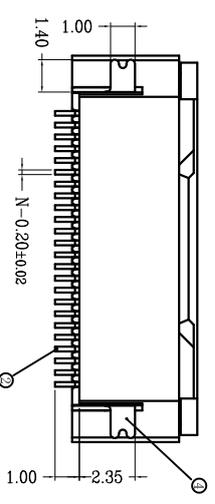
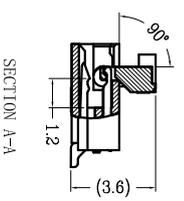
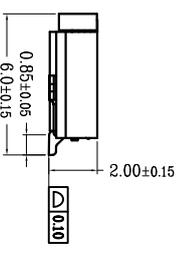
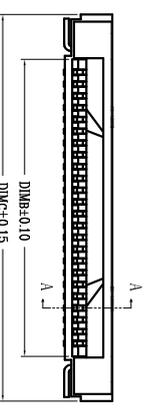
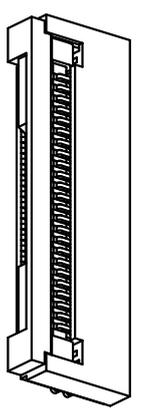
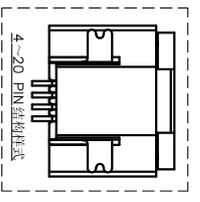


| REV. | ECN. NO. | APPD. |
|------|---------------------|----------------|
| A | | |
| 序号 | 品名 | 材质 |
| ① | 0.5mm 盖板芯 (H2.0) | LCP UL94V-0 本色 |
| ② | 0.5mm 盖端子 (H2.0) | 磷青铜/表面镀锡 |
| ③ | 0.5mm 盖后盖 (H2.0) | LCP UL94V-0 黑色 |
| ④ | 0.5mm 盖垫片 (H2.0) | 黄铜/表面镀锡 |

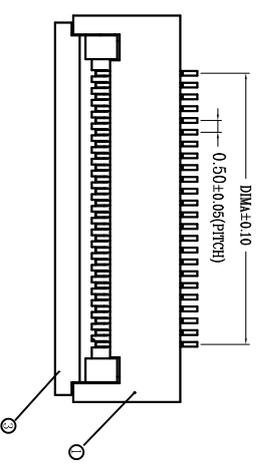

| CKT | DIMA | DIMB | DIMC | CKT | DIMA | DIMB | DIMC |
|-----|-------|-------|-------|-----|-------|-------|-------|
| 4 | 1.50 | 2.60 | 6.40 | 33 | 16.00 | 17.10 | 20.90 |
| 5 | 2.00 | 3.10 | 6.90 | 34 | 16.50 | 17.60 | 21.40 |
| 6 | 2.50 | 3.60 | 7.40 | 35 | 17.00 | 18.10 | 21.90 |
| 7 | 3.00 | 4.10 | 7.90 | 36 | 17.50 | 18.60 | 22.40 |
| 8 | 3.50 | 4.60 | 8.40 | 37 | 18.00 | 19.10 | 22.90 |
| 9 | 4.00 | 5.10 | 8.90 | 38 | 18.50 | 19.60 | 23.40 |
| 10 | 4.50 | 5.60 | 9.40 | 39 | 19.00 | 20.10 | 23.90 |
| 11 | 5.00 | 6.10 | 9.90 | 40 | 19.50 | 20.60 | 24.40 |
| 12 | 5.50 | 6.60 | 10.40 | 41 | 20.00 | 21.10 | 24.90 |
| 13 | 6.00 | 7.10 | 10.90 | 42 | 20.50 | 21.60 | 25.40 |
| 14 | 6.50 | 7.60 | 11.40 | 43 | 21.00 | 22.10 | 25.90 |
| 15 | 7.00 | 8.10 | 11.90 | 44 | 21.50 | 22.60 | 26.40 |
| 16 | 7.50 | 8.60 | 12.40 | 45 | 22.00 | 23.10 | 26.90 |
| 17 | 8.00 | 9.10 | 12.90 | 46 | 22.50 | 23.60 | 27.40 |
| 18 | 8.50 | 9.60 | 13.40 | 47 | 23.00 | 24.10 | 27.90 |
| 19 | 9.00 | 10.10 | 13.90 | 48 | 23.50 | 24.60 | 28.40 |
| 20 | 9.50 | 10.60 | 14.40 | 49 | 24.00 | 25.10 | 28.90 |
| 21 | 10.00 | 11.10 | 14.90 | 50 | 24.50 | 25.60 | 29.40 |
| 22 | 10.50 | 11.60 | 15.40 | 51 | 25.00 | 26.10 | 29.90 |
| 23 | 11.00 | 12.10 | 15.90 | 52 | 25.50 | 26.60 | 30.40 |
| 24 | 11.50 | 12.60 | 16.40 | 53 | 26.00 | 27.10 | 30.90 |
| 25 | 12.00 | 13.10 | 16.90 | 54 | 26.50 | 27.60 | 31.40 |
| 26 | 12.50 | 13.60 | 17.40 | 55 | 27.00 | 28.10 | 31.90 |
| 27 | 13.00 | 14.10 | 17.90 | 56 | 27.50 | 28.60 | 32.40 |
| 28 | 13.50 | 14.60 | 18.40 | 57 | 28.00 | 29.10 | 32.90 |
| 29 | 14.00 | 15.10 | 18.90 | 58 | 28.50 | 29.60 | 33.40 |
| 30 | 14.50 | 15.60 | 19.40 | 59 | 29.00 | 30.10 | 33.90 |
| 31 | 15.00 | 16.10 | 19.90 | 60 | 29.50 | 30.60 | 34.40 |
| 32 | 15.50 | 16.60 | 20.40 | | | | |

技术指标:

1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
2. 温度范围: -25°C ~ 85°C。
3. 额定电压: 50V, AC/DC(等效)。
4. 接触电阻: ≤0.03Ω。
5. 绝缘电阻: ≥500MΩ。
6. 产品料号:

XW05200—XX X X

NO OF CKT (产品PIN数)


Plating (电镀方式)

- 0: 端子全雾锡
- 1: 端子全金 (G/F OVERALL)
- 2: 端子半金锡

Packing (包装方式)

- T: TUBE管装
- R: TAPE & REEL卷装

适用扁平线

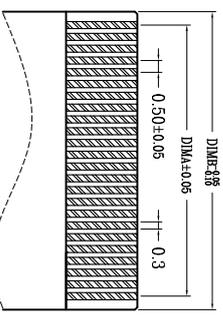

| X. | ± 0.30 | X° | ± 5° | UNITS | mm |
|-------------|--------|--------------|------|--------|----|
| X | ± 0.20 | X° | ± 2° | MATL | |
| .XX | ± 0.10 | .XX° | ± 1° | FINISH | |
| .XXX ± 0.05 | | .XXX° ± 0.5° | | | |

| NAME (INTENDED USE) | | PART NO. (INTENDED USE) | |
|---------------------|-----|-------------------------|-----------|
| FPC CONNECTOR | QTY | APPD: | SUNNY |
| | | CHKD: | LISA |
| | | DR: | ZOE |
| | | | 2015-1-28 |

| TITLE: | | DWG NO.: | |
|-----------------------|--|--------------|-------|
| MINTRON CO., LTD. | | XW05200-XXXX | |
| FPC0.5 掀盖卧式下接 (H=2.0) | | SCALE | SHEET |
| | | 1/1 | 1/1 |
| | | REV. | A |