


RS PRO Cat5e RJ45 Feedthrough Connector, 2 Port, FTP

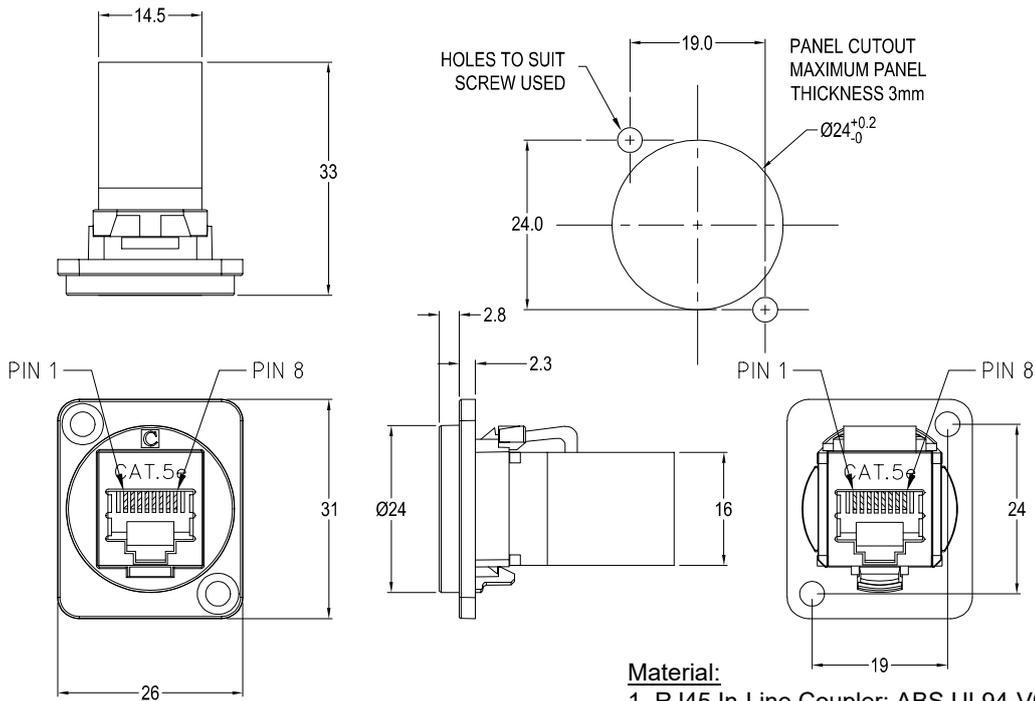

Feedthrough Features

- Fits standard XLR Ø24mm cutout.
- No soldering or punch termination. Use standard cable for each connector style.
- Front or rear mounted.
- Low rear profile

General:

Please note: Functionality is affected by cable quality, length and cable wiring configuration.

Other models available:
RS stock No.

- | | |
|----------|--|
| 874-1217 | Cat5e RJ45 Shielded Black plastic frame, CSK holes |
| 907-5656 | Cat5e RJ45 Shielded Nickel plated metal frame, CSK holes |
| 203-5595 | Cat5e RJ45 Shielded Nickel plated metal frame, M3 holes |
| 916-0252 | Cat5e RJ45 Shielded Black metal frame, CSK holes |
| 203-5596 | Cat5e RJ45 Shielded Black metal frame, M3 holes |
| 874-1260 | Cat5e RJ45 Shielded Black plastic frame, PLAIN holes |

Material:

1. RJ45 In-Line Coupler: ABS UL94-V0 Fully Shielded
2. RJ45 In-Line Coupler Contact: Phosphor Bronze, 3-50 micro inches gold plating over nickel plate.
3. PCB: FR4
4. Plastic Frame: Polyamide UL94 V-2
5. Metal Frame: Diecast, Black or Nickel plated

Performance:

1. T568A & T568B wiring.
2. Meet ISO/IEC 11801 and EN50173
3. Meet ANSI/TIA/EIA 568B.2
4. Rating: 125VAC RMS 1.5A
5. Operating Temperatures: Min -10°C Max +70°C