

## FEATURES

- Operating frequency is 2GHz
- Nickel-plated body
- Gold-plated contacts
- ensure maximum efficiency

# RS PRO Coaxial Connectors

RS Stock No.:

2537058



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

SHV series of high voltage coaxial connectors.

High voltage coaxial connectors are mainly used for connecting high voltage power supply and device in nuclear instrument or electronic measuring device.

SHV is bayonet connection type.

SHV connectors are not intermateable with the BNC series..

## General Specifications

Type of coaxial connector	SHV jack
Body Orientation	Straight
Body Plating	Nickel
Body Material	Copper
Contact Material	Copper
Contact Plating	Gold
Gender A	Male
Mounting Type	Panel Mount
Pannel thickness	5.5mm
Polarity	Normal
Termination Method	Solder
Bulkhead	Yes

## Electrical Specifications

Temperature Range	-45°~+125°
Frequency Range	0~1.2GHz
Voltage Rating	2500 V(rms)
Maximum operating voltage	10000V(rms)
Current rating	10A
Working Life	500Cycles


**Approvals**

Declarations	CE
Hazardous Area Certification	
Standards Met	ROHS

**Similar Products**

Stock No.	Brand	Product Name	Attribute 1	Attribute 2	Attribute 3
2127444	RS PRO	RF coaxial connector	Gold plated contacts	Operating frequency is 1.2GHz	

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories

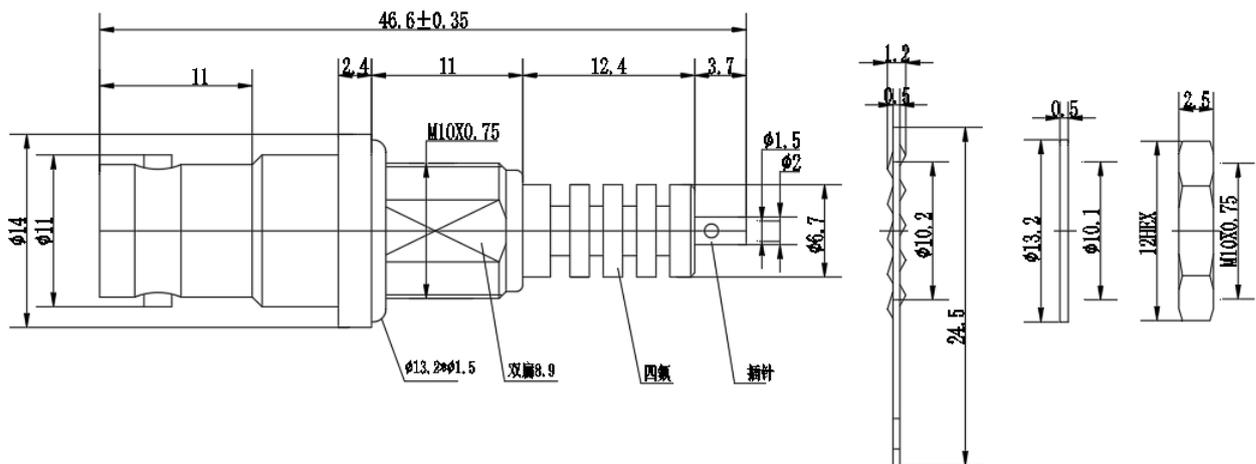

建议安装孔尺寸

