

Features

- HEAVY DUTY STRUCTURE AND HEAVY DUTY CARBON STEEL MADE
- EASY DISASSEMBLY
- MULTIFUNCTIONAL TOOL BOX
- SAFETY AND ELEGENT DESIGN
- DIAMOND-SHAPED PACKAGE DESIGN ON TOP
- INDUSTRIAL 5 INCH UNIVERSAL WHEEL
- MULTIPLE FUNCTIONS HANGING PANEL
- SELF LOCKING AND AUTOMATIC CLOSE DRAWER FUNCTION
- DULL POLISH SURFACE
- NEW DESIGN EMBEDDED HANDLE
- 6 LAYER EVA WITH 252PCS HIGH QUALITY TOOL SETS

RS PRO 252 Pieces Engineering Tool Kit with Trolley

RS Stock No.: 0214727



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO 252 Piece Tool Set and 7 Drawer Roller Cabinet

A hardwearing and spacious 7 drawer tool cabinet complete with a 252 piece tool kit fitted in EVA modules. The selected modules were chosen with engineers in mind supplying a comprehensive professional quality tool range.

Supplied ready to use the 7 drawer rolling tool cabinet is an excellent choice for industrial and automotive applications and is constructed from premium quality Steel enhanced with a scratch proof electrostatic powder coated finish.

Featuring a recessed worktop enabling use as a complete workstation and 7 low friction ball bearing drawers. Each Drawer accommodates up to one whole EVA Tool Modules and are fully extendable for easy access and are fitted with a Smart-Lock system preventing accidental opening when the cabinet is moved.

The heavy-duty roller cabinet wheels are made from industry PP featuring two fixed and two swivel for easy transport. A hardwearing tool cabinet with a comprehensive tool kit perfect for workshops and automotive applications.

Features and Benefits

- ***MULTI-FUNCTIONAL MECHANIC TOOL CART:*** This rolling tool chest features 7 drawers with movable wheels, allowing for flexible mobility and use as a detachable, linkable mobile tool case, catering to various storage and carrying needs.
- ***EASY TO OPERATION:*** The locking tool chest with drawers ensures tool security, while the drawers operate smoothly thanks to the ball-bearing design, providing users with a convenient user experience.
- ***DURABLE GARAGE TOOLBOX:*** Tool cabinets on wheels is constructed from robust and powder-coated steel, this garage tool box offers excellent wear resistance, ensuring a long service life and stable storage environment.
- ***EASY TO MOBILITY:*** The 7 drawer tool box on wheels equipped with 4 swivel wheels, including 2 with parking brakes, the tool cart can be freely moved within the garage and securely fixed in place, offering convenient operation and control.
- ***WIDE APPLICATIONS:*** The tool chest on wheels suitable for garage, warehouse, workshop, and repair shop use, meeting the diverse storage and carrying needs of professional users, enhancing work efficiency and convenience.

General Specifications

Set Type	Engineers
Set Contents	Hex Keys, Pliers, Ratchet, Screwdriver, Sockets, Spanners, Hammer, Wrench, Bits, Chisel
Number of Pieces	252
VDE/1000V Approved	No
Storage Type	Trolley

Mechanical Specifications

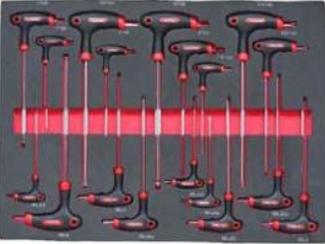
Type	258pcs tool trolley tool kit
Weight class	Heavy duty
Material	PP wheel / High carbon steel /Alu Guide rail
Use	Storage
Colour	Black/red
Assemble	Yes
Product Size	750*460*1030MM (including wheel and push hand)
COO	CHN
Loading	140KG
Product Weight	82kg
Drawer size	big drawer : 572*400*143mm small drawer : 572*400*65mm
Wheel details	2 parking brakes. 2 swivel wheels 5 inch
Locker / drawer details	One-button self-lock, automatic close function
Surface	Dull polish
Extension accessories	6 layer EVA tray and 252pcs tool set

Approvals

Declarations	REACH DoC
---------------------	-----------



	<p>17PC 1/2"DR.Sockets (Cr-V):8,9,10,11,12,13, 15,16,17,19,20,21,22,24,27,30,32mm 13PC 1/4"DR.Sockets (Cr-V):4,4.5,5,5.5,6,7,8, 9,10,11,12,13,14mm 10PC 3/8"DR.Sockets (Cr-V): 8,10,11,12,13,14, 15,16,17,19mm 9PC 1/2"DR.Deep Sockets (Cr-V): 8,9,10,11,12, 13,14,15,16mm 8PC 3/8"DR.Deep Sockets (Cr-V): 10,11,12, 13,14,15,17,19mm 10PC 1/4"DR.Deep Sockets (Cr-V):4,5,6,7,8,9, 10,11,12,13mm 1PC 1/4"Universal Joint 1PC 3/8"Universal Joint 1PC 1/2"Universal Joint 1PC 1/4"DR.Extension Bar:4" 1PC 3/8"DR.Extension Bar:6" 1PC 1/2"DR.Extension Bar:5" 1PC 1/4"DR.Quick Ratchet Handle 1PC 3/8"DR.Quick Ratchet Handle 1PC 1/2"DR.Quick Ratchet Handle 4PC Color socket:17-19-21-22mm</p>	<p>80 pcs</p>
	<p>24PC 8x30mm Bits: SL8,10,12, PH3,4,PZ3,4, T40,45,50,55,60,70,H7,8,10,12,14,T40H, 45H,50H,55H,60H,70H 1PC 3/8xH8 Bits Adapter 48PC 1/4 socket Bits: SL4,5,5.5,6,5.7,PH0,1,2,3, PZ0,1,2,3,T8,9,10,15,20,25,27,30,40,M8, 10,12,H3,4,5,6,7,8,T8H,9H,10H,15H,20H, 25H,27H,30H,40H,TS10H,15H,20H,25H, 27H,30H,40H,45H,50H 28PC 1/2 Socket Bits: H5,7,10,11,13,14,17,19, 22,24,M9,10,12,14,16,16H,R6,8,9,10, T30,40,45,50,55,60,70,80 1PC 1/2xM18</p>	<p>102 pcs</p>
	<p>1PC CS 6" Lognose plier 1PC CS 6" Diagonal plier 1PC CS 6" Combination plier 1PC CS 6" Bent nose plier 1PC 270mm Mechanism Hammer 1PC CS 10" Locking plier 1PC CS 7" Internal Straight circlip plier 1PC CS 7" Internal Bent circlip plier 1PC CS 7" External Bent circlip plier 1PC CS 7" External Straight circlip plier 6PC Stonecutter's Chisel:3x10x150, 4x10x150, 5x10x150, 6x10x150, 7x12x150, 8x12x150</p>	<p>16 pcs</p>
	<p>10PC Screwdriver : SL33*75,SL4*100,SL6*38,SL6*125,SL8*150,PH3*75,PH4*100,P H6*38,PH6*125,PH8*150 6PC Go-through Screwdriver: SL6*100,SL6*125,SL6*150,PH6*100,PH6*125,PH6*150 5PC Precision Screwdriver:t3 t4 t5 t6 +1.5</p>	<p>21 pcs</p>

	<p>9PC H Type Hex Key: H2*100, H2.5*100, H3*100, H4*150, H5*150, H6*150, H7*150, H8*200, H10*200 9PC T Type Hex Key: T10*100, T15*100, T20*100, T25*150, T27*100, T30*150, T40*150, T45*200, T50*200</p>	<p>18 pcs</p>
	<p>15 PC CS Combination Wrench sets 8-9-10-11-12-13-14-15-16-18-19-20-21--22-24mm</p>	<p>15 pcs</p>
	<p>EVA</p>	<p>6 Pcs</p>
	<p>Total</p>	<p>258 pcs</p>