


特点

**RS PRO 不可逆温度敏感标签，
71°C 至 110°C ， 8 个级别**

RS 库存号： 555-409

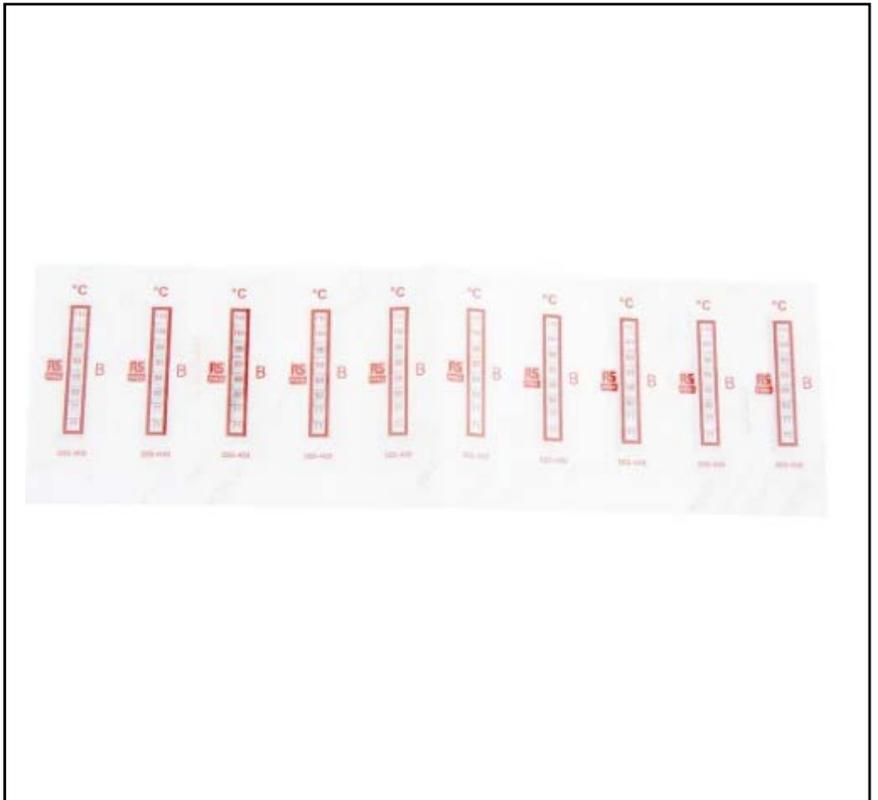

RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与杰出品牌相当的质量、而无需支付高昂的价格。

商品描述属性 1

RS PRO 的这些标签上的温度敏感棒是记录表面达到的最高温度的快速，简单方法。因此，它特别适用于需要密切关注机械表面温度的维护操作，或用于航空等行业中的测试应用。

一般规格

温度级别数	8
方向	垂直
可逆性	不可逆
比例	°C.
存储寿命	24 个月
表面或支架	聚酯
粘合剂类型	丙烯酸
换色材料	无毒、白色结晶、使用丙烯酸粘合剂粘合
公差	±1°C、±1.5°C
覆盖膜	聚酯
储存	存储在室温下
压力敏感	否
应用	食品工业、制药、医疗产品、工业设备、敏感货物的运输和包装

机械规格

尺寸	18mm x 51mm
标签长度	18mm
标签宽度	51mm

操作环境规格

最低温度灵敏度	71°C
最高温度灵敏度	110°C

附件

项目名称	项目说明	数量
时间指示器标签	时间带不可逆时间指示器标签, 19 x40mm, 3 个月	1box、共 100 个
时间指示器标签	时间带不可逆时间指示器标签 19 x40 毫米 6. 月	1box、共 100 个
时间指示器标签	时间带不可逆时间指示器标签 19 x40mm 12months	1box、共 100 个
时间指示器标签	时间带不可逆时间指示器标签 19 x40mm 1month	1box、共 100 个

Physical Properties:

(Not for specification purposes)

	Low Temperatures (171°C and below)	Mid Temperatures (177°C to 210°C)	High Temperatures (210°C+)
Adhesive Type	Acrylic	Modified Acrylic	Modified Acrylic
Carrier	Polyester	Tissue	Tissue
Covering Film	Polyester	Kaladex	Polyimide
Colour Change Material	Non-toxic, white crystalline solid on a black absorbent backing, adhered with acrylic adhesive		
Tolerance	29 to 99°C = ±1°C, 100 to 154°C = ±1.5°C and 160 to 280°C = ±1% +1°C		
Shelf Life	Temperatures from 29 – 34°C / 84 – 93°F = 6 months storage life, providing they are stored in a refrigerator inside a sealed bag. Temperatures from 37 – 49°C / 99 – 120°F = 12 months storage life, providing they are stored in a refrigerator inside a sealed bag. Temperatures from 54 – 290° / 130 – 554°F = 24 months storage life, store at room temperature & Humidity (i.e. 20°C/68°F & 50% relative humidity)		

RS Order Code	Description	Temperatures	Dimensions
555392	8 Level Range A	37-65°C	51mm x 18mm
555409	8 Level Range B	71-110°C	51mm x 18mm
555415	8 Level Range C	116-154°C	51mm x 18mm
555421	8 Level Range D	160-199°C	51mm x 18mm
555437	8 Level Range E	204-260°C	51mm x 18mm