

## FEATURES

- Operating frequency is 1GHz
- Nickel-plated body
- Gold-plated contacts
- ensure maximum efficiency

## RS PRO Family Name

RS Stock No.: 2469462



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

**Product Description**

The BNC RF coaxial plug connector with bayonet coupling and cable clamp. These 50Ω BNC direct RF coaxial cable clips feature a nickel plated body, gold plated center contact, and are suitable for use with a wide range of RF coaxial cable types.

**General Specifications**

Type of coaxial connector	BNC male
Body Orientation	Straight
Polarity	Normal
Mounting Type	Cable Mount
Body Plating	Nickel
Body Material	Copper
Contact Material	Copper
Contact Plating	Gold
Termination Method	Clamp
Gender	Male
Insulation Material	PTFE
Cable	RG174B

**Electrical Specifications**

Temperature Range	-40° ~+125°
Impedance	50 Ω
Frequency Range	0~1GHz
Voltage Rating	500 V
VSWR	1.5MAX
Working Life	500Cycles

**Protection Category**

--	--

**Additional Information**

EAN	
Custom Tariff Number	

**Classification**

eCl@ss (Version)	
UNSPSC (Version)	


**Approvals**

Declarations	CE
Hazardous Area Certification	
Standards Met	ROHS

**Similar Products**

Stock No.	Brand	Product Name	Attribute 1	Attribute 2	Attribute 3
5463800	RS PRO	RF coaxial connectorr	Gold plated contacts	Operating frequency is 1GHz	

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories

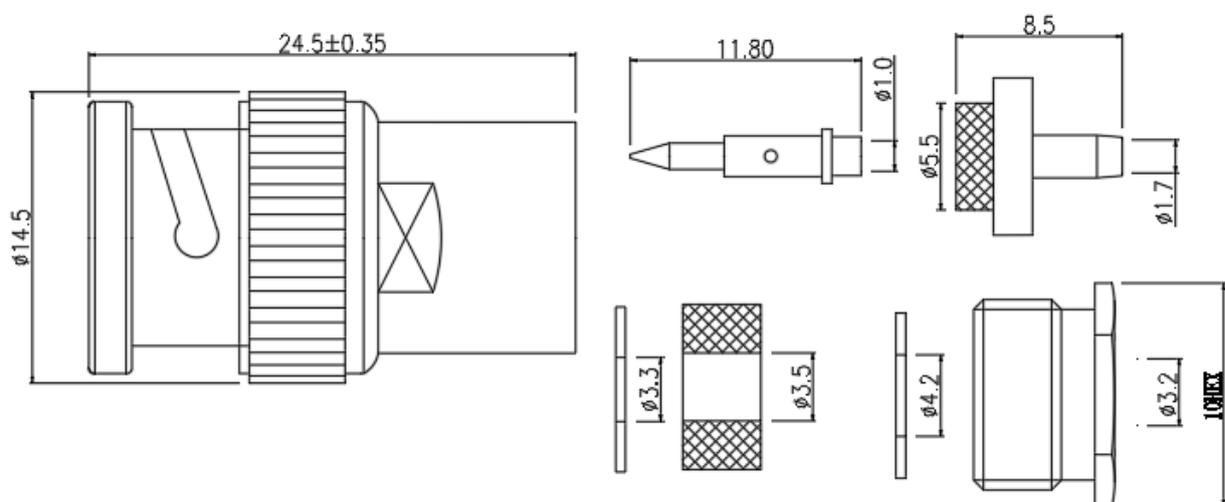

## 建议电缆剥线尺寸

