


特点

- 导线绞线是柔性的
- 耐油，温度高达 60°C
- 英国制造
- 各种护套颜色
- 适用于布线电路

RS PRO 蓝色三级电缆， 2.5 mm² CSA， 1 kV 直流， 600 V 交流， 30 A， 100 米

RS 库存号： 180-5959

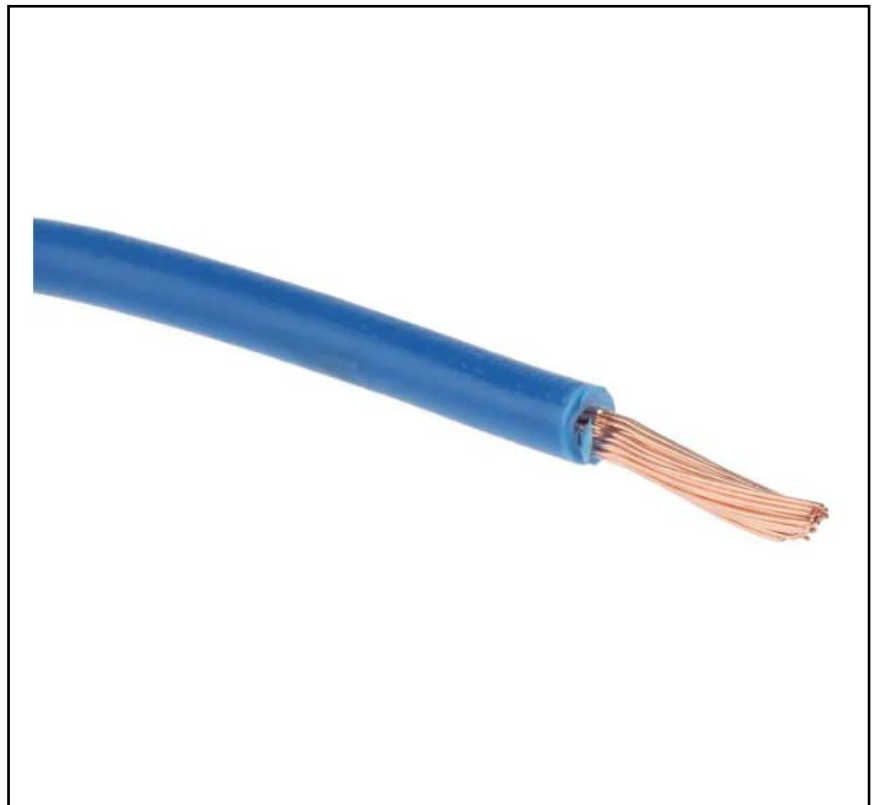

RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与杰出品牌相当的质量、而无需支付高昂的价格。

商品描述属性 1

我们的 RS PRO 三级电缆设计用于电气设备，最常用于包括电源开关设备在内的布线项目。该电缆还特别适用于整流器设备，电动机启动器和控制器内的内部连接。我们的 RS PRO 三级电缆系列具有高 Durable 电线，由柔性铜制成，采用 HR PVC (耐热聚氯乙烯) 绝缘封装。最大工作温度高达 105°C，使其可用于各种应用，如电气机柜。RS PRO 三级电缆提供各种不同颜色的 HR PVC 护套，包括蓝色，黑色，红色，棕色，绿色，黄色等，可适应多种应用

一般规格

类型	三级
三级	是的
护套颜色	蓝色
火灾行为	阻燃
应用	电气柜、工业电气安装、小型电子设备、继电器和仪表板、控制计量、电动机启动器

电气规格

额定电压	1kVdc 、 600Vac
额定电流	30A
导线材料	铜
绝缘材料	pvc

机械规格

长度	100m
横截面积	2.5mm ²
外径	3.7mm
芯线束	50/0.25mm
绞线尺寸	0.25mm
重量	33kg/km

操作环境规格

最高工作温度	105°C
最大导体温度	60°C 油

认证

合规性 / 认证	csa、ul、bsi、rohs 合规性认证。BSI EEE
符合标准	BS6231



Stock number:	180-5956	Black tri-rated cable 2.5mm 100m
	180-5959	Blue tri-rated cable 2.5mm 100m
	180-5962	Brown tri-rated cable 2.5mm 100m
	180-5972	Green tri-rated cable 2.5mm 100m
	180-5965	Green/yellow tri-rated cable 2.5mm 100m
	180-5964	Grey tri-rated cable 2.5mm 100m
	180-5958	Orange tri-rated cable 2.5mm 100m
	180-5966	Pink tri-rated cable 2.5mm 100m
	180-5960	Red tri-rated cable 2.5mm 100m
	180-5963	Violet tri-rated cable 2.5mm 100m
	180-5954	White tri-rated cable 2.5mm 100m
	180-5961	Yellow tri-rated cable 2.5mm 100m