


## 特点

- 导线绞线是柔性的，
- 耐油，温度高达 60°C
- 英国制造
- 各种护套颜色
- 适用于布线电路

**RS PRO 绿色 / 黄色三级电缆，  
1.5mm<sup>2</sup> CSA ， 1kV 直流，  
600V 交流， 21A ， 100 米**

RS 库存号： 180-5955

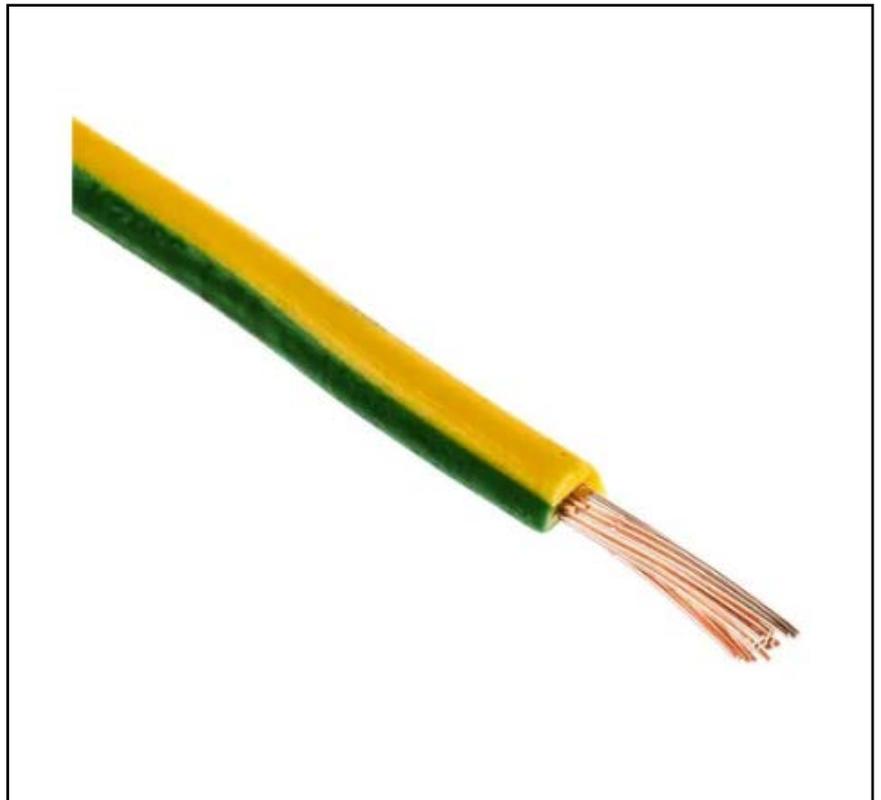

RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与杰出品牌相当的质量、而无需支付高昂的价格。

### 商品描述属性 1

我们的 RS PRO 三级电缆设计用于电气设备，最常用于包括电源开关设备在内的布线项目。该电缆还特别适用于整流器设备，电动机启动器和控制器内的内部连接。我们的 RS PRO 三级电缆系列具有高 Durable 电线，由柔性铜制成，采用 HR PVC (耐热聚氯乙烯) 绝缘封装。最大工作温度高达 105°C，使其可用于各种应用，如电气机柜。RS PRO 三级电缆提供各种不同颜色的 HR PVC 护套，包括蓝色，黑色，红色，棕色，绿色，黄色等，可适应多种应用

### 一般规格

类型	三级
三级	是的
护套颜色	黄色 / 绿色
火灾行为	阻燃
应用	电气柜、工业电气安装、小型电子设备、继电器和仪表板、控制计量、电动机启动器

### 电气规格

额定电压	1kVdc 、 600Vac
额定电流	21A
导线材料	铜
绝缘材料	pvc

## 机械规格

长度	100m
横截面积	1.5mm <sup>2</sup>
外径	3.3mm
芯线束	30/0.25 mm
绞线尺寸	0.25mm
重量	23kg/km

## 操作环境规格

最高工作温度	105°C
最大导体温度	60°C 油

## 认证

合规性 / 认证	csa 、 ul 、 bsi 、 rohs 合规性认证。 BSI EEE
符合标准	BS6231



---

<b>Stock number:</b>	<b>180-5946</b>	<b>Black tri-rated cable 1.5mm 100m</b>
	<b>180-5947</b>	<b>Blue tri-rated cable 1.5mm 100m</b>
	<b>180-5949</b>	<b>Brown tri-rated cable 1.5mm 100m</b>
	<b>180-5969</b>	<b>Green tri-rated cable 1.5mm 100m</b>
	<b>180-5955</b>	<b>Green/yellow tri-rated cable 1.5mm 100m</b>
	<b>180-5953</b>	<b>Grey tri-rated cable 1.5mm 100m</b>
	<b>180-5952</b>	<b>Orange tri-rated cable 1.5mm 100m</b>
	<b>180-5945</b>	<b>Pink tri-rated cable 1.5mm 100m</b>
	<b>180-5950</b>	<b>Red tri-rated cable 1.5mm 100m</b>
	<b>180-5971</b>	<b>Violet tri-rated cable 1.5mm 100m</b>
	<b>180-5948</b>	<b>White tri-rated cable 1.5mm 100m</b>
	<b>180-5951</b>	<b>Yellow tri-rated cable 1.5mm 100m</b>