


Features

- Material: UL approved Nylon 66, 94V-2.
- Color: Light green (standard), black color available.
- Feature : Designed for high-temperature up to 105°C.
- Feature: Low Smoke and Halogen Free cable tie suitable for various industry, also household DIY and gardening.
- Application: One piece self-lock cable tie save the time and make effective for installation.

RS PRO Heat Stabilized Cable Ties

RS Stock No.: 8111622

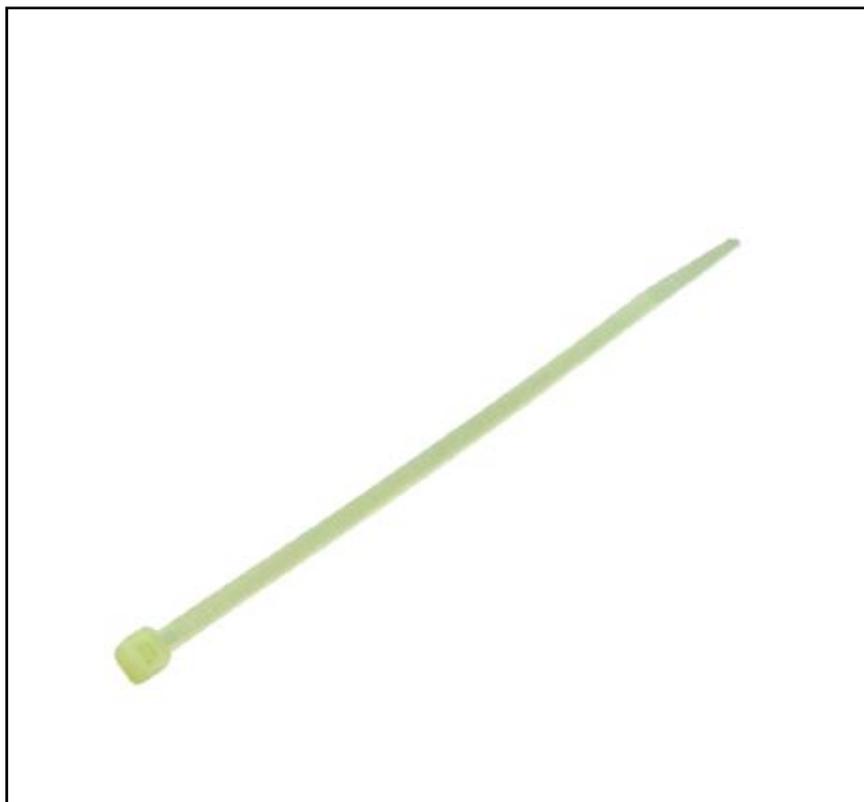

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

- *Material: UL approved Nylon 66 , 94V-2.*
- *Color: Light Green, other special colors are available upon request.*
- *Feature: Low Smoke and Halogen Free cable tie suitable for various industry, also household DIY and gardening.*
- *Max. operating temperature up to 105 °C*
- *Application: One piece self-lock cable tie save the time and make effective for installation.*

General Specifications

Type	Non-Releasable
Colour	Light Green
Material	Nylon 66
UV Resistant	No
Minimum Operating Temperature	-40°C
Maximum Operating Temperature	105°C
Fire Behaviour	Self-Extinguishing
Quantity	250

Mechanical Specifications

Length	203mm / 8"
Width	2.5mm / 0.1"
Min. Loop Tensile Strength(lbs/kgf/N)	18lbs / 8kgf / 80N
Maximum Bundle Dia.	55mm

Approvals

Standards Met	UL, RoHS, SVHC, ABS, HF
---------------	-------------------------

