


Datasheet

RS Pro Rectangular Magnetic Proximity Switch Magnet

Stock No: 339-768

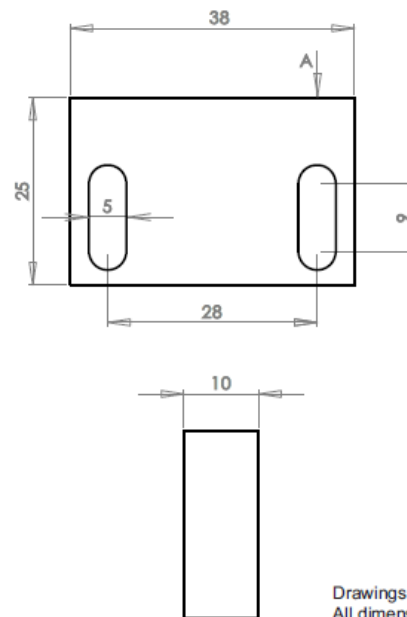

Drawings not to scale
All dimensions in mm nominal

✓ RoHS Compliant

SPECIFICATION		
Size	Length mm	38
	Width mm	10
	Height mm	25
Gauss Strength / Surface	Max	β00 (at point A)
Operating Temperature	Celsius	-20° to 85°
Case Material	Powder coated Aluminium	
Magnet	Neodymium N35	
Applications Include		Options/Features
- Position and Limit sensing. - Machinery safety guard. - Automated production line. - Security alarm system.		Robust sealed magnet.
		Powder coated to resist corrosion.
		Strong Neodymium magnet.