

Features

- DPST Rocker Switch
- Red Illuminated
- 28x22mm cutout
- 01 marking
- 20A/250VAC

RS PRO Rocker Switches

RS Stock No.: 1858229



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

This mains voltage rocker switches illuminates red ensuring it stands out within a panel. It is a stylish, robust switch with a current rating of 20A and a mechanical lifespan of 50,000 cycles. Applications are varied including:

- *Domestic appliances*
- *Medical equipment*
- *HVAC products*
- *Cleaning machines such as vacuum cleaners & steam cleaners*

General Specifications

Contact Configuration	DPST
Switch Operation	On-Off, Latching
Illuminated	Yes
Actuator Colour	Red
Actuator Shape	Rectangular
Legend Text	0 I
Legend Text Colour	White
Contact Material	Silver
Case Material	PA66
Actuator Style	Rocker

Electrical Specifications

Contact Current Rating	20A
AC Voltage Rating	250VAC / 125VAC
Terminal Type	Tab
Termination Style	6.3mm
Electrical Life	10,000 cycles
Illumination Voltage	250VAC

Mechanical Specifications

Panel Cut Out Size	28.2x22.3mm
Mounting Type	Panel
Mechanical Life	50,000 Operations
Unit Weight	12.8g
Contact Opening	Full disconnection $\geq 3\text{mm}$

Operation Environment Specifications

Max. Operating Temperature	Max 125°C / 55°C
----------------------------	------------------

Protection Category

IP Rating	IP40
Glow Wire Test	850°C



Classification

Class of Appliance	II
--------------------	----

Approvals

Compliance/Certifications	ENEC, EN61058, UL 1054, CQC
Declarations	CE, UKCA

Dimensions (mm)

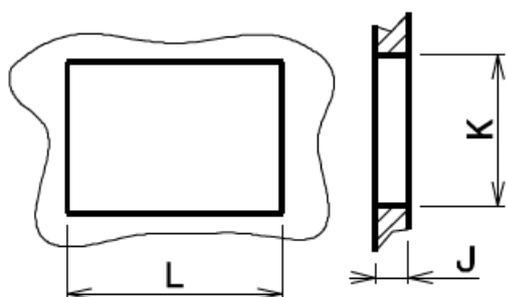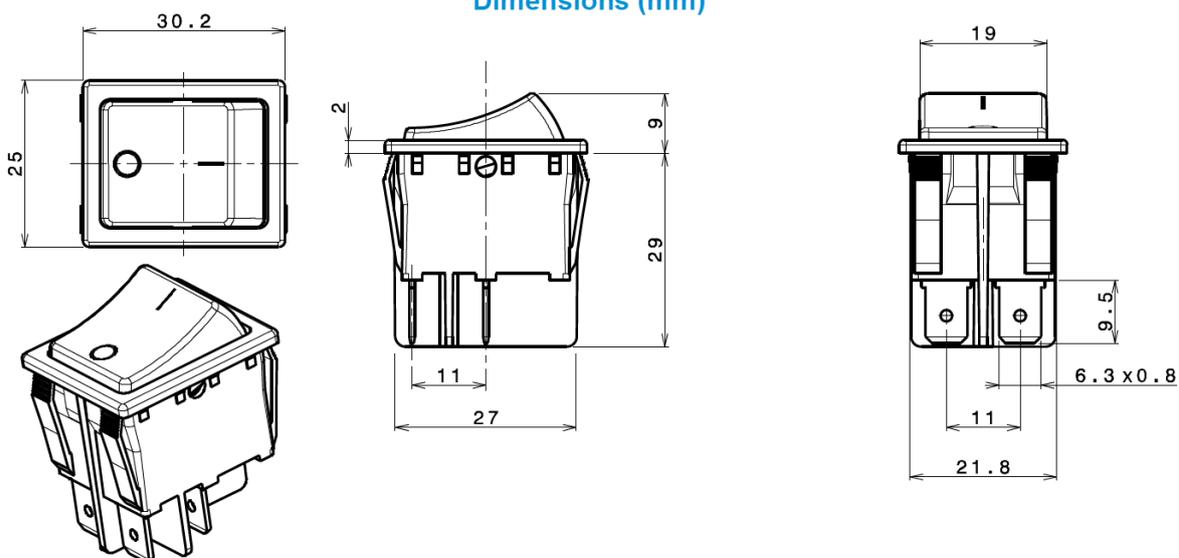

L	K	J
28.2 $^{+0.1}_0$	22.3 $^{+0.1}_0$	0.7+3.5

Wiring diagrams

