

Features

- Anti-vibration buffer foot
- Male
- EPDM rubber
- Stainless Steel thread

RS PRO Cylindrical Male - Foot Anti-Vibration Mounts

RS Stock No.:

See table



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description


MALE - FOOT/BUMP STOP Cylindrical mounts, a simple and cost effective mount. For use in compression or as a Buffer. A very large range of available size and studs.

H = Height

D = Diameter

G = Tread Size

L = Thread Length

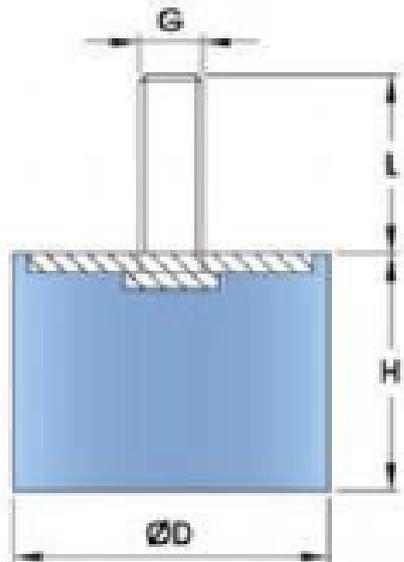

General Specifications

RS Code	Metal type	Rubber	Hardness	D (mm)	H (mm)	GxB (mm)
1264923	Zinc plated steel	Natural Rubber	60 Shore A	8	5	M3x6
1264925	Zinc plated steel	Natural Rubber	45 Shore A	10	8	M4x10
1263927	Stainless steel grade 304	EPDM Rubber	85 Shore A	10	8	M4x6
1264926	Zinc plated steel	Natural Rubber	60 Shore A	10	10	M4x6
1264927	Stainless steel grade 304	Natural Rubber	40 Shore A	12.5	15	M5x10
1264928	Zinc plated steel	Natural Rubber	55 Shore A	12	19	M5x12
1264929	Zinc plated steel	Natural Rubber	45 Shore A	15	8	M4x10
1264931	Zinc plated steel	Natural Rubber	60 Shore A	15	8	M4x15

1264932	Zinc plated steel	Natural Rubber	50 Shore A	15	15	M4x10
1264933	Zinc plated steel	Natural Rubber	60 Shore A	15	15	M5x15
1264934	Zinc plated steel	Natural Rubber	60 Shore A	15	15	M6x6
1264935	Zinc plated steel	Natural Rubber	60 Shore A	15	20	M5x12
1264936	Zinc plated steel	Natural Rubber	60 Shore A	15	25	M5x12
1264937	Zinc plated steel	Natural Rubber	55 Shore A	16	10	M5x12
1264938	Zinc plated steel	Natural Rubber	60 Shore A	16	18	M4x10
1264939	Zinc plated steel	Natural Rubber	60 Shore A	16	18	M5x15
1264940	Zinc plated steel	Natural Rubber	60 Shore A	16	20	M5x12
1264941	Zinc plated steel	Natural Rubber	60 Shore A	20	8	M6x15
1264942	Zinc plated steel	Natural Rubber	60 Shore A	20	10	M8x20
1264943	Zinc plated steel	Natural Rubber	60 Shore A	20	13	M6x20
1264944	Zinc plated steel	Natural Rubber	45 Shore A	20	15	M6x10
1264945	Zinc plated steel	Natural Rubber	60 Shore A	20	20	M6x15
1264947	Zinc plated steel	Natural Rubber	45 Shore A	20	20	M6x20
1264948	Zinc plated steel	Natural Rubber	55 Shore A	20	20	M6x20
1263928	Stainless steel grade 304	Natural Rubber	50 Shore A	20	20	M6x20
1264949	Zinc plated steel	Natural Rubber	60 Shore A	20	25	M6x15
1264950	Zinc plated steel	Natural Rubber	60 Shore A	25	10	M6x18
1264951	Zinc plated steel	Natural Rubber	60 Shore A	25	10	M8x20
1264953	Zinc plated steel	Natural Rubber	45 Shore A	25	15	M6x18
1264954	Zinc plated steel	Natural Rubber	60 Shore A	25	15	M8x20
1264955	Zinc plated steel	Natural Rubber	60 Shore A	25	20	M8x20
1264956	Zinc plated steel	Natural Rubber	60 Shore A	25	30	M6x18

1264957	Zinc plated steel	Natural Rubber	50 Shore A	30	8	M8x40
1264958	Zinc plated steel	Natural Rubber	55 Shore A	30	10	M6x28
1264959	Zinc plated steel	Natural Rubber	55 Shore A	30	10	M6x28
1264960	Zinc plated steel	Natural Rubber	60 Shore A	30	15	M8x25
1264961	Zinc plated steel	Natural Rubber	60 Shore A	30	17	M8x30
1263929	Stainless steel grade 304	Natural Rubber	45 Shore A	30	20	M8x15
1264962	Zinc plated steel	Natural Rubber	60 Shore A	30	20	M8x15
1264963	Zinc plated steel	Natural Rubber	60 Shore A	30	20	M8x25
1264964	Zinc plated steel	Natural Rubber	60 Shore A	30	25	M8x10
1264965	Zinc plated steel	Natural Rubber	60 Shore A	30	30	M8x25
1264966	Zinc plated steel	Natural Rubber	60 Shore A	30	35	M6x18
1264967	Zinc plated steel	Natural Rubber	60 Shore A	30	35	M8x15
1264969	Zinc plated steel	Natural Rubber	60 Shore A	30	35	M8x33
1264970	Zinc plated steel	Natural Rubber	60 Shore A	40	20	M10x25
1264971	Zinc plated steel	Natural Rubber	50 Shore A	40	20	M8x20
1264972	Zinc plated steel	Natural Rubber	60 Shore A	40	25	M10x25
1264973	Zinc plated steel	Natural Rubber	45 Shore A	40	25	M6x20
1264975	Zinc plated steel	Natural Rubber	60 Shore A	40	30	M10x25
1264976	Zinc plated steel	Natural Rubber	45 Shore A	40	30	M8x20
1264977	Zinc plated steel	Natural Rubber	60 Shore A	40	30	M8x23
1264978	Zinc plated steel	Natural Rubber	60 Shore A	40	30	M8x25
1264979	Zinc plated steel	Natural Rubber	55 Shore A	40	35	M8x20
1264981	Zinc plated steel	Natural Rubber	60 Shore A	40	40	M10x25
1264982	Zinc plated steel	Natural Rubber	60 Shore A	50	20	M10x30

1264983	Zinc plated steel	Natural Rubber	60 Shore A	50	25	M10x30
1264984	Zinc plated steel	Natural Rubber	60 Shore A	50	30	M10x25
1265930	Zinc plated steel	Natural Rubber	60 Shore A	50	30	M10x30
1265931	Zinc plated steel	Natural Rubber	60 Shore A	50	40	M10x25
1263930	Stainless steel grade 304	Natural Rubber	60 Shore A	50	40	M10x25
1265932	Zinc plated steel	Natural Rubber	60 Shore A	50	45	M10x25
1265933	Zinc plated steel	Natural Rubber	50 Shore A	50	50	M10x25
1265934	Zinc plated steel	Natural Rubber	60 Shore A	50	50	M8x25
1265935	Zinc plated steel	Natural Rubber	60 Shore A	60	35	M10x25
1265936	Zinc plated steel	Natural Rubber	60 Shore A	70	20	M10x15
1265937	Zinc plated steel	Natural Rubber	60 Shore A	70	50	M10x25
1265938	Zinc plated steel	Natural Rubber	60 Shore A	75	30	M12x40
1263931	Stainless steel grade 304	Natural Rubber	55 Shore A	75	35	M12x37
1265943	Zinc plated steel	Natural Rubber	45 Shore A	75	50	M10x28
1265944	Zinc plated steel	Natural Rubber	45 Shore A	75	50	M12x40