

特点

- 提供各种螺纹尺寸
- 坚固的镀锌钢
- 头高度等于柄直径
- 经济实惠

RS M4 Pro 6mm 内六角半圆头 螺钉、采用亮光 镀锌钢

RS 号: 822-9164



RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与领先品牌相当的质量、而无需支付高昂的价格。

商品描述属性

RS Pro 系列半圆头凹头螺钉提供的出色功能、适用于机器维修和固定应用。这些双镀锌钢是其他昂贵不锈钢的经济型解决方案、具有出色的固定方法。如果不存在腐蚀问题、它们特别适用于室内应用。所有型号均高度可靠且质量极佳。

一般规格

| | |
|------|-------------------------------------|
| 螺纹尺寸 | M4 |
| 头部形状 | 六角套筒按钮 |
| 材料 | 钢 |
| 表面 | 亮镀锌 |
| 螺纹类型 | 公制 |
| 等级 | 10.9 |
| 应用 | 木材加工、家用应用、紧固件和固定件、机器工具和维修、安全防护、面板制造 |

机械规格

| | |
|----------|-------------------|
| 长度 | 6mm |
| 螺距 | 0.7mm |
| 头直径范围 | 7.24 mm 至 7.60 mm |
| 头部高度范围 | 1.95 mm 至 2.20 mm |
| 钥匙尺寸标称范围 | 2.52 mm 至 2.56 mm |
| 关键敬业度 | 1.3 |
| 螺纹公差 | 6g |

认证

合规性 / 认证

rohs 符合性证书, ISO7380, ansi B18




Please view our full range listing below for all BZP Steel Hexagon Socket Button Head Screws:

| Head Shape | Material | Thread Size | Length | RS Part No. |
|---------------|-----------|-------------|--------|-------------|
| Socket Button | Steel BZP | M3 | 6 mm | 8229155 |
| Socket Button | Steel BZP | M4 | 6 mm | 8229164 |
| Socket Button | Steel BZP | M4 | 20 mm | 8229167 |
| Socket Button | Steel BZP | M4 | 25 mm | 8229161 |
| Socket Button | Steel BZP | M5 | 6 mm | 8229170 |
| Socket Button | Steel BZP | M5 | 8 mm | 8229173 |
| Socket Button | Steel BZP | M5 | 25 mm | 8229177 |
| Socket Button | Steel BZP | M5 | 35 mm | 8229186 |
| Socket Button | Steel BZP | M6 | 8 mm | 8229189 |
| Socket Button | Steel BZP | M6 | 10 mm | 8229183 |
| Socket Button | Steel BZP | M6 | 50 mm | 8229192 |

| | | | | |
|---------------|-----------|-----|-------|---------|
| Socket Button | Steel BZP | M8 | 10 mm | 8229195 |
| Socket Button | Steel BZP | M8 | 30 mm | 8229199 |
| Socket Button | Steel BZP | M8 | 35 mm | 8229209 |
| Socket Button | Steel BZP | M8 | 40 mm | 8229202 |
| Socket Button | Steel BZP | M8 | 45 mm | 8229206 |
| Socket Button | Steel BZP | M8 | 50 mm | 8229215 |
| Socket Button | Steel BZP | M10 | 16 mm | 8229218 |
| Socket Button | Steel BZP | M10 | 20 mm | 8229212 |
| Socket Button | Steel BZP | M10 | 25 mm | 8229221 |
| Socket Button | Steel BZP | M10 | 30 mm | 8229224 |
| Socket Button | Steel BZP | M10 | 35 mm | 8229228 |
| Socket Button | Steel BZP | M10 | 40 mm | 8229237 |
| Socket Button | Steel BZP | M10 | 50 mm | 8229320 |

Please view our full range listing below for all BZP Steel Hexagon Socket Button Head Screws:

| Head Shape | Material | Thread Size | Length | RS Part No. |
|---------------|-----------|-------------|--------|-------------|
| Socket Button | Steel BZP | M12 | 20 mm | 8229234 |
| Socket Button | Steel BZP | M12 | 25 mm | 8229243 |
| Socket Button | Steel BZP | M12 | 30 mm | 8229246 |
| Socket Button | Steel BZP | M12 | 35 mm | 8229240 |
| Socket Button | Steel BZP | M12 | 40 mm | 8229259 |

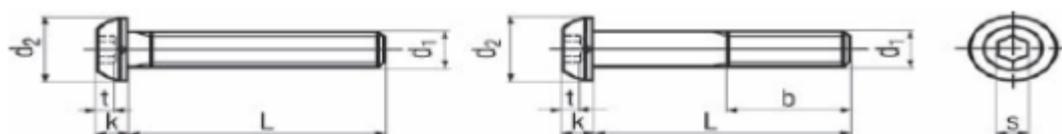

| Thread Size d1 | | M3 | M4 | M5 | M6 | M8 | M10 | M12 | M16 |
|---------------------------------|--------------|-------|------|-------|-------|-------|-------|-------|--------|
| Thread Pitch | | 0.5 | 0.7 | 0.8 | 1 | 1.25 | 1.5 | 1.75 | 2 |
| ~ISO 7380 Head Dia. d2 | min. | 5.4 | 7.24 | 9.14 | 10.07 | 13.57 | 17.07 | 20.48 | 27.48 |
| | max. | 5.7 | 7.60 | 9.50 | 10.50 | 14.00 | 17.50 | 21.00 | 28.00 |
| ANSI B 18.3.4M Head Dia. d2 | min. | 5.4 | 7.24 | 9.14 | 10.07 | 13.57 | 17.07 | 20.48 | 27.48 |
| | max. | 5.7 | 7.60 | 9.50 | 10.50 | 14.00 | 17.50 | 21.00 | 28.00 |
| ~ISO 7380 Head Height k | min. | 1.40 | 1.95 | 2.50 | 3.00 | 4.10 | 5.20 | 6.24 | 8.44 |
| | max. | 1.65 | 2.20 | 2.75 | 3.30 | 4.40 | 5.50 | 6.60 | 8.80 |
| ANSI B 18.3.4M Head Height k | min. | 1.43 | 1.95 | 2.50 | 3.00 | 4.05 | 5.20 | 6.24 | 8.44 |
| | max. | 1.65 | 2.20 | 2.75 | 3.30 | 4.40 | 5.50 | 6.60 | 8.80 |
| ~ISO 7380 Key Size s | Nominal Size | 2 | 2.5 | 3 | 4 | 5 | 6 | 8 | 10 |
| | min. | 2.020 | 2.52 | 3.020 | 4.020 | 5.020 | 6.020 | 8.025 | 10.025 |
| | max. | 2.045 | 2.56 | 3.071 | 4.084 | 5.084 | 6.095 | 8.115 | 10.115 |
| ANSI B 18.3.4M Key Size s | Nominal Size | 2 | 2.5 | 3 | 4 | 5 | 6 | 8 | 10 |
| | min. | 2.020 | 2.52 | 3.020 | 4.020 | 5.020 | 6.020 | 8.025 | 10.025 |
| | max. | 2.045 | 2.56 | 3.071 | 4.084 | 5.084 | 6.095 | 8.115 | 10.115 |
| ~ISO 7380 Key Engagement t | min. | 1.04 | 1.3 | 1.56 | 2.08 | 2.60 | 3.12 | 4.16 | 5.20 |
| ANSI B 18.3.4M Key Engagement t | min. | 1.04 | 1.3 | 1.56 | 2.08 | 2.60 | 3.12 | 4.16 | 5.20 |

