

Features

- Large static generator engines
- Compressors
- Motors
- Electronic control panels
- Engine Mounts

RS PRO Cylindrical Male - Male Anti-Vibration Mounts

RS Stock No.: 1263916 to 1264332



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

MALE - FEMALE Cylindrical mounts, a simple and cost effective mount. For use in compression and shear. A very large range of available size and studs.


H = Height

D = Diameter

G = Tread Size

L = Stud Length

B = Thread Depth

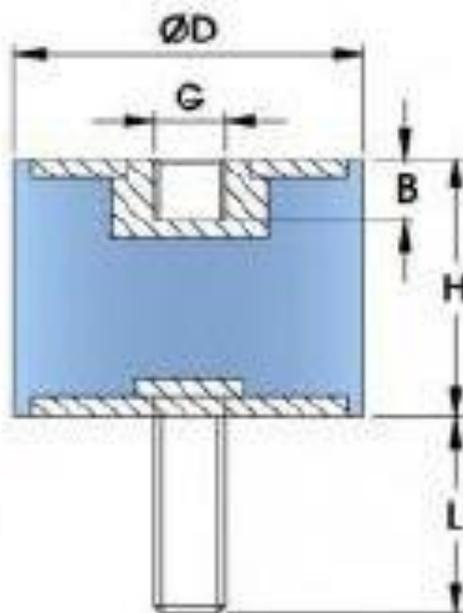

General Specifications

RS Code	Metal type	Rubber	Hardness	D (mm)	H (mm)	GxL/B (mm)	Max. Shear Load	Max. Compression Load
1263916	Stainless steel grade 304	EPDM Rubber	80 Shore A	10	15	M5x8/5	2.98kg	8.43kg
1263917	Stainless steel grade 304	Natural Rubber	60 Shore A	25	15	M6x20/6	13.2kg	47.3kg
1263918	Stainless steel grade 304	Natural Rubber	55 Shore A	30	20	M8x20/8	15.2kg	51.92kg
1263919	Stainless steel grade 316	EPDM Rubber	45 Shore A	40	30	M8x20/8	17kg	52.91kg
1263920	Stainless steel grade 304	Natural Rubber	60 Shore A	50	45	M10x25/10	53kg	154.22kg
1263921	Stainless steel grade 304	EPDM Rubber	60 Shore A	60	50	M10x25/10	45kg	165kg
1264282	Zinc plated steel	Natural Rubber	60 Shore A	8	8	M3x6/3	1.6kg	5.28kg
1264283	Zinc plated steel	Natural Rubber	55 Shore A	10	8	M4x6/4	1.44kg	4.75kg
1264284	Zinc plated steel	Natural Rubber	60 Shore A	10	18	M4x6/4	1.5kg	4.95kg
1264285	Zinc plated steel	Natural Rubber	60 Shore A	12	19	M5x10/5	1.5kg	5.5kg

1264286	Zinc plated steel	Natural Rubber	60 Shore A	13	15	M4x10/4	2kg	6.4kg
1264287	Zinc plated steel	Natural Rubber	60 Shore A	15	20	M4x10/4	3.2kg	10.78kg
1264288	Zinc plated steel	Natural Rubber	55 Shore A	15	30	M4x12/4	0.96kg	2.96kg
1264289	Zinc plated steel	Natural Rubber	50 Shore A	16	10	M5x12/5	7.62kg	20.96kg
1264290	Zinc plated steel	Natural Rubber	50 Shore A	16	15	M4x10/4	5.4kg	12.7kg
1264291	Zinc plated steel	Natural Rubber	60 Shore A	16	15	M4x10/4	7kg	25kg
1264292	Zinc plated steel	Natural Rubber	55 Shore A	16	15	M5x12/5	5.7kg	16kg
1264293	Zinc plated steel	Natural Rubber	60 Shore A	16	20	M5x12/5	1.5kg	5.5kg
1264294	Zinc plated steel	Natural Rubber	60 Shore A	20	10	M6x10/6	13.6kg	37.4kg
1264295	Zinc plated steel	Natural Rubber	55 Shore A	20	15	M6x15/6	5.33kg	17.18kg
1264296	Zinc plated steel	Natural Rubber	45 Shore A	20	15	M6x18/6	4.2kg	13.53kg
1264297	Zinc plated steel	Natural Rubber	60 Shore A	20	20	M6x18/6	8.4kg	24.2kg
1264298	Zinc plated steel	Natural Rubber	45 Shore A	20	25	M5x15/5	4.2kg	11.55kg
1264299	Zinc plated steel	Natural Rubber	60 Shore A	20	25	M6x18/6	8.4kg	23.1kg
1264300	Zinc plated steel	Natural Rubber	60 Shore A	20	30	M6x10/6	8.2kg	22.44kg
1264301	Stainless steel grade 304	Natural Rubber	60 Shore A	25	10	M6x20/6	10kg	53kg

1264302	Zinc plated steel	Natural Rubber	60 Shore A	25	15	M6x18/6	13.2kg	47.3kg
1264303	Zinc plated steel	Natural Rubber	60 Shore A	25	25	M8x20/8	13.2kg	37.62kg
1264304	Zinc plated steel	Natural Rubber	65 Shore A	25	30	M6x18/6	15.84kg	43.3kg
1264305	Zinc plated steel	Natural Rubber	60 Shore A	25	30	M8x12/8	13.2kg	36.08kg
1264306	Zinc plated steel	Natural Rubber	50 Shore A	25	30	M8x20/8	8.38kg	22.91kg
1264307	Zinc plated steel	Natural Rubber	60 Shore A	25	30	M8x20/8	13.2kg	36.08kg
1264308	Zinc plated steel	Natural Rubber	60 Shore A	30	15	M8x25/8	19kg	83.16kg
1264309	Zinc plated steel	Natural Rubber	60 Shore A	30	22	M8x20/8	19kg	59.4kg
1264310	Zinc plated steel	Natural Rubber	60 Shore A	30	22	M8x25/8	19kg	59.4kg
1264311	Zinc plated steel	Natural Rubber	45 Shore A	30	25	M6x10/6	9.5kg	28.93kg
1264312	Zinc plated steel	Natural Rubber	60 Shore A	30	25	M8x10/8	19kg	57.86kg
1264313	Zinc plated steel	Natural Rubber	60 Shore A	30	30	M8x20/8	19kg	54.56kg
1264314	Zinc plated steel	Natural Rubber	60 Shore A	30	30	M8x25/8	19kg	54.56kg
1264315	Zinc plated steel	Natural Rubber	60 Shore A	40	20	M10x25/10	34kg	139.04kg
1264316	Zinc plated steel	Natural Rubber	60 Shore A	40	20	M8x23/8	34kg	139.04kg
1264317	Zinc plated steel	Natural Rubber	60 Shore A	40	28	M10x25/10	34kg	108.24kg

1264318	Zinc plated steel	Natural Rubber	60 Shore A	40	30	M10x25/10	34kg	105.82kg
1264319	Zinc plated steel	Natural Rubber	60 Shore A	40	30	M8x23/8	34kg	105.82kg
1264320	Zinc plated steel	Natural Rubber	60 Shore A	40	35	M10x25/10	34kg	101.2kg
1264321	Zinc plated steel	Natural Rubber	60 Shore A	40	40	M8x20/8	34kg	96.14kg
1264322	Zinc plated steel	Natural Rubber	60 Shore A	50	20	M10x25/10	53kg	274.56kg
1264323	Zinc plated steel	Natural Rubber	60 Shore A	50	20	M12x33/12	53kg	274.56kg
1264324	Zinc plated steel	Natural Rubber	60 Shore A	50	35	M10x25/10	53kg	170.28kg
1264325	Zinc plated steel	Natural Rubber	60 Shore A	50	40	M10x25/10	53kg	160.6kg
1264326	Zinc plated steel	Natural Rubber	60 Shore A	50	45	M10x25/10	53kg	154.22kg
1264327	Zinc plated steel	Natural Rubber	60 Shore A	50	50	M10x25/10	53kg	149.82kg
1264328	Zinc plated steel	Natural Rubber	60 Shore A	50	55	M12x28/12	57.7kg	160.6kg
1264329	Zinc plated steel	Natural Rubber	60 Shore A	60	35	M10x25/10	60kg	272.14kg
1264330	Zinc plated steel	Natural Rubber	55 Shore A	60	45	M10x30/10	48kg	176.18kg
1264331	Zinc plated steel	Natural Rubber	60 Shore A	70	50	M10x25/10	80kg	313.06kg
1264332	Zinc plated steel	Natural Rubber	50 Shore A	75	40	M12x37/12	75.69kg	283.87kg