

Datasheet

NPT Stainless Steel Compression Glands for Thread Sizes: 1/8", 1/4" & 1/2"

- Thermocouple installation fittings
- To suit a wide range of mineral insulated and other probe type sensors offered by RS
- Male in-line stainless steel NPT compression type with nut & olive
- 1/8", 1/4", & 1/2" NPT threads available.
- Suits 1.0mm, 1.5mm, 2.0mm, 3.0mm, 4.0mm, 4.5mm, 6.0mm, 8.0mm, 1/8", 3/16" or 1/4" probe diameters







Type	Thread Size	Thread Type	Suits Probe Ø	RS order code
St/Steel	1/8"	NPT	1.0mm	123-5559
St/Steel	1/8"	NPT	1.5mm	123-5560
St/Steel	1/8"	NPT	2.0mm	178-0973
St/Steel	1/8"	NPT	3.0mm	123-5561
St/Steel	1/8"	NPT	4.0mm	123-5558
St/Steel	1/8"	NPT	4.5mm	123-5563
St/Steel	1/8"	NPT	6.0mm	123-5565
St/Steel	1/8"	NPT	1/8"	123-5562
St/Steel	1/8"	NPT	3/16"	123-5564
St/Steel	1/8"	NPT	1/4"	123-5566
St/Steel	1/4"	NPT	1.5mm	123-5567
St/Steel	1/4"	NPT	3.0mm	123-5568
St/Steel	1/4"	NPT	4.0mm	123-5574
St/Steel	1/4"	NPT	4.5mm	123-5570
St/Steel	1/4"	NPT	6.0mm	123-5572
St/Steel	1/4"	NPT	8.0mm	123-5573
St/Steel	1/4"	NPT	1/8"	123-5569
St/Steel	1/4"	NPT	3/16"	123-5571
St/Steel	1/4"	NPT	1/4"	123-5575
St/Steel	1/2"	NPT	3.0mm	123-5576
St/Steel	1/2"	NPT	4.5mm	123-5577
St/Steel	1/2"	NPT	6.0mm	123-5578
St/Steel	1/2"	NPT	8.0mm	123-5579
St/Steel	1/2"	NPT	1/8"	123-5580
St/Steel	1/2"	NPT	3/16"	123-5581
St/Steel	1/2"	NPT	1/4"	123-5582



DO NOT SCALE

THIRD ANGLE PROJECTION

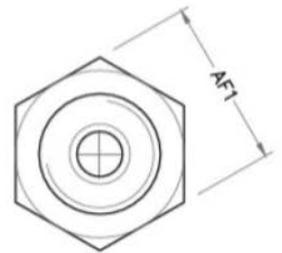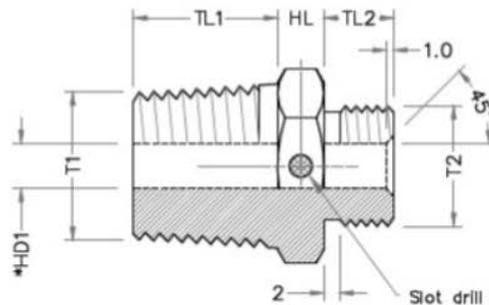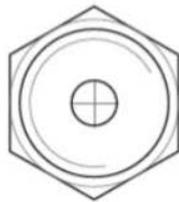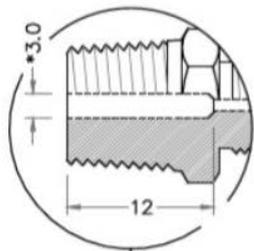

*Drill out 3.0mm dia. x 12mm deep
where HD1 = 0.60, 1.10, 1.60 or 1.70mm

Slot drill 3.0mm \varnothing x 0.35mm deep
(centrally to one side of hex face)