



EN

## Datasheet

# RS PRO NYLON-INSULATED CORD END

## TERMINALS

Stock number: 178-7308

MAXIMUM ELECTRIC CURRENT:

A.W.G.	16
AMP.	18


MAXIMUM ELECTRICAL RATING: 105° C 600 VOLTS MAX.

INSULATION MATERIAL: NYLON

TERMINAL MATERIAL: COPPER TUBE

SURFACE TREATMENT: TIN PLATE

INSULATION COLOR: RED

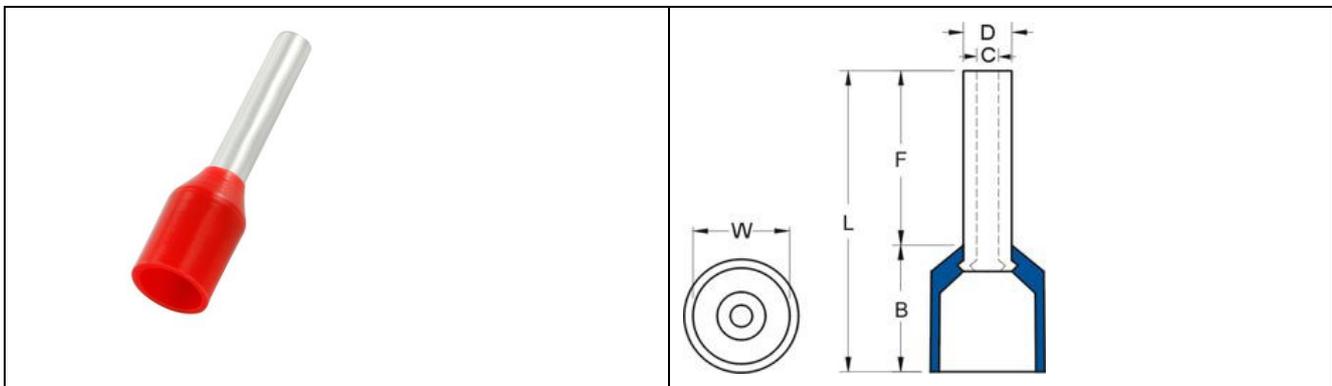

WIRE RANGE A.W.G. mm <sup>2</sup>	ITEM NO.	DIMENSION inch(mm)					
		F	L	W	B	D	C
16 A.W.G.	□ 178-7308	0.315	0.551	0.138	0.248	0.079	0.067
1.5 mm <sup>2</sup>		8	14	3.5	6.3	2.000	1.7