

## Features

- Large static generator engines
- Compressors
- Motors
- Electronic control panels
- Engine Mounts

## RS PRO Cylindrical Male - Male Anti-Vibration Mounts

RS Stock No.: 1263910 to 1264272



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

*Male - Male Cylindrical Mounts:*


*A Simple And Cost effective mount. For use in compression and shear. A Very large range of available size and studs.*

*H - Height*

*D- Diameter*

*G - Tread Size*

*L - Stud Length*

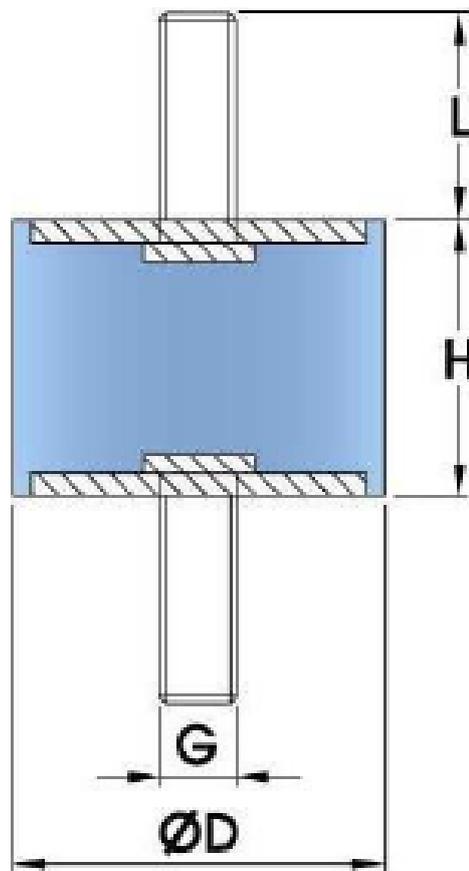

## General Specifications

RS Code	Metal type	Rubber	Hardness	D (mm)	H (mm)	GxL (mm)	Max. Shear Load	Max. Compression Load
1263935	Zinc plated steel	Natural Rubber	60 Shore A	8	8	M3x10	1.6kg	4.8kg
1263936	Zinc plated steel	Natural Rubber	50 Shore A	8	8	M3x6	1.02kg	3.05kg
1263937	Zinc plated steel	Natural Rubber	60 Shore A	100	100	M16x41	212kg	500kg
1263938	Zinc plated steel	Natural Rubber	60 Shore A	100	50	M16x47	212kg	715.4kg
1263939	Zinc plated steel	Natural Rubber	55 Shore A	10	8	M4x10	1.44kg	4.32kg
1263910	Stainless steel grade 316	Natural Rubber	60 Shore A	10	8	M5x15	1.8kg	5.4kg
1263940	Zinc plated steel	Natural Rubber	50 Shore A	12.5	20	M5x12	0.7kg	2.2kg
1263941	Zinc plated steel	Natural Rubber	60 Shore A	15	10	M4x10	8kg	18.4kg
1263942	Zinc plated steel	Natural Rubber	60 Shore A	15	30	M5x15	1.2kg	3.5kg
1263943	Zinc plated steel	Natural Rubber	70 Shore A	16	10	M5x12	17.64kg	44.1kg
1263944	Zinc plated steel	Natural Rubber	60 Shore A	16	18	M4x10	4kg	12kg
1263945	Zinc plated steel	Natural Rubber	60 Shore A	16	18	M5x12	4kg	12kg
1263946	Zinc plated steel	Natural Rubber	60 Shore A	16	18	M5x15	4kg	12kg
1263947	Zinc plated steel	Natural Rubber	60 Shore A	18	8.5	M6x15	8.7kg	26kg

# Anti Vibration Mounts



1263948	Zinc plated steel	Natural Rubber	50 Shore A	20	15	M6x18	5.33kg	15.62kg
1263911	Stainless steel grade 304	Natural Rubber	60 Shore A	20	15	M8x23	5.4kg	18kg
1263949	Zinc plated steel	Natural Rubber	60 Shore A	20	20	M6x15	8.4kg	22kg
1263950	Zinc plated steel	Natural Rubber	60 Shore A	20	20	M6x18	8.4kg	22kg
1263951	Zinc plated steel	Natural Rubber	60 Shore A	20	30	M6x20	8.2kg	20.4kg
1263952	Zinc plated steel	Natural Rubber	70 Shore A	20	30	M6x20	12.05kg	29.99kg
1263953	Zinc plated steel	Natural Rubber	50 Shore A	25	10	M8x20	8.38kg	41.91kg
1263954	Zinc plated steel	Natural Rubber	60 Shore A	25	15	M6x18	13.2kg	43kg
1263955	Zinc plated steel	Natural Rubber	60 Shore A	25	15	M8x20	13.2kg	43kg
1263956	Zinc plated steel	Natural Rubber	60 Shore A	25	20	M8x20	13.2kg	36.8kg
1263957	Zinc plated steel	Natural Rubber	60 Shore A	25	25	M6x18	13.2kg	34.2kg
1263958	Zinc plated steel	Natural Rubber	55 Shore A	25	25	M6x20	10.56kg	27.36kg
1263959	Zinc plated steel	Natural Rubber	60 Shore A	25	30	M6x18	13.2kg	32.8kg
1263960	Zinc plated steel	Natural Rubber	60 Shore A	25	30	M8x10	13.2kg	32.8kg
1263961	Zinc plated steel	Natural Rubber	60 Shore A	25	30	M8x20	13.2kg	32.8kg
1263962	Zinc plated steel	Natural Rubber	45 Shore A	25	35	M6x20	0.7kg	2.2kg

1263963	Zinc plated steel	Natural Rubber	60 Shore A	30	15	M8x25	19kg	75.6kg
1263964	Zinc plated steel	Natural Rubber	60 Shore A	30	20	M8x20	19kg	59kg
1263912	Stainless steel grade 316	Natural Rubber	55 Shore A	30	20	M8x20	15.2kg	47.2kg
1263965	Zinc plated steel	Natural Rubber	60 Shore A	30	22	M8x25	19kg	54kg
1263966	Zinc plated steel	Natural Rubber	60 Shore A	30	25	M8x20	19kg	52.6kg
1263967	Zinc plated steel	Natural Rubber	50 Shore A	30	30	M8x20	12.06kg	31.5kg
1263968	Zinc plated steel	Natural Rubber	60 Shore A	30	30	M8x25	19kg	49.6kg
1263969	Zinc plated steel	Natural Rubber	50 Shore A	35	30	M6x15	0.7kg	2.2kg
1263970	Zinc plated steel	Natural Rubber	45 Shore A	40	20	M10x25	17kg	63.2kg
1263971	Zinc plated steel	Natural Rubber	60 Shore A	40	25	M10x25	34kg	108kg
1263972	Zinc plated steel	Natural Rubber	60 Shore A	40	28	M10x25	34kg	98.4kg
1263973	Zinc plated steel	Natural Rubber	60 Shore A	40	30	M10x23	34kg	96.2kg
1263913	Stainless steel grade 304	Natural Rubber	60 Shore A	40	30	M10x25	34kg	96.2kg
1263974	Zinc plated steel	Natural Rubber	60 Shore A	40	30	M8x23	34kg	96.2kg
1263975	Zinc plated steel	Natural Rubber	50 Shore A	40	35	M8x23	21.59kg	58.42kg
1263976	Zinc plated steel	Natural Rubber	60 Shore A	40	40	M8x20	34kg	87.4kg

# Anti Vibration Mounts



1263977	Zinc plated steel	Natural Rubber	60 Shore A	40	40	M8x23	34kg	87.4kg
1263978	Zinc plated steel	Natural Rubber	60 Shore A	50	20	M10x25	53kg	249.6kg
1263979	Zinc plated steel	Natural Rubber	60 Shore A	50	25	M10x25	53kg	195.2kg
1263980	Zinc plated steel	Natural Rubber	60 Shore A	50	30	M10x25	53kg	169.2kg
1263981	Zinc plated steel	Natural Rubber	60 Shore A	50	35	M10x25	53kg	154.8kg
1263982	Zinc plated steel	Natural Rubber	60 Shore A	50	40	M10x25	53kg	146kg
1263914	Stainless steel grade 316	EPDM Rubber	60 Shore A	50	40	M10x28	53kg	146kg
1263983	Zinc plated steel	Natural Rubber	60 Shore A	50	42	M12x20	53kg	143kg
1263984	Zinc plated steel	Natural Rubber	60 Shore A	50	45	M10x25	53kg	140.2kg
1264268	Zinc plated steel	Natural Rubber	60 Shore A	60	25	M10x25	60kg	305kg
1264269	Zinc plated steel	Natural Rubber	60 Shore A	60	35	M10x25	60kg	247.4kg
1264270	Zinc plated steel	Natural Rubber	65 Shore A	70	35	M12x40	96kg	455.04kg
1264271	Zinc plated steel	Natural Rubber	45 Shore A	70	50	M10x25	40kg	142.3kg
1263915	Stainless steel grade 316	Natural Rubber	40 Shore A	75	40	M12x40	52.21kg	178kg
1264272	Zinc plated steel	Natural Rubber	60 Shore A	75	50	M12x40	119.2kg	353.2kg

