

## Features

- USB 2.0
- A - B
- Black

## RS PRO USB 3.0 A-B Cable - Black

RS Stock No: 2862921, 2862922, 2862923



RS Professionally Approved Products bring to you, professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

The RS PRO range of "SuperSpeed USB 3.0 " Type A (male) to Type B (male) cables support a data transfer rate up to 5 Gbit/s (625 MB/s), which is about ten times faster than USB 2.0 technology.

This is a standard Type A to B cable; it is designed to connect a Host to a Device. The Host (A) connection will connect to a computer/laptop and the Device (B) connection is commonly found on external hard drives, docking stations and USB hubs.

The official name for this cable would be USB3.2 Gen 1. (Previously known as USB3.1 Gen 1 and USB 3.0)

## General Specifications



USB Type	USB 3.0
Connector A	Male USB A
Connector A Type	USB 3.0
Connector A Gender	Male
Connector B	Male USB B
Connector B Type	USB 3.0
Connector B Gender	Male
Connector Style	Straight
Data Transfer Rate	5Gbps
Outer Sheath Material	PVC
Sheath Colour	Black
Connector Plating	Nickel
Pin Construction	Copper

## Approvals

Standards Met	CE UKCA ROHS REACH
Declarations	CE UKCA ROHS REACH

## Similar Products

Stock No.	Length	Spec	Colour
2862921	1mtr	USB3.0 A-M to Type B-M Cable	Black
2862922	3mtr	USB3.0 A-M to Type B-M Cable	Black
2862923	5mtr	USB3.0 A-M to Type B-M Cable	Black

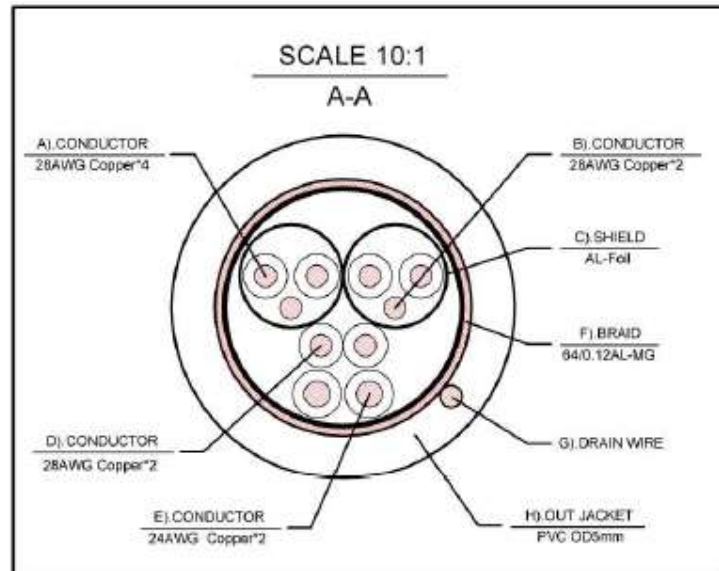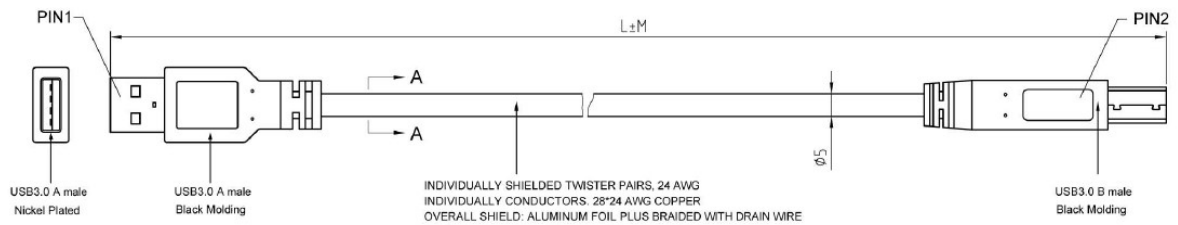

### Notes:

1. CABLE ASSEMBLY SHALL BE TESTED FOR CONTINUITY
2. USB3.0 CABLE 24AWG COPPER, OUTER JACKET OD=5MM
3. HOOD:MOLDING TYPE,BLACK IN COLOR
4. BOTH SIDES INNER MOLD MATERIAL PE.
- 5.CABLE ELECTRICAL TEST:  
100% OPEN SHORAR AND MIS-WIRE TEST