

特点

- 适合标准的 Ir 切口
- 可从正面或背面安装
- 低后部轮廓可确保节省空间
- 亚光黑表面框架

RS Pro 接头、面板安装、插座 2.0 a 至 a、插入式、直向 - 单端 口

RS 号: 916-0221



RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与杰出品牌相当的质量、而无需支付高昂的价格。

此款金属 USB 馈通连接器由备受信赖的 RS PRO 推出，它拥有专为适用标准 XLR 格式底盘设计的坚固面板，因此它可连接和适应不同的 USB 类型。

此系列中提供：

[907-5621](#) - usb 3.0 a 至 a 馈通连接器、带 埋头螺钉孔
[907-5624](#) - usb 3.0 b 至 a 馈通连接器、带埋头螺钉孔。
[907-5628](#) - usb 2.0 b 至 a 馈通连接器、带埋头螺钉孔。
[907-5630](#) - usb 2.0 a 至 b 馈通连接器、带埋头 螺钉孔
[907-5637](#) - usb 2.0 b 至 a 馈通连接器、带埋头 螺钉孔
[916-0215](#) - usb 3.0 a 至 a 馈通连接器
[916-0224](#) - usb 3.0 b 至 a 馈通连接器
[916-0227](#) - usb 2.0 b 至 a 馈通连接器
[916-0221.](#) - usb 2.0 a 至 a 馈通连接器
[916-0230](#) - usb 2.0 a 至 b 馈通连接器

一般规格

性别	母
安装类型	面板安装
usb 类型	a 至 a
终止方法	插入
usb 版本	2.0
身体方向	直向
端口数	1
触点材料	金属
颜色	黑色
插入材料	ABS
框架材料	镀镍锌压铸件
外壳材料	镀镍钢
应用	航海、自动化、军事、室外 led 照明

电气规格

额定电流	最大 1.5 安培
额定电压	30Vac
触点电阻	50mΩ μ a 最大值
绝缘电阻	20mΩ 分钟
介电耐电压	500Vac

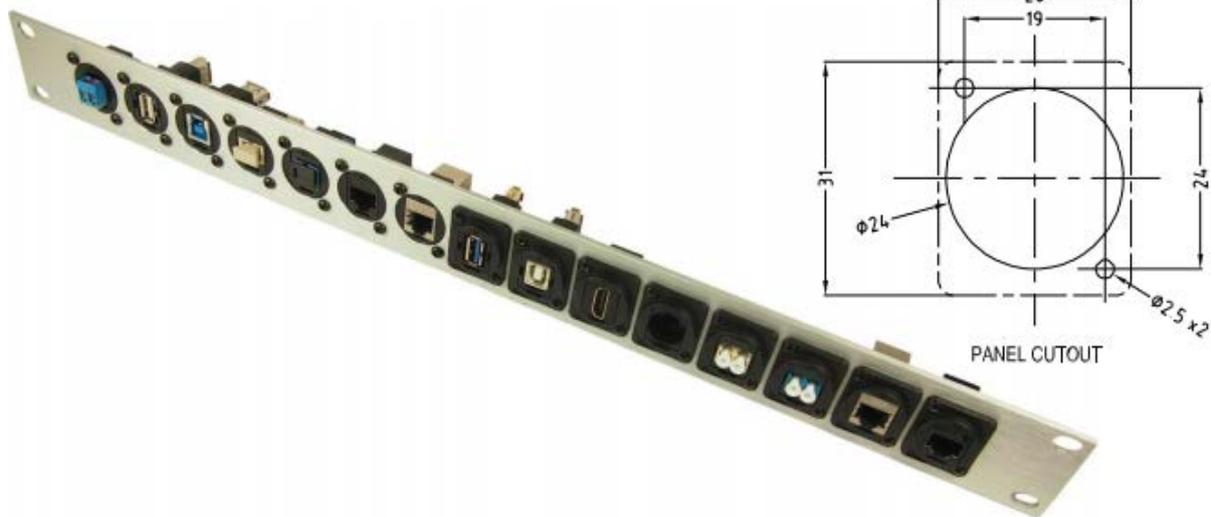
操作环境规格

最低工作温度	-20.0°C
最高工作温度	50°C

认证

合规性 / 认证	rohs
----------	------





Part No.
CP30205NMB
RS Stock No.
916-0215

Description
 USB 3.0 A to USB 3.0 A, CSK hole.



Part No.
CP30206NMB
RS Stock No.
916-0224

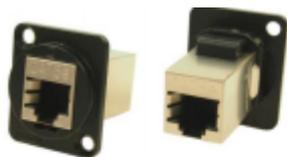
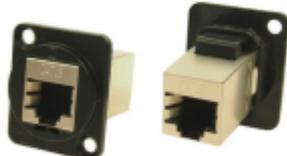
Description
 USB 3.0 B to USB 3.0 A, CSK hole.



Part No.
CP30207NMB
RS Stock No.
916-0227

Description
 USB 2.0 B to USB 2.0 A, CSK hole.

		Part No. CP30208NMB RS Stock No. 916-0221	Description USB 2.0 A to USB 2.0 A, CSK hole
		Part No. CP30209NMB RS Stock No. 916-0230	Description USB 2.0 A to USB 2.0 B, CSK hole
		Part No. CP30213MB RS Stock No. 916-0233	Description LC Duplex SM adaptor, CSK Hole
		Part No. CP30214MB	Description LC Duplex MM, CSK Hole
		Part No. CP30215MB RS Stock No. 916-0246	Description SC Simplex SM, CSK Hole
		Part No. CP30216MB	Description SC Simplex MM, CSK Hole
		Part No. CP30217MB RS Stock No. 916-0249	Description Toslink, CSK Hole
		Part No. CP30220MB RS Stock No. 916-0243	Description UTP Cat5e RJ45-RJ45, CSK Hole

	Part No. CP30220SMB RS stock No. 916-0252	Description FTP Cat5e RJ45-RJ45, Shielded, CSK Hole
	Part No. CP30222MB RS Stock No. 916-0255	Description UTP Cat6 RJ45-RJ45, CSK Hole
	Part No. CP30222SMB RS Stock No. 916-0259	Description FTP Cat6 RJ45-RJ45, Shielded, CSK Hole
	Part No. CP30230MB	Description RCA Phono RED, CSK Hole
	Part No. CP30231MB	Description RCA Phono WHITE, CSK Hole
	Part No. CP30232MB	Description RCA Phono YELLOW, CSK Hole Other colours available on request.
	Part No. CP30241MB	Description Blanking Plate, CSK Hole