



EN

Datasheet

RS PRO NYLON-INSULATED CORD END

TERMINALS

Stock number: 178-7282

MAXIMUM ELECTRIC CURRENT:

A.W.G.	21
AMP.	5.5


MAXIMUM ELECTRICAL RATING: 105° C 600 VOLTS MAX.

INSULATION MATERIAL: NYLON

TERMINAL MATERIAL: COPPER TUBE

SURFACE TREATMENT: TIN PLATE

INSULATION COLOR: YELLOW

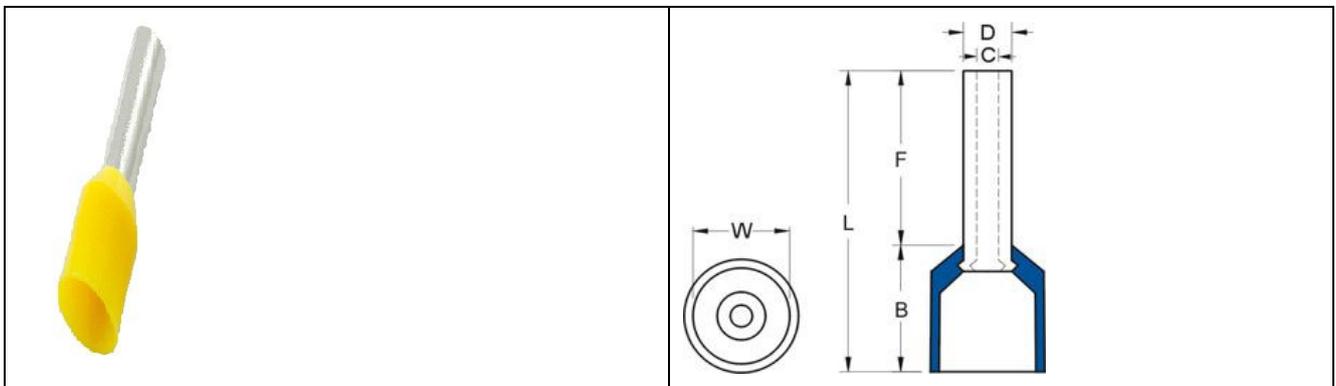

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION inch(mm)					
		F	L	W	B	D	C
24 A.W.G.	178-7282	0.236	0.409	0.075	0.173	0.043	0.031
0.25 mm ²		6	10.4	1.9	4.4	1.100	0.8